

C1608C0G1H100D080AA

TDK Item Description : C1608C0G1H100DT****



Application & Main Feature

Commercial Grade (General (Up to 50V))

Series

C1608 [EIA CC0603]



Dimensions

L 1.60mm +/-0.1mm
W 0.80mm +/-0.1mm
T 0.80mm +/-0.1mm
B 0.20mm Min.
G 0.30mm Min.

Temperature Characteristic

C0G (-55 to 125 degC 0+/-30ppm/degC)

Rated Voltage

1H (50Vdc)

Capacitance

10pF

Capacitance Tolerance

D (+/-0.5pF)

O Factor

600 Min.


Insulation Resistance

10Gohm Min.

AEC-Q200

Not Applicable


|Z|, ESR vs. Freq. Characteristics

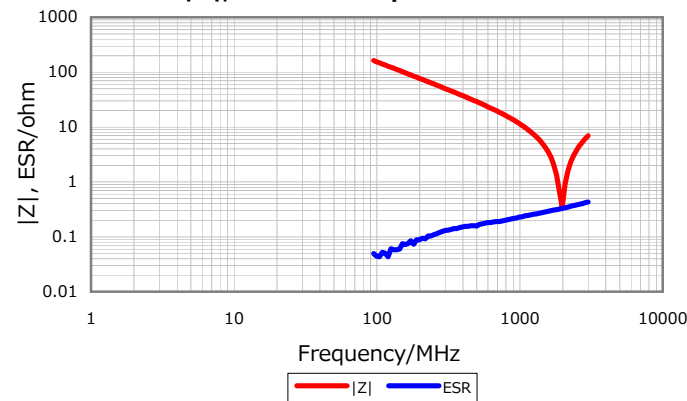


DC Bias Characteristic



Cap. vs. Freq. Characteristic

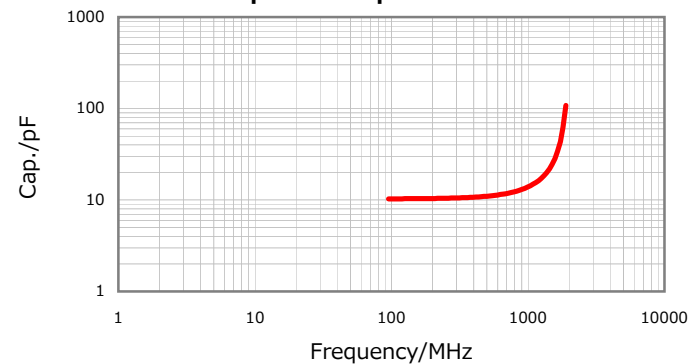

Temperature Characteristic

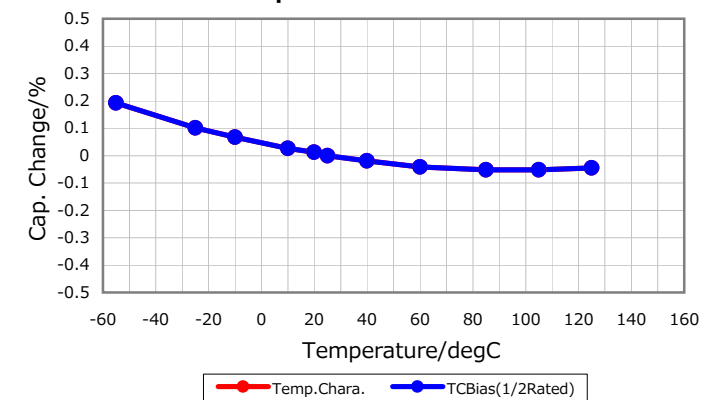

All specifications are subject to change without notice.

February 3, 2014

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

TDK:

[C1608C0G1H100D080AA](#)