



 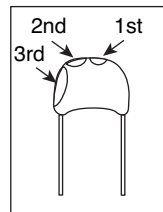


RF Chokes

43LR Series

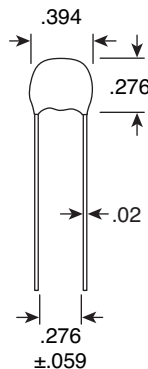

Color Code



SPECIFICATIONS

- Type: epoxy dipped, radial lead
- Inductive tolerance: .22 ~ 1.0 μ H $\pm$ 20%, 1.2~1000 μ H $\pm$ 10%
- Initial permeability: 70
- Maximum permeability: 180
- Coercive force: 4.4 oersteds
- Residual flux density: 1200 gauss
- Curie temperature: 300°C
- Volume resistivity: 10⁷ Ω
- Specific gravity: 4.7
- Loss factor: .075 @ 5 MHz
- Temperature coefficient of initial permeability: .3% per °C

Mouser Stock No.	L (μ H)	Test Freq. (MHz)	Res. Freq. (MHz)	DCR Max. (Ω)	Max DC Current (mA)	Color Code		
						1st	2nd	3rd
43LR227	.22	25.200	287.0	.123	---	Red	Red	Slvr
43LR337	.33	25.200	217.0	.138	---	Org	Org	Slvr
43LR477	.47	25.200	161.0	.150	---	Yel	Vio	Slvr
43LR687	.68	25.200	126.0	.167	---	Blu	Gry	Slvr
43LR106	1.00	7.960	96.0	.201	330	Brn	Blk	Gld
43LR126	1.20	7.960	84.0	.218	320	Brn	Red	Gld
43LR156	1.50	7.960	71.0	.240	315	Brn	Grn	Gld
43LR226	2.20	7.960	55.0	.280	300	Red	Red	Gld
43LR276	2.70	7.960	50.0	.281	295	Red	Vio	Gld
43LR336	3.30	7.960	43.0	.338	285	Org	Org	Gld
43LR476	4.70	7.960	33.0	.420	275	Yel	Vio	Gld
43LR566	5.60	7.960	29.0	.450	270	Grn	Blu	Gld
43LR686	6.80	7.960	25.0	.488	260	Blu	Gry	Gld
43LR105	10.00	2.520	20.0	1.140	250	Brn	Blk	Blk
43LR125	12.00	2.520	16.0	1.280	245	Brn	Red	Blk
43LR155	15.00	2.520	13.0	1.400	235	Brn	Grn	Blk
43LR185	18.00	2.520	12.0	1.550	225	Brn	Gry	Blk
43LR225	22.00	2.520	10.0	1.730	220	Red	Red	Blk
43LR275	27.00	2.520	9.0	1.950	215	Red	Vio	Blk
43LR335	33	2.520	8.0	2.150	205	Org	Org	Blk
43LR395	39	2.520	7.0	2.360	200	Org	Wht	Blk
43LR475	47	2.520	9.0	1.940	190	Yel	Vio	Blk
43LR565	56	2.520	9.0	1.950	180	Grn	Blu	Blk
43LR825	82	2.520	8.0	2.400	160	Gry	Red	Blk
43LR104	100	0.796	7.0	2.850	150	Brn	Blk	Brn
43LR124	120	0.796	6.0	4.350	145	Brn	Red	Brn
43LR154	150	0.796	5.0	3.600	130	Brn	Grn	Brn
43LR184	180	0.796	4.0	4.020	120	Brn	Gry	Brn
43LR224	220	0.796	4.0	4.700	115	Red	Red	Brn
43LR274	270	0.796	3.0	5.400	105	Red	Vio	Brn
43LR334	330	0.796	3.0	7.500	100	Org	Org	Brn
43LR394	390	0.796	3.0	8.550	90	Org	Wht	Brn
43LR474	470	0.796	2.8	9.900	85	Yel	Vio	Brn
43LR564	560	0.796	2.5	11.400	80	Grn	Blu	Brn
43LR684	680	0.796	2.3	10.800	68	Blu	Gry	Brn
43LR824	820	0.796	2.1	12.300	58	Gry	Red	Brn
43LR103	1000	0.252	1.9	14.100	50	Brn	Blk	Red



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Xicon:](#)

[43LR103](#) [43LR104](#) [43LR105](#) [43LR106](#) [43LR124](#) [43LR125](#) [43LR126](#) [43LR155](#) [43LR156](#) [43LR184](#) [43LR185](#)
[43LR224](#) [43LR225](#) [43LR226](#) [43LR274](#) [43LR335](#) [43LR336](#) [43LR476](#) [43LR477](#) [43LR564](#) [43LR565](#) [43LR686](#)
[43LR824](#) [43LR825](#)