




SIDE VIEW

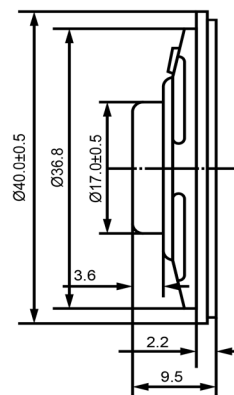

BOTTOM VIEW

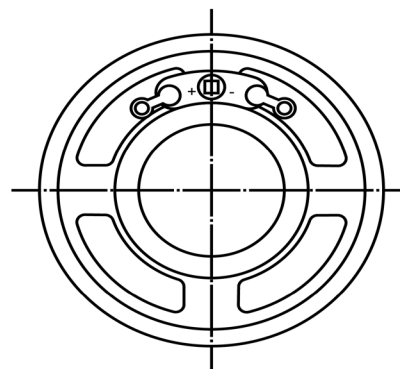

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	600	(Hz)								
Frequency Range	600 ~ 7,000	(Hz)								
SPL @ 10cm	82	(dBA)								
Impedance	16	(Ohm)								
Cone Material	Paper									
Nominal Power	0.25	(W)								
Max Power	0.5	(W)								
Mount Type	Flush									
Operating Temperature	-25 ~ +55	°C								
Storage Temperature	-25 ~ +55	°C		Drawn by		Date	Checked by	Date	Approved by	Date
Weight	10	(g)		A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			DB UNLIMITED	Dynamic Speaker			SP400616-1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP400616-1](#)