





Complete Hex Program

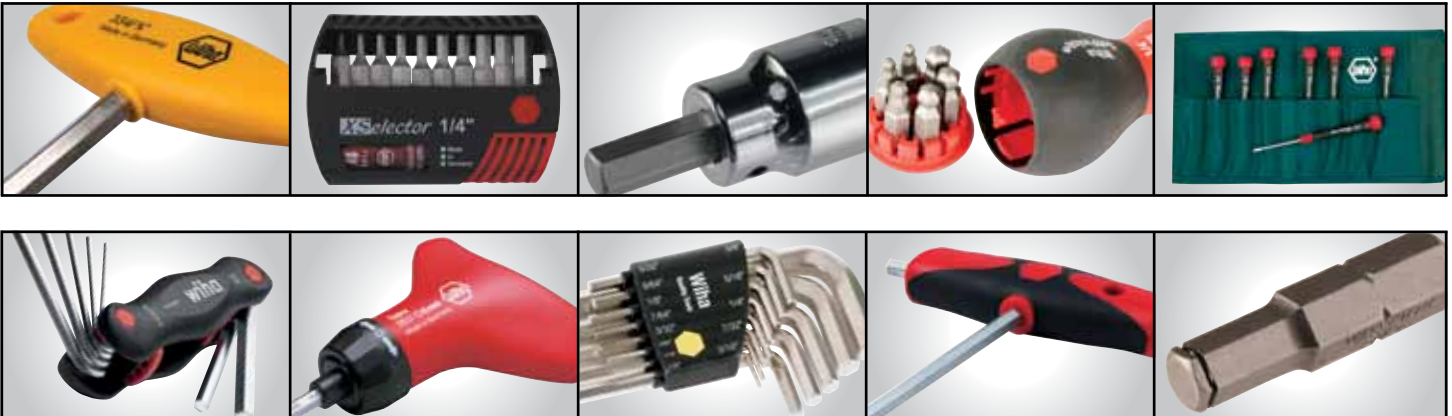

Professional HEX Tools *Inch & Metric*



   Wiha Hex Tools Index

	DESCRIPTION	Page
	T-handles	8
	PocketStar Fold Outs	16
	L-keys - Long/Short Nickel & Black Finish	17-20
	Insulated T-handle	21
	Insulated Hex Drivers	21
	Insulated L-keys	22
	Insulated Sockets	22
	Drive-Loc VI Blades	23
	ESD Safe Precision	26
	Precision	28
	PicoFinish	27
	SYSTEM 4 Blades	29-30
	SYSTEM 4 Micro Bits	31
	Insert/Power Bit Sets	33
	XSelectors	34
	Bit Insert & Power Bits	35-37
	Sockets	38-39



Wiha Security Hex Index

	DESCRIPTION	Page
	SYSTEM 4 Micro Bits	31
	Insert Bits	35-37
	Sockets	38-39

Wiha Ball End Hex Tools Index

	DESCRIPTION	Page
	Ball End L-keys & Sets Chrome Finish	5
	Ball End L-keys & Sets Black Finish	6-7
	Stainless Steel L-keys & Set	6
	Soft Grip T-handles Chrome & Black Finish	9-10
	3K Series Screwdrivers	14-15
	Drive-Loc VI Blades	23
	Precision	28-29
	PicoFinish Soft Grip	27
	SYSTEM 4 Blades	30
	Stubby Bit Holder Sets	32
	Ball End Hex Insert Bit	37
	Ball End Hex Socket	39

  MagicRing Screw Holding Hex Tools Index

	DESCRIPTION	Page
	L-keys Screw Holding	4
	T-handles Screw Holding	8
	SoftFinish Screw Holding Cushion Grip	12-13
	PocketStars Screw Holding	16
	Insert Bits Screw Holding	33
	Power Bits Screw Holding	33
	Bit-Selectors Screw Holding Insert & Power Bits	33


Wiha Drive-Loc VI Index

DESCRIPTION	Page
 Drive-Loc VI Handle SoftFinish® Cushion Grip	23
 Drive-Loc VI Handle ESD Safe Cushion Grip	23
 Drive-Loc VI Handle MicroFinish Non-Slip Grip	23
 Drive-Loc VI Blades Ball End Hex & Hex Inch/Metric	23
 Drive-Loc VI Blade Set	23

Wiha TorqueControl Tools Index

DESCRIPTION	Page
 TorqueFix Handle	24
 TorqueVario Handle	24
 Hex Inch/Metric Blades	24
 T-handle Torque Tools	25
 Hex Inch/Metric Blades	25

 Wiha Bit Sets Index

DESCRIPTION	Page
 MicroBit Sets	31
 Stubby Bit Holder Sets	32
 Topra Bit Sets	32
 Bit Selector Sets	33
 Power Bit Belt Packs	34
 XSelectors	34
 PokitPaks	34

Wiha Power & Insert Bits Index

DESCRIPTION	Page
 MagicRing Hex Inch & Metric Insert/Power Bits	33
 Hex Inch & Metric Insert/Power Bits	35-37
 Security Bits Inch & Metric Insert/Power Bits	36
 Ball End Hex Inch & Metric	37
 Stainless Steel Metric	36

Wiha Sockets & Sets Index

DESCRIPTION	Page
 Insulated Sockets	22
 Hex Bit Sockets 1/4" Drive	38-39
 Hex Bit Sockets 3/8" Drive	39
 Ball End Sockets	39
 6" Bit Sockets 1/4" & 3/8" Drive	38
 Socket Sets	40

MagicRing Ball End Hex Keys



Ball End Hex Keys
Chamfered ends for easy insertion

Ball End Hex Keys
CVM steel, hardened, hard chromed, screw holding

ProStar Holder (9-13 pc. Sets)
Sliding front detachable

ProStar Holder
Every key can be taken out separately without having to move another key

U.S. Patent 6,302,001 B1



669 MagicRing Ball End Metric Hex L-key, Long

Blade CVM steel, hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.	
66904*	1.5	90	14	.01	10	No Ring
66908*	2.0	99	16	.01	10	No Ring
66912*	2.5	111	18	.01	10	No Ring
MagicRing						
66916	3.0	125	20	.02	10	
66920	4.0	138	25	.04	10	
66924	5.0	158	28	.07	10	
66928	6.0	178	32	.12	10	
66936	8.0	198	36	.23	10	
66944	10.0	221	40	.40	10	

* Standard Ball - No Ring




66990 9 Piece MagicRing Long Metric Ball End Hex L-key Set, In ProStar Holder

Blade CVM steel, hardened, hard chrome finish.

Item No.	mm	mm	mm	mm	mm	lbs.
66990	66904*	1.5	90	66924	5.0	158
	66908*	2.0	99	66928	6.0	178
	66912*	2.5	111	66936	8.0	197
	66916	3.0	125	66944	10.0	221
	66920	4.0	138			

* Standard Ball - No Ring

Screw Holding Hex Tools!

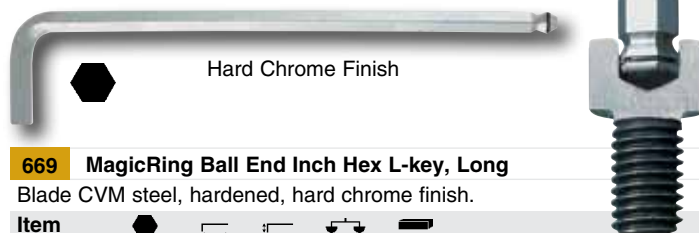

669 MagicRing Ball End Inch Hex L-key, Long

Blade CVM steel, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.	
66945*	.050	2.8	.5	.01	10	No Ring
66946*	1/16	3.1	.6	.01	10	No Ring
66947*	5/64	3.5	.7	.01	10	No Ring
66950*	3/32	3.9	.7	.01	10	No Ring
66952*	7/64	4.3	.7	.02	10	No Ring
MagicRing						
66953	1/8	4.6	.8	.02	10	
66955	9/64	5.2	.9	.03	10	
66956	5/32	5.7	1.0	.04	10	
66959	3/16	6.2	1.1	.06	10	
66962	7/32	6.7	1.2	.09	10	
66965	1/4	7.3	1.2	.13	10	
66968	5/16	8.0	1.4	.22	10	
66971	3/8	8.8	1.6	.36	10	

* Standard Ball - No Ring



66991 13 Piece MagicRing Long Inch Ball End Hex L-key Set, In ProStar Holder

Blade CVM steel, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	Inch	lbs.
66991	66945*	.050	2.8	66956	5/32
	66946*	1/16	3.1	66959	3/16
	66947*	5/64	3.5	66962	7/32
	66950*	3/32	3.9	66965	1/4
	66952*	7/64	4.3	66968	5/16
	66953	1/8	4.6	66971	3/8
	66955	9/64	5.2		

* Standard Ball - No Ring



66992 22 Piece Combination MagicRing L-key Set, In ProStar Holder

Blade CVM steel, hardened, hard chrome finish.

Item No.	lbs.
66992	Set includes Inch & Metric: 2.21
	66990 Set - 1.5*, 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm
	66991 Set - .050*, 1/16*, 5/64*, 3/32*, 7/64*, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

* Standard Ball - No Ring

Metric Ball End Hex Keys Chrome Finish



669 Ball End Metric Hex L-key, Long Arm


Blade CVM steel, hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.
66904	1.5	90	14	.004	10
66908	2.0	99	16	.007	10
66912	2.5	111	18	.012	10
66918	3.0	125	20	.019	10
66922	4.0	138	25	.042	10
66926	5.0	158	28	.072	10
66930	6.0	178	32	.12	10
66937	8.0	198	36	.23	10
66938	10.0	221	40	.40	10



66994 9 Piece Metric Ball End Hex Long L-key Set

Item No.	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	lbs. .98
66994		

 

66995 6 Piece Metric Ball End Hex Long L-key Set

Item No.	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0mm	lbs. .21
66995		



66998 11 Piece Metric Ball End Hex Long L-key Set

Item No.	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 7.0, 8.0, 9.0, 10.0mm	lbs. 1.36
66998		

Inch Ball End Hex Keys Chrome Finish



369 Ball End Inch Hex L-key, Long Arm

Blade CVM steel, hardened, hard chrome finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.
36940	.050	2.8	.5	.002	10
36941	1/16	3.1	.6	.004	10
36942	5/64	3.5	.7	.007	10
36943	3/32	3.9	.7	.010	10
36948	7/64	4.3	.7	.016	10
36949	1/8	4.6	.8	.021	10
36951	9/64	5.2	.9	.029	10
36954	5/32	5.7	1.0	.035	10
36957	3/16	6.2	1.1	.059	10
36958	7/32	6.7	1.2	.092	10
36960	1/4	7.3	1.2	.13	10
36961	5/16	8.0	1.4	.22	10
36963	3/8	8.8	1.6	.36	10



36998 13 Piece Inch Ball End Hex Long L-key Set, In Plastic

Holder Blade CVM steel, hardened, hard chrome finish.

Item No.	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs. 1.0
36998		



66993 2 Pack Inch & Metric Ball End Hex L-key Sets High alloy CVM steel, hardened, hard chrome finish. In molded Holders

Item No	lbs.
66993 2 Sets with 22 L-keys include:	
Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	2.0
Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	

ErgoStar Ball End Hex Keys Chrome Finish

Fast Auto Open
Key Holder



66996 9 Piece ErgoStar Metric Ball End Hex Long L-key Set

Item No.	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,	
66996	6.0, 8.0, 10.0mm	lbs. 1.02

Fast Auto Open
Key Holder



66988 13 Piece ErgoStar Inch Ball End Hex Long L-key Set

Item No.	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8,	
66988	9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs. 1.08



Fast Auto Open
Key Holder



66982 22 Piece ErgoStar Inch/Metric Ball End Hex Long L-key Set

Item No.	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8,	
66982	9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	lbs. 2.10
	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0,	
	6.0, 8.0, 10.0mm	



ErgoStar Inch Ball End L-key Set

- Patented ErgoStar auto open key holder
- Keys of chrome-vanadium-molybdenum steel
- 60HRC through hardened durability
- Hard chrome finish for best wear resistance

Stainless Steel Metric Ball End Hex Key



369 Stainless Steel Ball End Metric Hex L-key, Long Arm

Blade CVM steel, hardened, hard chrome finish.

Item No.	mm	mm	mm	lbs.	pkg.
36911	1.5	91	14	.004	10
36913	2.0	101	18	.007	10
36914	2.5	113	20	.012	10
36915	3.0	128	23	.020	10
36917	4.0	142	29	.050	10
36918	5.0	163	33	.074	10
36919	6.0	184	38	.13	10
36921	8.0	206	44	.25	10
36922	10.0	231	50	.44	10



36988 9 Pc. Stainless Steel Ball End L-key Set

In molded ergo handle

Item No.		
36988	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0mm	lbs. .88
	6.0, 8.0, 10.0mm	

L-keys Black Finish Sets



Inch & Metric

36995 2 Pack Inch & Metric Ball End Hex L-key Sets High alloy

CVM steel, hardened, black finish. Molded ergonomic handle.

Item No		
36995	2 Sets with 22 L-keys include:	lbs. 2.21
	Sizes: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	
	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	



Inch & Metric

TORX

36696 3 Pack Inch & Metric Ball End Hex & TORX L-key Sets

High alloy CVM steel, hardened, black finish. Molded ergonomic handle.

Item No		
36696	3 Sets with Hex & TORX L-keys include:	lbs.
	Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm	
	Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	
	TORX: T6, T7, T8, T9, T10, T15, T20, T25, T27, T30	

Metric Ball End Hex Keys Black Finish



369 Ball End Hex Metric L-key, Long Arm

Blade CVM steel, hardened, black finish.

Item No.	mm	mm	mm	lbs.	pkg.
36904	1.5	90	14	.004	10
36908	2.0	99	16	.007	10
36912	2.5	111	18	.012	10
36916	3.0	125	20	.019	10
36920	4.0	138	25	.042	10
36924	5.0	158	28	.072	10
36928	6.0	178	32	.12	10
36936	8.0	198	36	.23	10
36944	10.0	221	40	.40	10



36990 9 Piece Metric Ball End Hex Long L-key Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish.

Blade chrome-vanadium alloy, boron steel, hardened, black finish.							
Item							
No.		mm	mm		mm	mm	lbs.
36990	36904	1.5	90	36924	5.0	158	.98
	36908	2.0	99	36928	6.0	178	
	36912	2.5	111	36936	8.0	198	
	36916	3.0	125	36944	10.0	221	
	36920	4.0	138				



36992 6 Piece Metric Ball End Long Hex L-key Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish.

Blade chrome vanadium molybdenum steel, hardened, black finish.							
Item							
No.		mm	mm		mm	mm	lbs.
36992	36904	1.5	90	36916	3.0	125	.30
	36908	2.0	99	36920	4.0	138	
	36912	2.5	111	36924	5.0	158	

Inch Ball End Hex Keys Black Finish



369 Ball End Hex Inch L-key, Long Arm

Blade CVM steel, hardened, black finish.

Item No.	Inch	Inch	Inch	lbs.	pkg.
36945	.050	2.8	.5	.002	10
36946	1/16	3.1	.6	.004	10
36947	5/64	3.5	.7	.007	10
36950	3/32	3.9	.7	.010	10
36952	7/64	4.3	.7	.016	10
36953	1/8	4.6	.8	.021	10
36955	9/64	5.2	.9	.029	10
36956	5/32	5.7	1.0	.035	10
36959	3/16	6.2	1.1	.059	10
36962	7/32	6.7	1.2	.092	10
36965	1/4	7.3	1.2	.13	10
36968	5/16	8.0	1.4	.22	10
36971	3/8	8.8	1.6	.36	10



36991 13 Piece Inch Ball End Hex Long L-key Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish.

Item No.		lbs.
36991	13 pc. set includes: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1.0



36993 8 Piece Inch Ball End Hex Long L-key Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish.

Item No.		lbs.
36993	8 pc. set includes: 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16"	.62

Wiha MagicRing Screw Holding T-handle


Hole for hanging

Proportioned ergonomic handle designed for high torque

Handle is molded directly onto blade

Blade CVM tool steel, hardened, hard chrome finish

Screw Holding Hex Tools

Smooth edges prevent injuries & eliminate pressure marks

540 MagicRing Hex Metric Ball End, With Wiha T-handle

Blade CVM steel, hardened, hard chromed. Ball end for easy insertion. Wiha T-handle high quality plastic, impact resistant.

Item No.							
	mm	mm	mm	mm	Inch	lbs.	pkg.
54040	4.0	150	80	176	6.9	.08	10
54050	5.0	150	100	182	7.1	.14	10
54060	6.0	150	100	182	7.1	.17	10
54080	8.0	200	100	232	9.1	.29	10
54086	10.0	200	120	238	9.3	.49	10

540 MagicRing Hex Inch Ball End, With Wiha T-handle

Blade CVM steel, hardened, hard chromed. Ball end for easy insertion. Wiha T-handle high quality plastic, impact resistant.

Item No.							
	Inch	Inch	Inch	Inch	lbs.	pkg.	
54012	5/32	5.8	2.8	6.9	.08	10	
54014	3/16	5.8	4.0	7.2	.14	10	
54016	7/32	5.8	4.0	7.2	.16	10	
54018	1/4	5.8	4.0	7.2	.19	10	
54022	5/16	7.8	4.0	7.2	.29	10	
54024	3/8	7.8	4.7	7.5	.45	10	


54090 5 Piece MagicRing Ball End T-handle Set, Metric Sizes

Blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha T-handle high quality plastic, impact resistant.


Item No.					
	mm	mm	mm	mm	lbs.
54090	54040	4.0 150	54080	8.0 200	1.49
	54050	5.0 150	54086	10.0 200	
	54060	6.0 150			

54091 6 Piece MagicRing Ball End T-handle Set, Inch Sizes

Blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha T-handle high quality plastic, impact resistant.

Item No.					
	Inch	Inch	Inch	Inch	lbs.
54091	54012	5/32 5.8	54018	1/4 5.8	1.59
	54014	3/16 5.8	54022	5/16 7.8	
	54016	7/32 5.8	54024	3/8 7.8	

Wiha Soft Grip Dual Drive T-handle

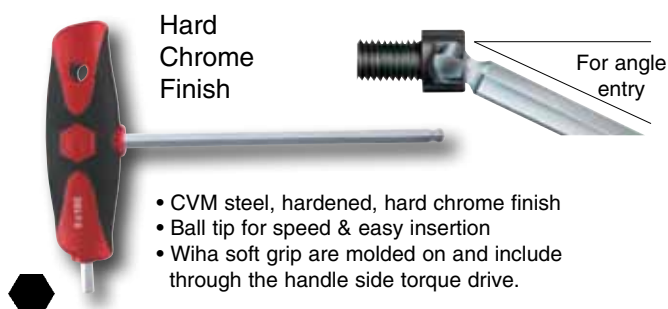

540 Soft Grip Ball End Hex Metric Dual Drive T-handle

Item No.	mm	mm	Tip	lbs.	pkg.
54020	2.0	150	Ball	.06	10
54025	2.5	150	Ball	.06	10
54030	3.0	150	Ball	.07	10
54042	4.0	150	Ball	.09	10
54052	5.0	150	Ball	.18	10
54062	6.0	150	Ball	.21	10
54082	8.0	200	Ball	.35	10
54088	10.0	200	Ball	.55	10


54095 8 Pc. Ball End Hex Metric Soft Grip T-handle Set- No stand

Item								
No.		mm	mm			mm	mm	lbs.
54095	54020	2.0	150	54052	5.0	150		1.90
	54025	2.5	150	54062	6.0	150		
	54030	3.0	150	54082	8.0	200		
	54042	4.0	150	54088	10.0	200		

54092 8 Piece Ball End Hex Metric Soft Grip T-handle Set

Blade chrome-vanadium-molybdenum steel, hardened, chrome finish.
 Wiha soft grips are molded on with through the handle side torque drive.

Item No.			
	mm	mm	lbs.
54092	54020	2.0 150	3.34
	54025	2.5 150	
	54030	3.0 150	
	54042	4.0 150	
	54052	5.0 150	
	54062	6.0 150	
	54082	8.0 200	
	54088	10.0 200	

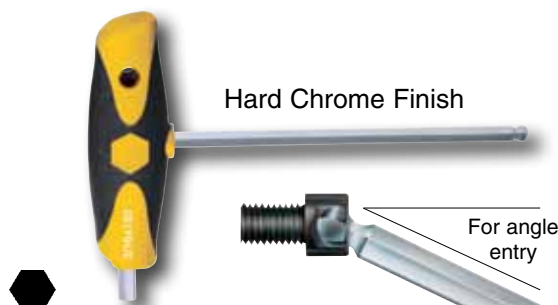

540 Soft Grip Ball End Hex Inch Dual Drive T-handle CVM steel, hardened, hard chrome finish. Ball tip for speed & easy insertion.
 Wiha soft grips are molded on with through the handle side torque drive.

Item No.	Inch	Inch	Tip	lbs.	pkg.
54007	3/32	5.9	Ball	.06	10
54008	7/64	5.9	Ball	.07	10
54009	1/8	5.9	Ball	.08	10
54010	9/64	5.9	Ball	.08	10
54001	5/32	5.9	Ball	.09	10
54002	3/16	5.9	Ball	.17	10
54003	7/32	5.9	Ball	.20	10
54004	1/4	5.9	Ball	.23	10
54005	5/16	7.9	Ball	.35	10
54006	3/8	7.9	Ball	.51	10

54097 10 Pc. Ball End Hex Inch Soft Grip T-handle Set- No stand

Item							
No.		Inch	Inch		Inch	Inch	lbs.
54097	54007	3/32	5.9	54002	3/16	5.9	2.15
	54008	7/64	5.9	54003	7/32	5.9	
	54009	1/8	5.9	54004	1/4	5.9	
	54010	9/64	5.9	54005	5/16	7.9	
	54001	5/32	5.9	54006	3/8	7.9	




54094 8 Piece Ball End Hex Inch Soft Grip T-handle Set

Blade chrome-vanadium-molybdenum steel, hardened, chrome finish.
 Wiha soft grips are molded on with through the handle side torque drive.

Item							
No.		Inch	Inch		Inch	Inch	lbs.
54094	54009	1/8	5.9	54003	7/32	5.9	3.37
	54010	9/64	5.9	54004	1/4	5.9	
	54001	5/32	5.9	54005	5/16	5.9	
	54002	3/16	5.9	54006	3/8	7.9	

Soft Grip Dual Drive T-handle - Black Finish

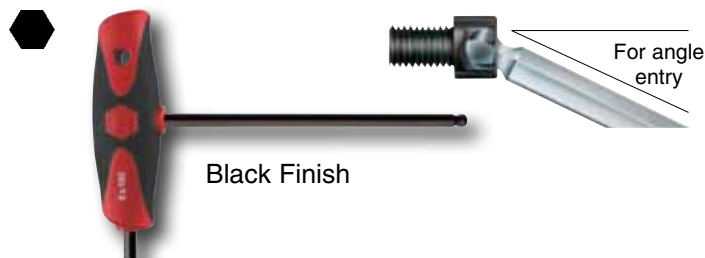

334 Soft Grip Ball End Hex **Metric** Dual Drive T-handle CVM steel, hardened, black finish. Ball tip for speed & easy insertion. Wiha soft grip are molded on with through the handle side torque drive.

Item No.				
	mm	mm	lbs.	pkg.
33442*	2.0	150	.06	10
33444*	2.5	150	.06	10
33446*	3.0	150	.07	10
33448	4.0	150	.09	10
33450	5.0	150	.18	10
33452	6.0	150	.21	10
33454	8.0	200	.35	10
33458	10.0	200	.55	10

*No Ball - Standard Hex



33496 8 Pc. Ball End Hex **Metric** Soft Grip T-handle Set

Blade CVM steel, hardened, black finish. Wiha soft grip are molded on with through the handle side torque drive.

Item No.					
	mm	mm	mm	mm	lbs.
33496	33442*	2.0 150	33450	5.0 150	2.04
	33444*	2.5 150	33452	6.0 150	
	33446*	3.0 150	33454	8.0 200	
	33448	4.0 150	33458	10.0 200	

*No Ball - Standard Hex


33489 8 Piece Ball End Hex **Metric** Soft Grip T-handle Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish. Wiha soft grips are molded on with through the handle side torque drive.

Item No.			
	mm	mm	lbs.
33489	33442*	2.0 150	3.33
	33444*	2.5 150	
	33446*	3.0 150	
	33448	4.0 150	
	33450	5.0 150	
	33452	6.0 150	
	33454	8.0 200	
	33458	10.0 200	

*No Ball - Standard Hex

In metal stand

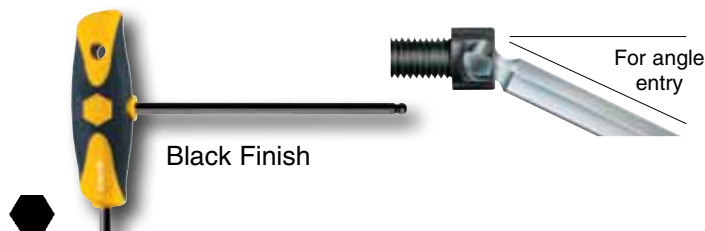

334 Soft Grip Ball End Hex Inch Dual Drive T-handle CVM steel, hardened, black finish. Ball tip for speed & easy insertion. Wiha soft grips are molded on with through the handle side torque drive.

Item No.				
	Inch	Inch	lbs.	pkg.
33418*	5/64	5.9	.06	10
33420*	3/32	5.9	.06	10
33422*	7/64	5.9	.07	10
33424*	1/8	5.9	.08	10
33426*	9/64	5.9	.08	10
33428	5/32	5.9	.09	10
33430	3/16	5.9	.17	10
33432	7/32	5.9	.20	10
33433	1/4	5.9	.23	10
33439	5/16	7.9	.35	10
33440	3/8	7.9	.51	10

*No Ball - Standard Hex

33494 11 Pc. Ball End Hex Inch Soft Grip Dual Drive T-handle Set

Item No.					
	Inch	Inch	Inch	Inch	lbs.
33494	33418*	5/64 5.9	33430	3/16 5.9	2.39
	33420*	3/32 5.9	33432	7/32 5.9	
	33422*	7/64 5.9	33433	1/4 5.9	
	33424*	1/8 5.9	33439	5/16 7.9	
	33426*	9/64 5.9	33440	3/8 7.9	
	33428	5/32 5.9			

*No Ball - Standard Hex

33498 8 Piece Ball End Hex Inch Soft Grip T-handle Set

Item No.				
	Inch	Inch	Inch	lbs.
33498	33424*	1/8 5.9	33432	7/32 5.9
	33426*	9/64 5.9	33433	1/4 5.9
	33428	5/32 5.9	33439	5/16 7.9
	33430	3/16 5.9	33440	3/8 7.9

*No Ball - Standard Hex

33499 8 Piece Ball End Hex Inch Soft Grip T-handle Set

Blade chrome-vanadium-molybdenum steel, hardened, black finish. Wiha soft grips are molded on with through the handle side torque drive.

Item No.			
	Inch	Inch	lbs.
33499	33424*	1/8 5.9	3.46
	33426*	9/64 5.9	
	33428	5/32 5.9	
	33430	3/16 5.9	
	33432	7/32 5.9	
	33433	1/4 5.9	
	33439	5/16 7.9	
	33440	3/8 7.9	

*No Ball - Standard Hex

In metal stand

Wiha T-handle Hex Tools

Ergonomic handle design for high torque

Hole for hanging

Handle is molded directly onto blade

Smooth edges prevent injuries & eliminate pressure marks

Blade CVM tool steel, hardened, nickel-plated

Yellow = Inch
Red = Metric

334 Hex Inch & Metric Drivers, With Wiha T-handle Chamfered tip for easy insertion. Wiha-T-handle high quality plastic, impact resistant.

Item No.	Inch	Inch	Inch	Inch	lbs.	pkg.
33453	3/32	6.0	2.8	7.0	.05	10
33456	7/64	6.0	2.8	7.0	.05	10
33459	1/8	6.0	2.8	7.0	.06	10
33462	9/64	6.0	2.8	7.0	.07	10
33465	5/32	6.0	2.8	7.0	.08	10
33468	3/16	6.0	3.5	7.0	.13	10
33471	7/32	6.0	3.5	7.0	.16	10
33474	1/4	6.0	3.5	7.0	.18	10
33477	5/16	6.0	3.5	7.0	.25	10
33480	3/8	6.0	4.1	7.0	.39	10

Item No.	mm	mm	mm	mm	Inch	lbs.	pkg.
33401	2.0	100	80	126	4.9	.05	10
33436	2.0	200	80	226	8.9	.05	10
33402	2.5	100	80	126	4.9	.05	10
33437	2.5	200	80	226	8.9	.08	10
33403	3.0	100	80	126	4.9	.05	10
33404	3.0	150	80	176	6.9	.08	10
33405	3.0	200	80	226	8.9	.09	10
33435	3.0	350	100	382	15.0	.22	10
33406	4.0	100	80	126	4.9	.07	10
33407	4.0	150	80	176	6.9	.10	10
33408	4.0	200	80	226	8.9	.09	10
33438	4.0	350	100	382	15.0	.26	10
33409	5.0	100	100	132	5.2	.13	10
33410	5.0	150	100	182	7.1	.17	10
33411	5.0	200	100	232	9.1	.16	10
33412	5.0	350	100	382	15.0	.26	10
33413	5.0	450	120	488	19.1	.53	10
33414	6.0	100	100	132	5.2	.14	10
33415	6.0	150	100	182	7.1	.18	10
33416	6.0	200	100	232	9.1	.20	10
33417	6.0	350	100	382	15.0	.32	10
33419	7.0	200	100	232	9.1	.22	10
33421	8.0	100	100	132	5.2	.20	10
33423	8.0	200	100	232	9.1	.29	10
33434	8.0	350	100	372	14.6	.48	10
33425	10.0	100	120	138	5.4	.34	10
33427	10.0	200	120	238	9.3	.49	10
33429	12.0	200	120	238	9.3	.58	10



33492 10 Piece Hex Driver T-handle Set, Inch Sizes

Item No.	Inch	Inch	Inch	Inch	lbs.
33453	3/32	6.0	33468	3/16	6.0
33456	7/64	6.0	33471	7/32	6.0
33459	1/8	6.0	33474	1/4	6.0
33462	9/64	6.0	33477	5/16	6.0
33465	5/32	6.0	33480	3/8	6.0



33493 8 Piece Hex Driver T-handle Set, Metric Sizes

Item No.	mm	mm	mm	mm	lbs.
33401	2.0	100	33409	5.0	100
33402	2.5	100	33416	6.0	200
33403	3.0	100	33423	8.0	200
33406	4.0	100	33427	10.0	200



33484 8 Pc. Hex Driver T-handle Set, Inch Sizes - In metal stand

Item No.	Inch	Inch	Inch	Inch	lbs.
33459	1/8	6.0	33471	7/32	6.0
33462	9/64	6.0	33474	1/4	6.0
33465	5/32	6.0	33477	5/16	6.0
33468	3/16	6.0	33480	3/8	6.0

33488 8 Pc. Hex Driver T-handle Set, Metric Sizes - In metal stand

Item No.	mm	mm	mm	mm	lbs.
33401	2.0	100	33410	5.0	150
33402	2.5	100	33415	6.0	150
33403	3.0	100	33423	8.0	200
33406	4.0	100	33427	10.0	200

Wiha MagicRing SoftFinish® Hex Drivers

Screw Holding Hex Tools



367 MagicRing Ball End Hex-Driver Inch, With Wiha-SoftFinish®

Handle Hex blade, high alloy CVM steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Inch	Inch	mm	mm	lbs.	pkg.
36710*	.050	3.1	80	179	.06	10
36713*	1/16	3.1	80	204	.06	10
36716*	5/64	3.9	100	204	.07	10
36719*	3/32	3.9	100	204	.07	10
36723*	7/64	3.9	100	211	.07	10

With MagicRing

36726	1/8	3.9	100	243	.12	10
36728	9/64	3.9	100	243	.12	10
36732	5/32	5.0	125	271	.12	10
36734	3/16	6.0	150	271	.16	10
36736	7/32	6.0	150	271	.23	10
36738	1/4	6.0	150	271	.25	10
36742	5/16	8.0	200	271	.37	10
36744	3/8	8.0	200	271	.54	10

* Standard Ball - No Ring



36793 8 Piece MagicRing Inch Ball End Screwdriver Set

Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item							
No.		Inch	Inch		Inch	Inch	lbs.
36793	36726	1/8	4.0	36736	7/32	6.0	2.25
	36728	9/64	4.0	36738	1/4	6.0	
	36732	5/32	5.0	36742	5/16	8.0	
	36734	3/16	6.0	36744	3/8	8.0	

Don't Drop That Screw!
Save Valuable Time!
Improve Productivity!
Make The Job Easy!




36791 13 Piece MagicRing Inch Ball End Screwdriver Set

Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item							
No.	Inch	Inch		Inch	Inch		lbs.
36791	36710*	.050	3.0	36732	5/32	5.0	2.58
	36713*	1/16	3.0	36734	3/16	6.0	
	36716*	5/64	4.0	36736	7/32	6.0	
	36719*	3/32	4.0	36738	1/4	6.0	
	36723*	7/64	4.0	36742	5/16	8.0	
	36726	1/8	4.0	36744	3/8	8.0	
	36728	9/64	4.0				

* Standard Ball - No Ring

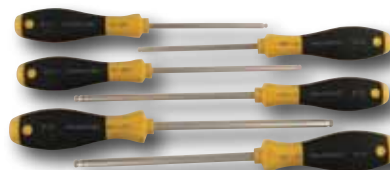

36794 6 Piece MagicRing Inch Ball End Screwdriver Set

Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item							
No.		Inch	Inch		Inch	Inch	lbs.
36794	36726	1/8	4.0	36734	3/16	6.0	1.34
	36728	9/64	4.0	36736	7/32	6.0	
	36732	5/32	5.0	36738	1/4	6.0	

Wiha MagicRing SoftFinish® Hex Drivers

Screw Holding Hex Tools



Don't Drop That Screw!
Save Valuable Time!
Improve Productivity!
Make The Job Easy!



367 MagicRing Ball End Hex Driver **Metric**, With Wiha-SoftFinish®

Handle Hex blade, high alloy CVM steel, hardened, hard chromed.

Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	mm	mm	mm	lbs.	pkg.
36715*	1.5	75	179	.06	10
36720*	2.0	100	204	.07	10
36725*	2.5	100	204	.07	10
With MagicRing					
36730	3.0	100	204	.07	10
36740	4.0	125	211	.12	10
36750	5.0	150	243	.16	10
36760	6.0	150	243	.23	10
36780	8.0	200	268	.37	10
36786	10.0	200	271	.54	10

* Standard Ball - No Ring

Hardened spring steel retaining ring holds screws on

Hard chrome super durable corrosion resistant finish

Precision machined for exact fit

Made from Wiha exclusive CVM hardened tool steel

36790 9 Piece MagicRing **Metric** Ball End Hex Screwdriver Set

Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item		 		 			
No.		mm	mm	mm	mm	lbs.	
36790	36715*	1.5	75	36750	5.0	150	2.06
	36720*	2.0	100	36760	6.0	150	
	36725*	2.5	100	36780	8.0	200	
	36730	3.0	100	36786	10.0	200	
	36740	4.0	125				

* Standard Ball - No Ring





36792 6 Piece MagicRing **Metric** Ball End Hex Screwdriver Set

Hex blade chrome-vanadium-molybdenum steel, hardened, hard chromed. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item		 		 			
No.		mm	mm		mm	lbs.	
36792	36730	3.0	100	36760	6.0	150	1.86
	36740	4.0	125	36780	8.0	200	
	36750	5.0	150	36786	10.0	200	

 Wiha Ball End 3K Series Drivers & Sets

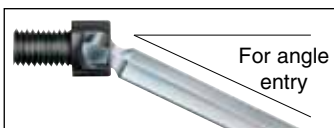


Inch / Soft Grip

467 Ball End Hex Inch Drivers, With 3K Ergo Soft Grip Handles

Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.

Item No.	Inch	Inch	Inch	lbs.	pkg.
46702	.050	2.9	6.3	.07	10
46704	1/16	2.9	6.3	.07	10
46706	5/64	3.9	7.3	.07	10
46708	3/32	3.9	7.3	.07	10
46710	7/64	3.9	7.3	.07	10
46712	1/8	3.9	7.7	.09	10
46714	9/64	3.9	7.7	.10	10
46716	5/32	3.9	7.7	.11	10
46718	3/16	3.9	7.7	.12	10
46722	7/32	5.9	10.0	.19	10
46724	1/4	5.9	10.0	.22	10
46726	5/16	7.9	12.0	.34	10
46728	3/8	7.9	12.5	.48	10

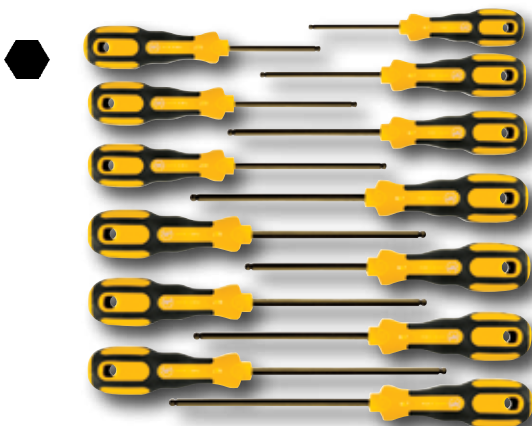


46797 13 Piece 3K Ergo Inch Ball End Hex Screwdriver Set

Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.

Item No.	Inch	Inch	Inch	Inch	lbs.
46797	46702	.050	2.9	46716	5/32 3.9
	46704	1/16	2.9	46718	3/16 2.9
	46706	5/64	3.9	46722	7/32 5.9
	46708	3/32	3.9	46724	1/4 5.9
	46710	7/64	3.9	46726	5/16 7.9
	46712	1/8	3.9	46728	3/8 7.9
	46714	9/64	3.9		

- Soft panel grip
- Convenient hang hole
- Hardened CVM tool steel
- Exact fit precision machined tips
- Fast angle entry

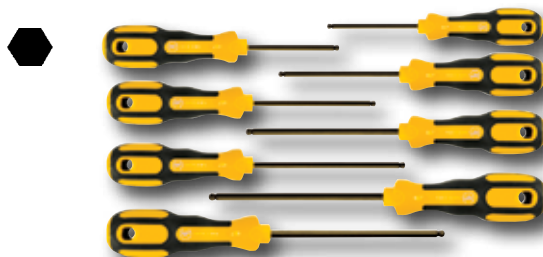

46793 8 Piece 3K Ergo Inch Ball End Hex Screwdriver Set

Item No.	Inch	Inch	Inch	Inch	lbs.
46793	46702	.050	2.9	46710	7/64 3.9
	46704	1/16	2.9	46712	1/8 3.9
	46706	5/64	3.9	46714	9/64 3.9
	46708	3/32	3.9	46716	5/32 3.9




46794 6 Piece 3K Ergo Inch Ball End Hex Screwdriver set

Item No.	Inch	Inch	Inch	Inch	lbs.
46794	46712	1/8	3.9	46718	3/16 3.9
	46714	9/64	3.9	46722	7/32 5.9
	46716	5/32	3.9	46724	1/4 5.9

Yellow = Inch
Red = Metric

Wiha Ball End 3K Series Drivers & Sets

- Soft panel grip
- Convenient hang hole
- Hardened CVM tool steel
- Exact fit precision machined tips
- Fast angle entry

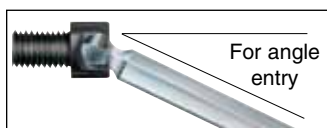

467 Ball End Hex Metric Screwdriver, With Wiha-3K Ergo Handle

Blades of CVM special steel, hardened, black finish. Molded on Wiha-3K Ergo soft grip handles.

Item No.	mm	mm	mm	lbs.	pkg.
46715	1.5	75	161	.07	10
46720	2.0	100	186	.07	10
46725	2.5	100	186	.07	10
46730	3.0	100	186	.07	10
46740	4.0	100	197	.11	10
46750	5.0	100	197	.13	10
46760	6.0	150	257	.21	10
46780	8.0	200	307	.34	10
46786	10.0	200	319	.52	10



46796 7 Piece Metric Ball End Hex Screwdriver Set

Blades of CVM special steel, hardened, black finish.

Molded on Wiha-3k Ergo soft grip handles.

Included on Winlink Large Cock Grip Hardware:							
Item							
No.		mm	mm		mm	mm	lbs.
46796	46715	1.5	75	46740	4.0	100	1.15
	46720	2.0	100	46750	5.0	100	
	46725	2.5	100	46760	6.0	150	
	46730	3.0	100				



46799 9 Piece Metric Ball End Hex Screwdriver Set

Blades of CVM special steel, hardened, black finish.

Molded on Wiha-3k Ergo soft grip handles.

Item			Item			Item
No.	mm	mm	mm	mm	lbs.	
46799	46715	1.5 75	46750	5.0 100	1.93	
	46720	2.0 100	46760	6.0 150		
	46725	2.5 100	46780	8.0 200		
	46730	3.0 100	46786	10.0 200		
	46740	4.0 100				

Yellow = Inch

Red = Metric

Wiha PocketStar Fold-Ups



Push button key release

36997 9 Piece MagicRing Inch PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .46
36997 PocketStar

Inch: 5/64", 3/32", 7/64", 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

* Standard Ball - No Ring



Push button key release

36996 7 Piece MagicRing Metric PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .50
36996 PocketStar

Metric: 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0mm

* Standard Ball - No Ring



Push button key release

66997 2 Pack MagicRing PocketStar Fold Outs Inch & Metric
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .98
66997 Fold Outs Inch/Metric Includes:

36996 - 2.0*, 2.5*, 3.0, 4.0, 5.0, 6.0, 8.0mm

36997 - 5/64", 3/32", 7/64", 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

* Standard Ball - No Ring



#35195

#35196

35195 7 Piece Metric Hex PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .51
35195 PocketStar

Metric: 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm

35196 7 Piece Metric Hex PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .31
35196 PocketStar

Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0mm



Push button key release

35197 9 Piece Inch Hex PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .47
35197 PocketStar

Inch: 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"



Push button key release

35198 6 Pc. Slotted, Phillips & Hex Metric PocketStar Fold Outs
High alloy CVM steel, hardened, molded ergonomic handle.

Item No.  lbs. .35
35198 PocketStar

Slotted: 5.5mm **Phillips:** #2

Metric: 3.0, 4.0, 5.0, 6.0mm

Nickel-Plated Long Arm Hex L-keys



Nickel-Plated

- Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

352 Metric L-key Hex, Long Arm high alloy CVM steel, hardened, nickel plated. Precision machined, burr free chamfered ends.

Item No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
35201	1.5	89	3.5	14	.6	.01	10
35202	2.0	99	3.9	16	.6	.01	10
35204	2.5	110	4.3	18	.7	.02	10
35206	3.0	124	4.9	20	.8	.02	10
35208	4.0	138	5.4	25	1.0	.04	10
35210	5.0	158	6.2	28	1.1	.07	10
35211	6.0	178	7.0	32	1.3	.12	10
35212	7.0	187	7.4	34	1.3	.17	10
35214	8.0	196	7.7	36	1.4	.23	10
35217	10.0	219	8.6	40	1.6	.40	10
35219	12.0	245	9.6	45	1.8	.77	1
35221	14.0	277	10.9	56	2.2	1.12	1
35223	17.0	316	12.4	63	2.5	1.80	1
35227	19.0	355	14.0	70	2.8	2.46	1



Nickel-Plated

- Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

352 Inch L-key Hex, Long Arm

Item No.	Inch	mm	Inch	lbs.	pkg.
35231	.050	75	3.0	.01	10
35233	1/16	78	3.1	.01	10
35235	5/64	82	3.2	.01	10
35237	3/32	85	3.3	.01	10
35239	7/64	92	3.6	.01	10
35241	1/8	95	3.7	.02	10
35243	9/64	100	3.9	.03	10
35251	5/32	105	4.1	.03	10
35252	3/16	113	4.4	.05	10
35253	7/32	122	4.8	.07	10
35254	1/4	135	5.3	.10	10
35255	5/16	152	6.0	.18	10
35256	3/8	173	6.8	.30	10
35257	1/2	209	8.2	.77	1
35258	9/16	230	9.1	1.04	1
35259	5/8	245	9.6	1.27	1
35261	3/4	286	11.3	2.01	1



35297 9 Piece Metric Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

Item No.	lbs.	pkg.
35297	1.00	1



35295 13 Piece Inch Hex L-key Set, In Plastic Holder

Equipped with .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

Item No.	lbs.	pkg.
35295	.90	1

Black Finish Long Arm Hex L-keys



352 Metric L-key Hex **Metric**, Long Arm, high alloy CVM steel, hardened, black finish. Precision machined, burr free chamfered ends.

Item No.							
No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
35200	0.7	66	2.6	5	.2	.01	10
35203	0.9	68	2.7	8	.3	.01	10
35205	1.3	72	2.8	12	.5	.01	10
35215	1.5	76	3.5	14	.6	.01	10
35220	2.0	99	3.9	16	.6	.01	10
35225	2.5	110	4.3	18	.7	.02	10
35230	3.0	124	4.9	20	.8	.02	10
35240	4.0	138	5.4	25	1.0	.04	10
35250	5.0	158	6.2	28	1.1	.07	10
35260	6.0	178	7.0	32	1.3	.12	10
35270	7.0	187	7.4	34	1.3	.18	10
35280	8.0	196	7.7	36	1.4	.24	10
35282	10.0	219	8.6	40	1.6	.40	10
35284	12.0	245	9.6	45	1.8	.77	1
35285	14.0	277	10.9	56	2.2	1.13	1
35286	17.0	316	12.4	63	2.5	1.80	1
35288	19.0	355	14.0	70	2.8	2.45	1



352 Inch L-key Hex, Long Arm

Item No.					
No.	Inch	mm	Inch	lbs.	pkg.
35200	.028	67	2.6	.01	10
35203	.035	69	2.7	.01	10
35213	.050	75	3.0	.01	10
35216	1/16	78	3.1	.01	10
35218	5/64	82	3.2	.01	10
35222	3/32	85	3.3	.01	10
35224	7/64	92	3.6	.02	10
35226	1/8	95	3.7	.02	10
35228	9/64	100	3.9	.03	10
35232	5/32	105	4.1	.04	10
35234	3/16	113	4.4	.05	10
35236	7/32	122	4.8	.07	10
35238	1/4	135	5.3	.10	10
35242	5/16	152	6.0	.18	10
35244	3/8	173	6.8	.30	10
35245	1/2	209	8.2	.75	1
35246	9/16	230	9.1	.99	1
35247	5/8	245	9.6	1.26	1
35248	3/4	286	11.3	2.02	1
35249	1"	359	14.1	4.38	1



35290 9 Piece **Metric** Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

Item No.		
No.	lbs.	pkg.
35290	.97	1



35291 13 Piece **Inch** Hex L-key Set, In Plastic Holder

Equipped with .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

Item No.		
No.	lbs.	pkg.
35291	.98	1

Short Arm Hex L-keys Nickel Finish

- Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

Nickel-Plated

351 Metric L-key Hex **Metric**, Short Arm high alloy CVM steel, hardened, nickel plated. Precision machined, burr free chamfered ends.

Item No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
35104	1.5	45	1.8	14	.6	.01	10
35108	2.0	49	1.9	16	.6	.01	10
35112	2.5	55	2.2	18	.7	.01	10
35116	3.0	61	2.4	20	.8	.02	10
35120	4.0	68	2.7	25	1.0	.03	10
35124	5.0	78	3.1	28	1.1	.04	10
35128	6.0	88	3.5	32	1.3	.07	10
35132	7.0	92	3.6	34	1.3	.10	10
35136	8.0	97	3.8	36	1.4	.13	10
35140	9.0	103	4.1	38	1.5	.18	10
35144	10.0	109	4.3	40	1.6	.23	10
35145	12.0	122	4.8	45	1.8	.40	1
35175	14.0	137	5.4	56	2.2	.61	1
35177	17.0	156	6.1	63	2.5	1.02	1
35179	19.0	176	6.9	70	2.8	1.40	1

- Ideal for use in clean rooms & other environments where non-oxidizing surfaces are specified or required.

Nickel-Plated

351 Inch L-key Hex, Short Arm Nickel-plated

Item No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.
35143	.050	40	1.6	10	.39	.01	10
35146	1/16	46	1.8	14	.55	.01	10
35147	5/64	50	2.0	16	.63	.01	10
35150	3/32	52	2.1	19	.75	.01	10
35152	7/64	54	2.1	19	.75	.01	10
35153	1/8	58	2.3	21	.83	.02	10
35155	9/64	62	2.4	23	.91	.02	10
35156	5/32	68	2.7	25	.99	.02	10
35159	3/16	70	2.8	26	1.0	.04	10
35162	7/32	77	3.1	29	1.2	.05	10
35165	1/4	88	3.5	31	1.2	.08	10
35168	5/16	98	3.9	36	1.4	.13	10
35171	3/8	107	4.2	38	1.5	.20	10
35174	1/2	133	5.2	44	1.7	.46	1
35176	9/16	158	6.2	64	2.5	.64	1
35178	5/8	175	6.9	71	2.8	.85	1
35180	3/4	198	7.8	89	3.5	1.40	1



35191 9 Piece Metric Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

lbs. .59 pkg. 1



35193 6 Piece Metric Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0mm

lbs. .20 pkg. 1



35192 8 Piece Inch Hex L-key Set, In Plastic Holder

Equipped with 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16"

lbs. .41 pkg. 1



35194 13 Piece Inch Hex L-key Set, In Plastic Holder

Equipped with .050 - 3/8"

lbs. .72 pkg. 1

Short Arm Hex L-keys Black Finish


 Black Finish

353 Metric L-key Hex Metric, Short Arm high alloy CVM steel, hardened, black finish. Precision machined, burr free chamfered ends.

Item No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
35301	0.7	31	1.2	-	-	.01	10
35302	0.9	31	1.2	-	-	.01	10
35303	1.3	40	1.6	12	.5	.01	10
35304	1.5	45	1.8	14	.6	.01	10
35305	2.0	49	1.9	16	.6	.01	10
35306	2.5	55	2.2	18	.7	.01	10
35307	3.0	61	2.4	20	.8	.02	10
35308	4.0	68	2.7	25	1.0	.03	10
35309	5.0	78	3.1	28	1.1	.04	10
35310	6.0	88	3.5	32	1.3	.07	10
35311	7.0	92	3.6	34	1.3	.10	10
35312	8.0	97	3.8	36	1.4	.13	10
35313	9.0	103	4.1	38	1.5	.17	10
35314	10.0	109	4.3	40	1.6	.23	10
35316	11.0	115	4.5	42	1.7	.29	10
35317	12.0	122	4.8	45	1.8	.40	1
35318	14.0	137	5.4	56	2.2	.61	1
35319	17.0	156	6.1	63	2.5	1.03	1
35320	19.0	176	6.9	70	2.8	1.40	1
35321	22.0	195	7.7	80	3.1	2.17	1


 Black Finish

353 Inch L-key Hex Inch, Short Arm black finish


Item No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.
35301	.028	31	1.2	-	-	.01	10
35302	.035	31	1.2	-	-	.01	10
35330	.050	40	1.6	10	.4	.01	10
35331	1/16	46	1.8	14	.6	.01	10
35332	5/64	50	2.0	16	.6	.01	10
35333	3/32	52	2.1	19	.8	.01	10
35334	7/64	54	2.1	19	.8	.01	10
35335	1/8	58	2.3	21	.8	.02	10
35336	9/64	62	2.4	23	.9	.02	10
35337	5/32	68	2.7	25	1.0	.02	10
35338	3/16	70	2.8	26	1.0	.05	10
35339	7/32	77	3.1	29	1.2	.07	10
35340	1/4	88	3.5	31	1.2	.07	10
35341	5/16	98	3.9	36	1.4	.13	10
35342	3/8	107	4.2	38	1.5	.20	10
35343	1/2	133	5.2	44	1.7	.49	1
35345	9/16	158	6.2	64	2.5	.66	1
35346	5/8	175	6.9	71	2.8	.86	1
35347	3/4	198	7.8	89	3.5	1.45	1
35348	1"	220	8.7	91	3.6	3.14	1



35390 9 Piece Metric Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm


 lbs. .59  pkg. 1

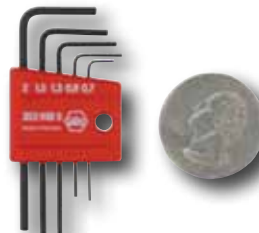

35392 5 Piece Mini Metric Hex L-key Set, In Plastic Holder

Equipped with 0.7, 0.9, 1.3, 1.5, 2.0mm

 lbs. .03  pkg. 1

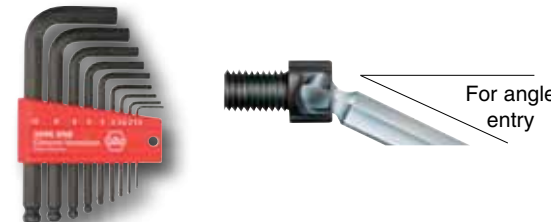

36989 9 Piece Short Arm Metric Ball End Hex L-key Set, In Plastic Holder

Equipped with 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0mm

 lbs. .59  pkg. 1



35391 13 Piece Inch Hex L-key Set, In Plastic Holder

Equipped with .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"

 lbs. .64  pkg. 1



35393 5 Piece Mini Inch Hex L-key Set, In Plastic Holder

Equipped with .028, .035, .050, 1/16, 5/64"

 lbs. .03  pkg. 1

Wiha Insulated T-handles

Insulation Test Standards:

Insulation according to EN/IEC 60900, ASTM F-1505-01, VDE 0682/part 201, DIN 7437, NFPA70E, CSA

Responds to OSHA's use specification 29 CFR1910


Insulation

Molded directly onto blade for permanent bonding

Each tool individually tested to 10,000 volts and certified to 1000 Volt ac or 1500 Volt dc

Blade CVM tool steel, hardened to average 58/60RC

1000V

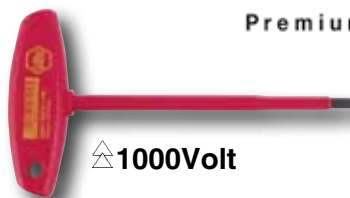

1000Volt

334 **Metric** T-handle, With Wiha-Molded Handle. Insulation According to ASTM, VDE, EN/IEC, NFPA70E and CSA, **1000 Volt. Individually Tested.**

Item	Hex	mm	Inch	mm	Inch	lbs.	pkg.
33441	4.0	150	5.9	176	6.9	.09	10
33443	5.0	150	5.9	176	6.9	.15	10
33445	6.0	150	5.9	176	6.9	.18	10
33447	8.0	150	5.9	176	6.9	.26	10
33449	10.0	150	5.9	176	6.9	.46	10



1000Volt

33478 5 Piece Hex **Metric** T-handle Set

Item	Hex	lbs.
No.	Hex Metric :	lbs.
33478	4.0, 5.0, 6.0, 8.0, 10.0mm	1.20


Wiha Insulated Hex Metric Screwdrivers



1000Volt

323 Hex **Metric** Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-01, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E & CSA, **1000 Volt. Individually Tested.** Blade high alloy CVM steel, hardened, black finish. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component, cushion grip.


Item	Hex	mm	Inch	mm	Inch	lbs.	pkg.
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
32302	2.5	75	3.0	179	7.0	.06	10
32303	3.0	75	3.0	179	7.0	.08	10
32304	4.0	75	3.0	186	7.3	.12	10
32305	5.0	75	3.0	186	7.3	.15	10
32306	6.0	100	3.9	218	8.6	.21	10
32308	8.0	100	3.9	218	8.6	.34	10

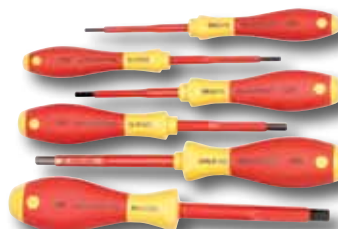

1000Volt

32366 6 Piece Insulated Hex **Metric** Screwdriver Set

Item No.	Hex	lbs.
No. 32366	Hex Metric : 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm	1.06

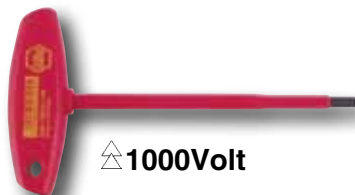

1000Volt

334 Inch T-handle, With Wiha-Molded Handle Insulation According to ASTM F-1505-01, New VDE Specification 0682/part 201, EN/IEC 60900, NFPA70E and CSA, **1000 Volt. Individually Tested.**

Blade CVM steel, hardened. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component.

Item	Hex	Inch	Inch	mm	lbs.	pkg.
No.	Inch	Inch	Inch	mm	lbs.	pkg.
33481	5/32	5.9	6.9	176	.09	10
33482	3/16	5.9	6.9	176	.15	10
33483	7/32	5.9	6.9	176	.19	10
33485	1/4	6.9	6.9	176	.20	10
33486	5/16	6.9	6.9	176	.26	10
33487	3/8	6.9	6.9	176	.44	10



1000Volt

33490 6 Piece Hex Inch T-handle Set

Item	Hex	lbs.
No.	Hex Inch:	lbs.
33490	5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1.66

Wiha Insulated Hex L-keys

Insulation Test Standards:

Insulation according to ASTM,
F-1505-01, EN/IEC 60900
and CSA



Insulation

Applied directly
onto blade for
permanent
bonding

Each tool individually
tested to 10,000 volts
and certified to 1000
Volt ac or 1500 Volt dc

1000V



#13691



#13690

1000Volt

13690 8 Piece Insulated Hex L-key Set - Inch

Item No.			
13690	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2"	lbs. 2.17	

13691 7 Piece Insulated Hex L-key Set - Metric

Item No.			
13691	3.0, 4.0, 5.0, 6.0, 8.0, 10.0, 12.0mm	lbs. 2.07	



1000Volt

136 Inch Insulated Hex L-keys, With Insulated Handle

Insulation According to IEC 60900 specification, up to 1000 Volt.
Individually Tested. Blade chrome-vanadium steel, hardened.

Item No.	ØMM	OAL	OAL		
No.	Inch	mm	Inch	lbs.	pkg.
13670	1/16	79	3.1	.05	1
13671	5/64	84	3.3	.05	1
13672	3/32	89	3.5	.05	1
13673	7/64	94	3.7	.06	1
13663	1/8	104	4.1	.06	1
13665	5/32	104	4.1	.06	1
13666	3/16	134	5.3	.10	1
13667	7/32	134	5.3	.12	1
13668	1/4	134	5.3	.16	1
13669	5/16	144	5.7	.24	1
13662	3/8	234	9.2	.51	1
13664	1/2	234	9.2	.77	1



1000Volt

136 Metric Insulated Hex L-keys, With Insulated Handle

Insulation According to IEC 60900 specification, up to 1000 Volt.
Individually Tested. Blade chrome-vanadium steel, hardened.

Item No.	ØMM	OAL	OAL		
No.	mm	mm	Inch	lbs.	pkg.
13650	1.5	100	3.9	.09	1
13651	2.0	105	4.1	.09	1
13652	2.5	115	4.5	.09	1
13653	3.0	130	5.1	.10	1
13654	4.0	120	4.7	.10	1
13655	5.0	140	5.5	.10	1
13656	6.0	140	5.5	.13	1
13658	8.0	150	5.9	.24	1
13659	10.0	220	8.7	.51	1
13657	12.0	260	10.2	.77	1



1000Volt

13693 10 Piece Insulated Hex L-key Set - Metric

Item No.			
13693	1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0, 10.0, 12.0mm	lbs. 2.26	

13694 12 Piece Insulated Hex L-key Set - Inch

Item No.			
13694	1/16, 5/64, 3/32, 7/64, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2"	lbs. 2.40	

Wiha Insulated 3/8" Bit Sockets & Set



1000Volt

318 Insulated 3/8" Drive Sockets - Insulation according to EN/IEC 60900, DIN 7448 specification, up to 1000 Volt.

Individually Tested. Chrome-vanadium steel, forged, oil-hardened.

Item No.	Inch	OAL	lbs.	pkg.
31805	3/16	3.1"	.13	1
31807	7/32	3.1"	.14	1
31809	1/4	3.1"	.14	1
31811	5/16	3.1"	.16	1
31813	3/8	3.1"	.18	1
31815	7/16	3.1"	.20	1
31817	1/2	3.1"	.22	1

*Sockets must be used with insulated ratchets & extensions



1000Volt

31890 7 Piece Insulated 3/8" Drive Socket Set - Inch

CV steel, forged, oil-hardened sockets. Insulated to EN/IEC 60900.

Item No.	31890	Set includes the following:
	lbs. 1.7	3/16, 7/32, 1/4, 5/16, 3/8, 7/16, 1/2"

Wiha Drive-Loc VI Handles



Allows adjustable blade lengths 1.7" to 4.7" in 1/8" increments

28488 Drive-Loc VI Cushion Grip Handle

Wiha-SoftFinish® impact resistant, with roll off protection.

Advantages:

Ergonomic cushion grip, Drive-Loc mechanism guarantees a secure hold and rapid blade exchange.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28488	6.0	115	4.5	36.0	1.41	.26



Allows adjustable blade lengths 1.7" to 4.7" in 1/8" increments

28486 ESD Safe Drive-Loc VI Cushion Grip Handle

Wiha-SoftFinish® impact resistant, with roll off protection.

Advantages:

Ergonomic cushion grip, Drive-Loc mechanism guarantees a secure hold and rapid blade exchange. Static Dissipative.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28486	6.0	115	4.5	36.0	1.41	.21



Allows adjustable blade lengths 1.7" to 4.7" in 1/8" increments

28487 Drive-Loc VI MicroFinish Non-Slip Grip Handle

Wiha-MicroFinish handle, won't peel, crack or deteriorate when exposed to petroleum solvents. Ideal for Hex, TORX® & Nut Drivers.


Advantages:

Ergonomic handle shape for maximum comfort, Drive-Loc mechanism guarantees a secure hold and rapid blade exchange.

Item						
No.	mm	mm	Inch	mm	Inch	lbs.
28487	6.0	115	4.5	36.0	1.41	.20



Wiha Drive-Loc VI Blades

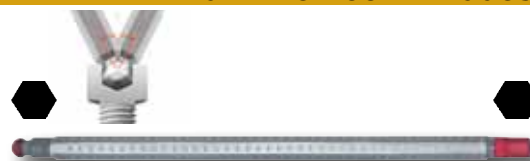

281 Ball End Hex & Hex Metric Drive-Loc VI Interchangeable

Blade High alloy CVM steel, through hardened, hard chrome finish. Ball end enables the user to work at angles up to 25°. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + mm		lbs.	pkg.
28116	2.5	2.5	.10	1
28117	3	3	.10	1
28118	4	4	.10	1
28119	5	5	.10	1
28120	6	6	.10	1



281 Hex Metric Drive-Loc VI Interchangeable Blade

High alloy CVM steel, through hardened, hard chrome finish. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	mm + mm		lbs.	pkg.
28149	2.0	2.5	.09	1
28150	3.0	4.0	.10	1
28151	5.0	6.0	.10	1



281 Hex Inch Drive-Loc VI Interchangeable Blade

High alloy CVM steel, through hardened, hard chrome finish. Over all blade length 150mm/5.9". Blades fit all Drive-Loc VI handles.

Item				
No.	Inch +	Inch	lbs.	pkg.
28122	3/32	7/64	.10	1
28123	1/8	9/64	.10	1
28124	5/32	3/16	.10	1



28192 7 Piece Hex Inch & Metric Drive-Loc VI Blade Set

Blade CVM steel, hardened, hard chromed. In storage pouch

Item	
No. 28192	lbs.
Inch: 3/32 x 7/64, 1/8 x 9/64, 5/32 x 3/16	.74
Metric: 2.0 x 2.5, 3.0 x 4.0, 5.0 x 6.0	
Wiha SoftFinish® Cushion Grip Handle	

TorqueControl Tools



+/-6% accuracy
tolerance
Certificate of
calibration



+/-6% accuracy tolerance
Certificate of calibration

285 TorqueFix, With Wiha-SoftFinish® Handle

Fixed Torque value pre-set. Tested in accordance with EN ISO 6798, BS EN 26789, ASME B107.14M, tolerance +/- 6%. Audible and perceptible click when pre-set torque has been attained.

Automatically resets for next torque cycle; 50% greater reverse torque.

Item No.	Pre-Sets						
	oz.	lbs.	Nm	mm	Inch	lbs.	pkg.
28503	80	5	0.56	112	4.4	.16	1
28505	120	7.5	0.84	112	4.4	.15	1
28507	160	10	1.12	119	4.7	.28	1
28509	200	12.5	1.41	119	4.7	.27	1
28511	240	15	1.69	119	4.7	.27	1
28513	320	20	2.25	119	4.7	.28	1
28515	400	25	2.82	126	4.9	.37	1
28517	480	30	3.39	126	4.9	.37	1
28518	560	35	3.95	126	4.9	.37	1
28519	640	40	4.52	126	4.9	.37	1
28521	800	50	5.65	132	5.2	.52	1
28523	960	60	6.78	132	5.2	.52	1
28525	1120	70	7.91	132	5.2	.52	1

Direct Reading Scale



+/-6% accuracy
tolerance
Certificate of
calibration

285 Adjustable TorqueVario With Direct Reading Scale

EN ISO 6798, BS EN 26789, ASME B107.14M. Ergonomic molded multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible and perceptible click when the torque setting has been attained, automatically resets for next torque cycle.

Item No.	Range				
	Inch	lbs.	Increments	mm	lbs.
28501*	15 - 80(in/oz)		2.5 Inch oz	122 - 127	.22
28502	5 - 10		.5 Inch lbs	122 - 127	.41
28504	7.5 - 20		.5 Inch lbs	126 - 131	.50
28506	10 - 50		2 Inch lbs	133 - 138	.59
28508	20 - 70		2 Inch lbs	137 - 142	.74

Above includes Micro Bit Holder 28583

See 4mm Micro Bits on Page 30

* +/- 10% (This unit only)

* (1 Nm = 8.8507)

285 Adjustable TorqueVario-S Handle - In Newton Meter Scale

EN ISO 6798, BS EN 26789, ASME B107.14M. Ergonomic molded multi-component handle, light and compact. Handle sizes proportioned to optimize torque range. Audible and perceptible click when the torque setting has been attained, automatically resets for next torque cycle.

Item No.	Newton Meter Scale	Increments			
			mm	lbs.	pkg.
28550*	0.1 - 0.6Nm	.02 Nm	122 - 127	.35	1
28551	0.4 - 1.0Nm	.05 Nm	122 - 127	.35	1
28552	0.8 - 2.0Nm	.05 Nm	126 - 131	.45	1
28553	1.0 - 5.0Nm	.20 Nm	133 - 138	.55	1
28554	2.0 - 8.0Nm	.25 Nm	137 - 142	.70	1

* +/- 10% (This unit only)

* (1 Nm 8.8507)



285 Hex Metric Interchangeable Blades For TorqueFix &

TorqueVario Hex tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.				Max. Torque	
	mm	mm	lbs.	Nm	pkg.
28545	1.5	175	.07	0.9	1
28546	2.0	175	.07	1.8	1
28547	2.5	175	.07	3.8	1
28548	3.0	175	.07	8.0	1
28549	4.0	175	.07	8.0	1



285 Hex Inch Interchangeable Blades For TorqueFix &

TorqueVario Hex tip blades on narrow 5/32 Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.				Max. Torque	
	Inch	mm	lbs.	Nm	pkg.
28555	.050	175	.07	.4	1
28556	1/16	175	.07	.9	1
28557	5/64	175	.07	1.8	1
28558	3/32	175	.07	1.8	1
28559	7/64	175	.07	3.8	1
28560	1/8	175	.07	3.8	1
28587	9/64	175	.07	8.0	1
28588	5/32	175	.07	8.0	1

T-handle TorqueControl Tools



Includes Calibration
Certificate

289 TorqueFix T-handle

EN ISO 6798, BS EN 26789, ASME B107.14M, +/- 6% Accuracy
Ergonomic multi-component handle, light and compact.
With Certificate of calibration.

Item No.	Torque In-lbs.	Torque Nm	 mm x mm	 lbs.	 pkg.
28931	53.1	6	56 x 120	.81	1
28933	70.8	8	56 x 120	.82	1
28935	88.5	10	56 x 120	.79	1
28937	106.2	12	56 x 120	.79	1
28938	110.6	12.5	56 x 120	.80	1
28939	123.9	14	56 x 120	.80	1

Each TorqueFix T-handle has unique serial number and certificate of calibration



Includes Calibration
Certificate

28940 Adjustable TorqueVario STplus T-handle

EN ISO 6798, BS EN 26789, ASME B107.14M, +/- 6% Accuracy
Ergonomic multi-component handle, light and compact.

Item No.	Torque In-lbs.	Torque Nm	 mm x mm	 lbs.	 pkg.
28940	44.3-123.9	5-14	56 x 120	.81	1

* (1 Nm 8.8507)



289 Hex Metric Interchangeable Blades For TorqueFix T-handle

Hex tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.


Item No.	 mm	 mm	 Inch	 lbs.	 pkg.
28916	3.0	130	5.1	.11	1
28917	4.0	130	5.1	.11	1
28918	5.0	130	5.1	.11	1
28919	6.0	130	5.1	.11	1



289 Hex Inch Interchangeable Blades For TorqueFix T-handle

Hex tip blades on 6mm Hex shafts. High alloy CVM steel, hardened, satin hard chrome finish.

Item No.	 Inch	 mm	 Inch	 lbs.	 pkg.
28920	1/8	130	5.1	.11	1
28921	9/64	130	5.1	.11	1
28922	5/32	130	5.1	.11	1
28923	3/16	130	5.1	.11	1
28924	7/32	130	5.1	.11	1

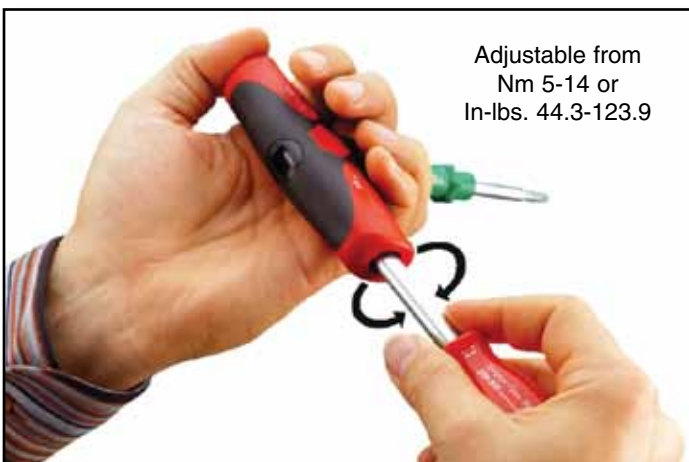

Adjustable from
Nm 5-14 or
In-lbs. 44.3-123.9

Wiha Precision ESD Safe Hex Drivers

Wiha Precision ESD Static Dissipative Screwdrivers meet the requirements for tools used in static sensitive areas.



ESD Standard IEC 61340-5-1

Surface resistance of handles is $10^6 - 10^9$ Ohms

Rotating cap for precise turning & control with fingertip

Molded Precision handle of impact resistant dissipative material

Tapered handle allows rapid rotation

Blade, CVM steel, hardened, hard chrome finish

Tip, precision ground for exact fit, Wiha Chromtop finish



275 Inch Hex Driver, With Precision ESD Safe Dissipative

Handle Blade high alloy chrome-vanadium-molybdenum steel.

Hard chrome finished. Handle manufactured from impact resistant, dissipative material. ESD standard IEC 61340-5-1

Item	Hex	mm	Inch	mm	Inch	lbs.	pkg.
No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.
27505	.028	40	1.6	120	4.7	.02	10
27510	.035	40	1.6	120	4.7	.02	10
27513	.050	40	1.6	120	4.7	.02	10
27537	1/16	50	2.0	145	5.7	.03	10
27539	5/64	50	2.0	145	5.7	.03	10
27541	3/32	60	2.4	170	6.7	.04	10
27543	7/64	60	2.4	170	6.7	.04	10
27545	1/8	60	2.4	170	6.7	.04	10
27547	9/64	60	2.4	170	6.7	.05	10
27549	5/32	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate

275 Metric Hex Metric Driver, With Precision ESD Safe

Dissipative Handle Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished. Handle manufactured from impact resistant, dissipative material. ESD standard IEC 61340-5-1

Item	Hex	mm	Inch	mm	Inch	lbs.	pkg.
No.	mm	mm	Inch	mm	Inch	lbs.	pkg.
27507	.71	40	1.6	120	4.7	.02	10
27509	.89	40	1.6	120	4.7	.02	10
27513	1.27	40	1.6	120	4.7	.03	10
27515	1.5	50	2.0	145	5.7	.03	10
27520	2.0	50	2.0	145	5.7	.04	10
27525	2.5	60	2.4	170	6.7	.05	10
27530	3.0	60	2.4	170	6.7	.05	10
27535	4.0	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate



ESD standard
IEC 61340-5-1

27591 8 Piece Hex Inch Precision Set, ESD Safe Dissipative

Handle Blade CVM steel, hardened, hard chromed. Handle impact resistant, dissipative material. In storage pouch

Item	Hex	Inch	Inch	Hex	Inch	Inch	lbs.
No.		Inch	Inch		Inch	Inch	lbs.
27591	27513	.050	1.6	27543	7/64	2.4	.57
	27537	1/16	2.0	27545	1/8	2.4	
	27539	5/64	2.0	27547	9/64	2.4	
	27541	3/32	2.4	27549	5/32	2.4	



91118 Rugged Polyester Canvas Storage Pouch

Holds 8 Precision Tools up to 170mm in length. Folding pouch. Has security flaps and velcro closer.

Item	Size	lbs.	pkg.
No.	Size	lbs.	pkg.
91118	14 1/2" W x 7 3/4" L	.13	1

Pico Soft Grip Ball End Inch & Metric



264 Ball End Hex Inch Screwdriver, With Precision Soft

PicoFinish Handle Blade high alloy chrome-vanadium-molybdenum tool steel, hardened, hard chrome finish.

Item						
No.	Inch	Inch	mm	Inch	mm	pkg.
26455	1/16	2.0	50	5.9	150	10
26457	5/64	2.0	50	5.9	150	10
26459	3/32	2.0	50	5.9	150	10
26461	7/64	2.4	60	6.3	160	10
26463	1/8	2.4	60	6.3	160	10
26465	9/64	2.4	60	6.3	160	10
26467	5/32	2.4	60	6.3	160	10

*Metric dimensions actual - Inch dimensions approximate



26493 7 Piece Inch Ball End Hex Precision Driver Set, With

Soft PicoFinish Handle Blade high alloy CVM steel, hardened, hard chromed. ChromTop finish on tip for a perfect fit. In storage pouch

Item	No.	Inch	Inch	Inch	Inch	lbs.
26493	26455	1/16	2.0	26463	1/8	2.4
	26457	5/64	2.0	26465	9/64	2.4
	26459	3/32	2.0	26467	5/32	2.4
	26461	7/64	2.4			



264 Ball End Hex Metric Screwdriver, With Precision Soft

PicoFinish Handle. Blade high alloy chrome-vanadium-molybdenum tool steel, hardened, hard chrome finish.

Item							
No.	mm	mm	Inch	mm	Inch	pkg.	
26441	1.27	40	1.6	134	5.3	10	
26443	1.5	50	2.0	150	5.9	10	
26445	2.0	50	2.0	150	5.9	10	
26447	2.5	60	2.4	160	6.3	10	
26449	3.0	60	2.4	160	6.3	10	

*Metric dimensions actual - Inch dimensions approximate

Pico Soft Grip Hex Inch & Metric



263 Hex Inch Screwdriver, With Precision Soft PicoFinish Handle

Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	Inch	mm	Inch	mm	Inch	pkg.
26341	.028(.71)	40	1.6	134	5.3	10
26343	.035(.89)	40	1.6	134	5.3	10
26345	.050(1.27)	40	1.6	134	5.3	10
26349	5/64(2.0)	50	2.0	150	5.9	10
26363	1/16	50	2.0	144	5.7	10
26367	3/32	60	2.4	160	6.3	10
26369	7/64	60	2.4	160	6.3	10
26371	1/8	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate



In storage pouch

26392 8 Piece Hex Inch Precision Driver Set

Item	No.	Inch	Inch	Inch	Inch	lbs.
26392	26341	.028	1.6	26363	1/16	2.0
	26343	.035	1.6	26367	3/32	2.4
	26345	.050	1.6	26369	7/64	2.4
	26349	5/64	2.0	26371	1/8	2.4



263 Hex Metric Driver, With Precision Soft PicoFinish Handle

Blade high alloy CVM tool steel, hardened, hard chrome finish.

Item						
No.	mm	mm	Inch	mm	Inch	pkg.
26341	.71(.028)	40	1.6	134	5.3	10
26343	.89(.035)	40	1.6	134	5.3	10
26345	1.27(.050)	40	1.6	134	5.3	10
26347	1.5	50	2.0	144	5.7	10
26349	2.0(5/64)	50	2.0	150	5.9	10
26351	2.5	60	2.4	160	6.3	10
26353	3.0	60	2.4	160	6.3	10

*Metric dimensions actual - Inch dimensions approximate



In storage pouch

26393 7 Pc. Hex Metric Precision Driver Set

Item	No.	mm	mm	mm	mm	lbs.
26393	26341	.71	40	26349	2.0	50
	26343	.89	40	26351	2.5	60
	26345	1.27	40	26353	3.0	60
	26347	1.5	50			

Wiha Hex Precision Series



263 Metric Metric Hex Driver, With Precision Handle

Metric sizes. Blade high alloy chrome-vanadium-molybdenum steel.

Item								
No.	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26307	.71	.028	40	1.6	120	4.7	.02	10
26309	.89	.035	40	1.6	120	4.7	.02	10
26313	1.27	.050	40	1.6	120	4.7	.02	10
26315	1.5	-	50	2.0	145	5.7	.03	10
26320	2.0	5/64	50	2.0	145	5.7	.03	10
26325	2.5	-	60	2.4	170	6.7	.04	10
26330	3.0	-	60	2.4	170	6.7	.04	10
26340	4.0	-	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate



26390 7 Pc. Precision Hex Driver Set - Metric

Blade high alloy chrome-vanadium-molybdenum steel.

Item			
No.	Inch	Inch	lbs.
26390 26307	.71	1.6	.28
26390 26309	.89	1.6	
26390 26313	1.27	1.6	
26390 26315	1.5	2.0	
26390 26320	2.0	2.0	
26390 26325	2.5	2.4	
26390 26330	3.0	2.4	



263 Inch Inch Hex Driver, With Precision Handle

Inch sizes. Blade high alloy chrome-vanadium-molybdenum steel.

Item								
No.	Inch	mm	mm	Inch	mm	Inch	lbs.	pkg.
26307	.028	.71	40	1.6	120	4.7	.02	10
26309	.035	.89	40	1.6	120	4.7	.02	10
26313	.050	1.27	40	1.6	120	4.7	.02	10
26316	1/16	-	50	2.0	145	5.7	.03	10
26320	5/64	2.0	50	2.0	145	5.7	.03	10
26323	3/32	-	60	2.4	170	6.7	.04	10
26327	7/64	-	60	2.4	170	6.7	.04	10
26331	1/8	-	60	2.4	170	6.7	.04	10
26333	9/64		60	2.4	170	6.7	.05	10
26336	5/32		60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate




26391 8 Pc. Precision Hex Driver Set - Inch

Blade high alloy CVM steel.

Item			
No.	Inch	Inch	lbs.
26391 26307	.028	1.6	.32
26391 26309	.035	1.6	
26391 26313	.050	1.6	
26391 26316	1/16	2.0	
26391 26320	5/64	2.0	
26391 26323	3/32	2.4	
26391 26327	7/64	2.4	
26391 26331	1/8	2.4	

Wiha Ball End Precision Series

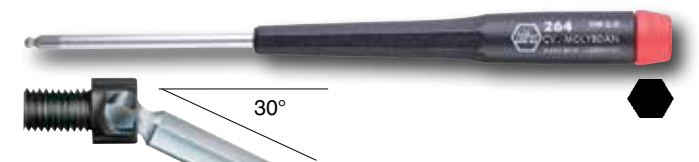

264 Metric Ball End Hex Metric Screwdriver With Precision Handle

Angle entry up to 30°. Blade high alloy CVM steel.

Item								
No.	mm	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26413	1.27	.050	40	1.6	120	4.7	.02	10
26415	1.5	-	50	2.0	145	5.7	.03	10
26420	2.0	-	50	2.0	145	5.7	.03	10
26425	2.5	-	60	2.4	170	6.7	.04	10
26430	3.0	-	60	2.4	170	6.7	.05	10
26440	4.0		60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate



26399 8 Piece Precision Hex Driver Set - Inch

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished. In canvas storage pouch

Item						
No.	Inch	Inch	Inch	Inch	Inch	lbs.
26399 26307	.028	1.6	26320	5/64	2.0	.55
26399 26309	.035	1.6	26323	3/32	2.4	
26399 26313	.050	1.6	26327	7/64	2.4	
26399 26316	1/16	2.0	26331	1/8	2.4	




26491 5 Piece Ball End Hex Driver Set - Metric

Angle entry up to 30°.

Blade high alloy CVM steel.

Item			
No.	mm	mm	lbs.
26491 26413	1.27	40	.31
26491 26415	1.5	50	
26491 26420	2.0	50	
26491 26425	2.5	60	
26491 26430	3.0	60	

Wiha Ball End Precision Series

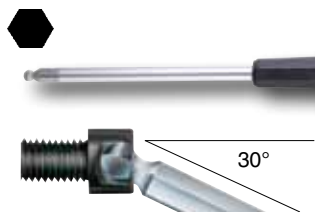


264 Inch Ball End Hex Inch Screwdriver With Precision Handle

Angle entry up to 30°. Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finish.

Item							
No.	Inch	mm	Inch	mm	Inch	lbs.	pkg.
26413	.050	40	1.6	120	4.7	.02	10
26416	1/16	50	2.0	145	5.7	.03	10
26419	5/64	50	2.0	145	5.7	.03	10
26423	3/32	50	2.0	145	5.7	.03	10
26427	7/64	60	2.4	170	6.7	.03	10
26431	1/8	60	2.4	170	6.7	.05	10
26436	9/64	60	2.4	170	6.7	.05	10
26439	5/32	60	2.4	170	6.7	.05	10

*Metric dimensions actual - Inch dimensions approximate

Wiha Ball End Precision Series

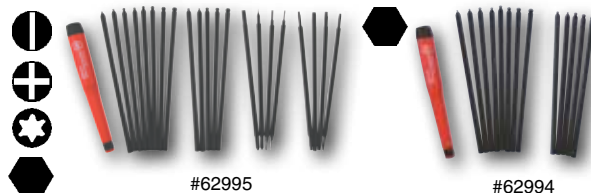

62995 22 Piece Slotted/Phillips/TORX®/Ball End Hex Inch & Metric Tech Pack

Wiha Proturm precision ball retainer handle & 21 Wiha interchangeable blades. Set in canvas storage pouch

62995 Set includes the following blades:

- Slotted: 1.5, 2.0, 3.0, 4.0
- Phillips: #000, #00, #0, #1
- TORX®: T6, T7, T8, T9, T10, T15, T20
- Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0mm

lbs. .87

62994 14 Piece Inch/Metric Ball End Hex Work Tech Pack

Proturm precision ball retainer handle & 13 Wiha interchangeable blades.

62994 Set includes the following blades:

- Hex Inch: .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
- Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0mm

lbs. .66 Set in canvas storage pouch

26490 8 Piece Ball End Hex Driver Set - Inch

Angle entry up to 30°.

Blade high alloy chrome-vanadium-molybdenum steel.



Item			
No.	Inch	Inch	lbs.
26490	26413	.050	1.6
	26416	1/16	2.0
	26419	5/64	2.0
	26423	3/32	2.0
	26427	7/64	2.4
	26431	1/8	2.4
	26436	9/64	2.4
	26439	5/32	2.4

SYS 4 Drive-Loc Precision Locking Tools



26961 ESD Safe Dissipative Precision Drive-Loc Handle

Surface resistant 10⁶-10⁹ Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Ball retainer hold. 105mm/4.13" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26961	4.0	.1574	23	.91	.08



26499 8 Piece Ball End Hex Driver Set - Inch

Blade high alloy chrome-vanadium-molybdenum steel. Hard chrome finished. In canvas storage pouch


finished - in cavity storage pouch						
Item						
No.		Inch	Inch		Inch	Inch
26499	26413	.050	1.6	26427	7/64	2.4
	26416	1/16	2.0	26431	1/8	2.4
	26419	5/64	2.0	26436	9/64	2.4
	26423	3/32	2.0	26439	5/32	2.4



280 SYSTEM 4 Metric Hex Drive-Loc Reversible Locking Blades

On 4mm Hex blades

Item			
No.	mm	mm	lbs.
28003	1.3	+	1.3
28004	1.5	+	1.5
28005	2.0	+	2.0
28006	2.5	+	2.5
28007	3.0	+	3.0
28008	4.0	+	4.0

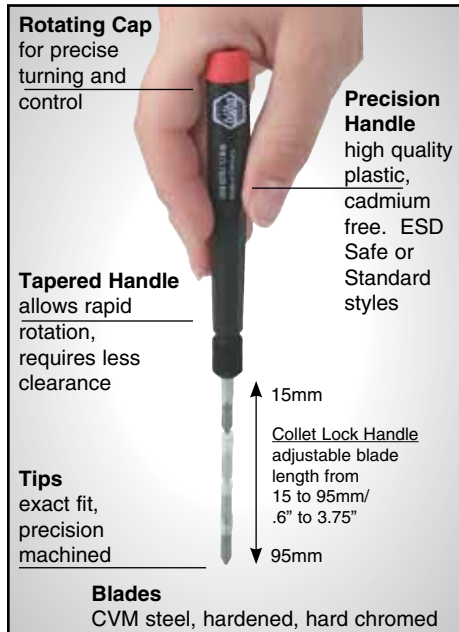

26900 SYS 4 Standard Precision Handle, with rotating control cap. Accepts all SYSTEM 4 interchangeable blades. Wiha Precision handle, tapered, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26900	4.0	.1574	14.0	.55	.04

26901 SYSTEM 4 Standard Precision

Adjustable handle with rotating control cap.

- Allows adjustable blade from 15 to 95mm.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
26901	4.0	.1574	14.0	.55	.06

269 SYSTEM 4 Metric Ball End & Standard Hex, Reversible Blade

Wiha vapor Chrome-Top finish on tips.

One side hex, other side ball end hex.

Item					
No.	mm	mm	mm	Inch	lbs.
26932	1.27 + 1.27	120	4.7	.05	
26933	1.5 + 1.5	120	4.7	.05	
26934	2.0 + 2.0	120	4.7	.06	
26935	2.5 + 2.5	120	4.7	.06	
26936	3.0 + 3.0	120	4.7	.06	
26937	4.0 + 4.0	120	4.7	.06	



28000 ESD Safe Dissipative Precision

Handle with rotating control cap. Surface resistant 10^6 - 10^9 Ohms. 4 mm hex retainer for all SYSTEM 4 interchangeable blades. Tapered handle, high quality plastic, impact resistant. Ball retainer hold. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28000	4.0	.1574	14.0	.55	.04



28001 ESD Safe Dissipative Precision Adjustable Handle with rotating control cap.

Advantages:

- Use in ESD sensitive applications. Surface resistant 10^6 - 10^9 Ohms.
- Collet lock allows for quick & easy adjustment.
- Holds blade securely in place. Accepts all SYSTEM 4 blades. 110mm/4.3" OAL

Item					
No.	mm	Inch	mm	Inch	lbs.
28001	4.0	.1574	14.0	.55	.04



280 SYSTEM 4 Metric Ball End Hex

Interchangeable Blade Ball end works at 30° angle entry for easy access to fasteners.

Item					
No.	mm	mm	Inch	lbs.	pkg.
28033	1.5	120	4.7	.06	1
28034	2.0	120	4.7	.06	1
28035	2.5	120	4.7	.06	1
28036	3.0	120	4.7	.06	1
28037	4.0	120	4.7	.06	1



280 SYSTEM 4 Inch Ball End Hex

Interchangeable Blade Ball end works at 30° angle entry for easy access to fasteners.

Item					
No.	Inch	mm	Inch	lbs.	
28021	.050	120	4.7	.06	
28023	1/16	120	4.7	.06	
28024	5/64	120	4.7	.06	
28025	3/32	120	4.7	.06	
28026	7/64	120	4.7	.06	
28027	1/8	120	4.7	.06	
28028	9/64	120	4.7	.06	
28029	5/32	120	4.7	.06	



269 SYSTEM 4 Metric Hex,

Interchangeable Blade High alloy CVM steel, hardened, corrosion protected.

Item					
No.	mm	mm	Inch	lbs.	
26913	.71	120	4.7	.06	
26914	.89	120	4.7	.06	
26915	1.27	120	4.7	.06	
26916	1.5	120	4.7	.06	
26917	2.0	120	4.7	.06	
26918	2.5	120	4.7	.06	
26919	3.0	120	4.7	.06	
26920	4.0	120	4.7	.06	



269 SYSTEM 4 Inch Hex,

Interchangeable Blade High alloy CVM steel, hardened, corrosion protected.

Item					
No.	Inch	mm	Inch	lbs.	
26921	.050	120	4.7	.06	
26923	1/16	120	4.7	.06	
26924	5/64	120	4.7	.06	
26925	3/32	120	4.7	.06	
26926	7/64	120	4.7	.06	
26927	1/8	120	4.7	.06	
26928	9/64	120	4.7	.06	
26929	5/32	120	4.7	.06	



Wiha ESD Safe Precision Collet Lock handle and 8 Wiha interchangeable blades



26999 9 Pc. Hex Metric Precision Blade Set Set includes the following blades:

Hex Metric:	.71, .89, 1.27, 1.5, 2.0, 2.5, 3.0, 4.0mm
lbs.	.66



Wiha ESD Safe Precision Collet Lock handle and 8 Wiha interchangeable blades



26989 9 Pc. Hex Inch Precision Blade Set Set includes the following blades:

Hex Inch:	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
lbs.	.64

SYSTEM 4 Handles & Micro Bits

Tips
exact fit,
precision
machined

Rotating Cap
for precise
turning and
control

Tapered Handle
allows rapid rotation,
requires less clearance

Bits CVM steel,
hardened

Use bits directly in handle or with 4" bit extension



110mm/4.3" OAL

75800 SYSTEM 4 Standard Precision Bit

Handle with rotating control cap. Tapered, high quality plastic, impact resistant, ball retainer. Accepts all SYSTEM 4 Series bits.

Item No.				
No.	mm	Inch	mm	Inch lbs.
75800	4.0	.1574	14.0	.55 .06



110mm/4.3" OAL

75801 SYSTEM 4 ESD Safe Dissipative

Precision Bit Handle with rotating control cap. Tapered, high quality plastic, impact resistant. **Advantages:**

- For working in ESD sensitive applications Surface resistant 10^6 - 10^9 Ohms 
- Ball retainer holds bits securely in place
- Accepts all SYSTEM 4 Series bits

Item No.				
No.	mm	Inch	mm	Inch lbs.
75801	4.0	.1574	14.0	.55 .06



75901 Magnetic Bit Extension Blade For SYSTEM 4 Micro Bits Shaft CVM steel, hardened. Magnetic bit holder.

Item No.				
No.	Size	mm	mm	lbs.
75901	4.0	100	4.0	.04



75900 Extension Blade For SYSTEM 4 Micro Bits Shaft CVM steel, hardened, corrosion protected. Ball retainer bit extension for 4 mm bits.

Item No.				
No.	Size	mm	mm	lbs.
75900	4.0	100	4.0	.07



753 SYSTEM 4 Hex Metric Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item No.				
No.	mm	mm	Inch	lbs.
75307	.71	28	1.1	.01
75309	.89	28	1.1	.01
75313	1.27	28	1.1	.01
75315	1.5	28	1.1	.01
75320	2.0	28	1.1	.01
75325	2.5	28	1.1	.01
75330	3.0	28	1.1	.01
75340	4.0	28	1.1	.01



753 SYSTEM 4 Hex Inch Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item No.				
No.	Inch	mm	Inch	lbs.
75307	.028	28	1.1	.01
75309	.035	28	1.1	.01
75313	.050	28	1.1	.01
75350	1/16	28	1.1	.01
75352	5/64	28	1.1	.01
75354	3/32	28	1.1	.01
75356	7/64	28	1.1	.01
75358	1/8	28	1.1	.01
75360	9/64	28	1.1	.01
75340	5/32	28	1.1	.01



753 SYSTEM 4 Metric Security Hex Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item No.				
No.	mm	mm	Inch	lbs.
75322	2.0	28	1.1	.01
75327	2.5	28	1.1	.01
75332	3.0	28	1.1	.01
75342	4.0	28	1.1	.01



753 SYSTEM 4 Security Hex Inch Bits High alloy CVM steel, hardened, on 4 mm hex stock.

Item No.				
No.	Inch	mm	Inch	lbs.
75362	5/64	28	1.1	.01
75364	3/32	28	1.1	.01
75366	7/64	28	1.1	.01
75368	1/8	28	1.1	.01
75370	9/64	28	1.1	.01
75372	5/32	28	1.1	.01

Wiha SYSTEM 4 Micro Bits & Compact Bit Sets



75395 18 Piece SYSTEM 4 Hex Inch & Metric Precision Interchangeable Bit Set, In Compact Fold Out Box

Wiha precision handle, bit extension & 16 Wiha interchangeable bits.

Item No. Combination Bit Set

75395 Set with Standard Precision Handle

Set includes the following bits:

-  **Hex Metric:** .71, .89, 1.27, 1.5, 2.0, 2.5, 3.0, 4.0mm
-  **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"

 **100mm Bit Extension**

 **lbs.** .58



75096 16 Piece Precision Micro Bit Hex Inch & Metric Sets

ESD Safe precision handle, Bit Extension and 14 CVM steel Micro Bits.

Set includes the following Micro Bits:

-  **Inch:** 0.89/0.35", 1.27/.050", 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"
-  **Metric:** 1.5, 2.0, 2.5, 3.0, 4.0mm

 **lbs.** .14



75983 Micro Bit Handle Storage Hex Inch Bit Set, 7 Pcs. Wiha precision storage handle & 6 interchangeable bits.

Item No. Precision Storage Handle Set

75983  **Hex Inch:** .050, 1/16, 5/64, 3/32, 7/64, 1/8"

 **lbs.** .08

Wiha Cushion Grip Stubby Bit Holder

Stubby 6 in 1 Multi-Bit Driver Sets

Ergo soft grip
handles

Stainless steel
bit holder



Bits
hardened
for extreme
durability

Just 2.5" over all length



38056 Ball End Hex SoftFinish® CushionGrip Stubby Bit Holder
with Wiha cushion grip handle and CVM tool steel shaft.

Set includes the following 1/4" bits:

● **Ball End Hex Inch:** 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs. .21



38057 Hex Metric SoftFinish® CushionGrip Stubby Bit Holder
with Wiha cushion grip handle and CVM tool steel shaft.

Set includes the following 1/4" bits:

● **Hex Metric:** 2.0, 2.5, 3.0, 4.0, 5.0, 6.0mm lbs. .18



38058 Hex Inch SoftFinish® CushionGrip Stubby Bit Holder
with Wiha cushion grip handle and CVM tool steel shaft.

Set includes the following 1/4" bits:

● **Hex Inch:** 3/32, 7/64, 1/8, 9/64, 5/32, 3/16" lbs. .18

Wiha Torque Ratchet Bit Sets

Smooth, high torque, silent ratchet handle


Pistol Grip Handle ergonomic design with free running mechanism. Instant clutch engagement allows constant turning pressure on the fastener.

Hex Retainer
for bit holder
blades



No release
of handle is needed, change of
direction can be made with index
finger and thumb.
Allows for quick adjustment to
right, left or fixed turning.


**Opens a new generation of easier
torque transmission**

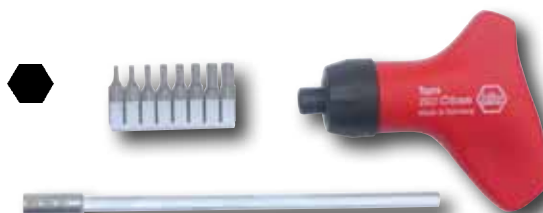

28298 12 Piece Hex Inch Topra Ratchet Bit Set

Set includes Topra Handle, Magnetic bit holder and the following bits:

● **Hex Inch:** 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs. .65

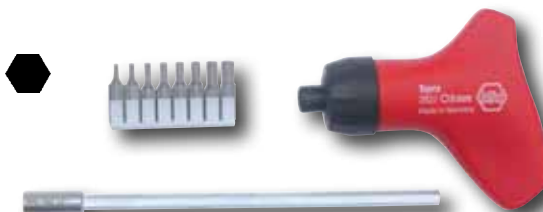

28299 10 Piece Hex Metric Topra Ratchet Bit Set

Set includes Topra Handle, Magnetic bit holder and the following bits:

● **Hex Metric:** 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm lbs. .65

Wiha Bit Selectors

Compact size and easy bit selection make the Bit Selector an ideal maintenance tool



Plastic storage box is compact, durable and light weight

Slide out drawer allows quick bit access and secure storage



Molded hex cavity in box end Magnetic adapter fits into opening so tool case can be used as a handle on quick fastening jobs

1/4" Magnetic Adapter fits all standard 1/4" bits

792 Sets Bit-Selector Sets

These handy sets include 10 hardened bits of chrome-vanadium-molybdenum steel. 1/4" magnetic bit holder can be used in power tools. Plastic storage box is compact, durable and light weight. Molded hex cavity turns box into handle for quick fastening jobs. Quick bit access with slide out drawer. Packaged in clear blister pack.



79276 Bit-Selector With Ball End Hex Inch Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 8 Bits:

● Ball End Hex Inch: 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs. .30



Item #79246

79246 Bit-Selector With Hex Metric Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 10 Bits:

● Hex Inch: 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs. .32

79256 Bit-Selector With Hex Metric Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 8 Bits:

● Hex Metric: 1.5, 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm lbs. .30



79266 Bit-Selector With Security Hex Inch Bits. Set Includes Magnetic 1/4" Bit Holder & The Following 9 Bits:

● Hex Inch: 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs. .31

Screw Holding



MagicRing



71399 Bit-Selector With Metric & Inch MagicRing Insert 1/4" Bits Set Includes Magnetic 1/4" Bit Holder & The Following 10 Bits:

● No Ball End lbs. .46
 Hex Metric: 3.0, 4.0, 5.0, 6.0mm
 Hex Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Wiha MagicRing Insert Bits

Screw Holding Hex Bits



713 MagicRing Metric Insert Bits, 1/4"

Item	mm	mm	pkg.	lbs.
No.	mm	mm	pkg.	lbs.
71304	3.0	25	1	.01
71307	4.0	25	1	.01
71310	5.0	25	1	.01
71311	6.0	25	1	.01

713 MagicRing Inch Insert Bits, 1/4"

Item	Inch	mm	pkg.	lbs.
No.	Inch	mm	pkg.	lbs.
71343	1/8	25	1	.01
71346	9/64	25	1	.01
71349	5/32	25	1	.01
71352	3/16	25	1	.01
71354	7/32	25	1	.01
71358	1/4	25	1	.01

Wiha MagicRing Power Bits

Screw Holding Hex Bits



743 MagicRing Metric Power Bits, 1/4"

Item	mm	mm	pkg.	lbs.
No.	mm	mm	pkg.	lbs.
74301	3.0	50	1	.02
74305	4.0	50	1	.02
74307	5.0	50	1	.03
74319	6.0	50	1	.03

743 MagicRing Inch Power Bits, 1/4"

Item	mm	mm	pkg.	lbs.
No.	mm	mm	pkg.	lbs.
74369	1/8	50	1	.02
74371	9/64	50	1	.02
74373	5/32	50	1	.02
74375	3/16	50	1	.03
74377	7/32	50	1	.03
74379	1/4	50	1	.03

Wiha XSelector Bit Sets

Compact size and easy bit selection make the Wiha XSelector an ideal maintenance tool

Easy bit access
with hinged
cover



XSelector Pocket Sized
3-1/8" x 2-1/8" x 1/2"

Sets include Clicfix quick
release holder

794 Sets XSelector Bit Sets

These handy sets include 10 hardened bits of chrome-vanadium-molybdenum steel. 1/4" Quick Release holder can be used in power tools. Quick bit access through integrated bit-clamp.



79446 XSelector Bit Set With Hex Inch Bits

Set Includes Quick Release Holder and the following 10 bits: lbs. .27

Hex Inch: 1/16, 5/64, 3/32, 7/64,
1/8, 9/64, 5/32, 3/16, 7/32, 1/4"

Wiha Security Hex Inch & Metric PokitPaks



71998 PokitPak - Security Hex Inch Insert Bits In Molded Case - Set includes 6 - 1/4" Insert Bits

Inch Security Hex: lbs. .12
3/32, 7/64, 1/8, 9/64, 5/32, 3/16"



71995 PokitPak - Security Hex Insert Bits In Molded Case - Set includes 6 - 1/4" Insert Bits

Metric Security Hex: lbs. .31
2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm

Wiha Power Bit Belt Packs



74986 Power Bit Belt Pack With Inch & Metric Hex Bits

Set includes the following 10 bits:

Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs.
Metric: 3.0, 4.0, 5.0, 6.0mm .34



Screw Holding Hex Bits

 
74989 Power Bit Belt Pack With Screw Holding Hex MagicRing Bits

Set includes the following 10 bits:

Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs.
Metric: 3.0, 4.0, 5.0, 6.0mm .34



Screw Holding Hex Bits



74999 Power Bit Belt Pack With Screw Holding Inch & Metric Ball End Hex MagicRing Bits

Set includes the following 10 bits:

Inch: 1/8, 9/64, 5/32, 3/16, 7/32, 1/4" lbs.
Metric: 3.0, 4.0, 5.0, 6.0mm .37

Wiha Security Hex Inch Multi Bit Set



38014 Security Hex Inch Multi-Bit Screwdriver, 6 Pc. Set

With Wiha Powerhandle & CVM steel, hardened shaft.

Set includes the following 1/4" bits: lbs. .39
Security Hex: 3/32, 1/8, 5/32, 3/16, 7/32"

Wiha Hex Inch & Metric Power Bits



743 Hex Inch Power Bits

1/4" Hex Drive, Length 2.0"/50mm

Item				
No.	Inch	mm	pkg.	lbs.
74311	3/32	50	10	.30
74312	7/64	50	10	.30
74313	1/8	50	10	.30
74314	9/64	50	10	.30
74315	5/32	50	10	.30
74316	3/16	50	10	.30
74317	7/32	50	10	.30
74318	1/4	50	10	.30



743 Hex Metric Power Bits

1/4" Hex Drive, Length 2.0"/50mm

Item				
No.	mm	mm	pkg.	lbs.
74325	2.5	50	10	.25
74330	3.0	50	10	.25
74340	4.0	50	10	.25
74350	5.0	50	10	.25
74360	6.0	50	10	.25
74380	8.0	50	10	.38



2 bit
pack

743 Hex Inch Power Bit Packs, 2"

Item			
No.	Inch	mm	lbs.
74381	3/32	50	.07
74382	7/64	50	.07
74383	1/8	50	.07
74384	9/64	50	.07
74385	5/32	50	.07
74386	3/16	50	.07
74387	7/32	50	.07
74388	1/4	50	.07

743 Hex Metric Power Bit Packs, 2"

Item			
No.	mm	mm	lbs.
74361	2.5	50	.07
74362	3.0	50	.07
74363	4.0	50	.07
74364	5.0	50	.07
74365	6.0	50	.07
74366	8.0	50	.09



743 Hex Inch Power Bits

1/4" Hex Drive, Length 2.75"/70mm

Item				
No.	Inch	mm	pkg.	lbs.
74341	5/64	70	1	.36
74342	3/32	70	1	.36
74343	7/64	70	1	.36
74344	1/8	70	1	.36
74345	9/64	70	1	.36
74346	5/32	70	1	.36
74347	3/16	70	1	.36
74348	7/32	70	1	.36
74349	1/4	70	1	.36



743 Hex Metric Power Bits

1/4" Hex Drive, Length 2.75"/70mm

Item				
No.	mm	mm	pkg.	lbs.
74351	2.0	70	1	.36
74352	2.5	70	1	.36
74353	3.0	70	1	.36
74354	4.0	70	1	.36
74355	5.0	70	1	.36
74356	6.0	70	1	.36
74357	8.0	70	1	.36

Hex Metric Long Insert Bit On 5/16"



72388 Hex Metric Bit On 5/16" Stock

Item				
No.	mm	mm	pkg.	lbs.
72388	12.0	75	10	.14

Stainless Steel Hex Metric Bits



701 Stainless Steel Hex Metric Insert Bits

Item			
No.	mm	mm	pkg.
70170	1.5	25	10
70171	2.0	25	10
70172	2.5	25	10
70173	3.0	25	10
70174	4.0	25	10
70175	5.0	25	10
70176	6.0	25	10

Wiha Ball End Hex Inch Insert Bits



717 Ball End Hex Inch Insert Bits, 1/4"

Item				
No.	Inch	mm	pkg.	lbs.
71701	3/32	25	10	.12
71702	7/64	25	10	.12
71703	1/8	25	10	.12
71704	9/64	25	10	.12
71705	5/32	25	10	.12
71706	3/16	25	10	.13
71707	7/32	25	10	.13
71708	1/4	25	10	.13



2 bit
pack

717 Ball End Hex Inch Insert Bit Packs, 1"

Item			
No.	Inch	mm	lbs.
71711	3/32	25	.03
71712	7/64	25	.03
71713	1/8	25	.03
71714	9/64	25	.03
71715	5/32	25	.04
71716	3/16	25	.04
71717	7/32	25	.04
71718	1/4	25	.04

Ball End Hex Metric Power Bits

2 pc. bit pack!



717 Ball End Hex Metric Power Bits

1/4" Hex Drive, Length 1.5"/38mm

Item			
No.	mm	mm	pkg.
71719	1.5	38	1
71720	2.0	38	1
71721	2.5	38	1
71722	3.0	38	1
71723	4.0	38	1
71724	5.0	38	1
71725	6.0	38	1

Wiha Terminator Hex Inch & Metric Impact Bits - Insert & Power

**Up To 30X
Performance Over
Standard
Screwdriver Bits**



Dual material
impact absorbing
torsion zone

Impact rated bits for long life in impact applications

Provide up to 30 times impact performance over standard bits

Standard 1/4" drive - No special adaptor required

Wiha enhanced bi-material torsion zone

Precision machined exact fit tips

Wiha exclusive CVM tool steel

Guaranteed to out perform impact imposters


**765 Hex Inch Terminator Impact Bits,
1/4" Insert - 10 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76530	1/8	29	10
76531	9/64	29	10
76532	5/32	29	10
76533	3/16	29	10
76534	7/32	29	10
76535	1/4	29	10


**768 Hex Inch Terminator Impact Bits,
1/4" Insert - 2 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76830	1/8	29	2
76831	9/64	29	2
76832	5/32	29	2
76833	3/16	29	2
76834	7/32	29	2
76835	1/4	29	2


**765 Hex Metric Terminator Impact Bits,
1/4" Insert - 10 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76523	3.0	29	10
76524	4.0	29	10
76525	5.0	29	10
76526	6.0	29	10


**768 Hex Metric Terminator Impact Bits,
1/4" Insert - 2 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76823	3.0	29	2
76824	4.0	29	2
76825	5.0	29	2
76826	6.0	29	2


**765 Hex Inch Terminator Impact Bits,
1/4" Power - 10 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76570	1/8	49	10
76571	9/64	49	10
76572	5/32	49	10
76573	3/16	49	10
76574	7/32	49	10
76575	1/4	49	10


**768 Hex Inch Terminator Impact Bits,
1/4" Power - 2 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76870	1/8	49	2
76871	9/64	49	2
76872	5/32	49	2
76873	3/16	49	2
76874	7/32	49	2
76875	1/4	49	2


**765 Hex Metric Terminator Impact Bits,
1/4" Power - 10 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76563	3.0	49	10
76564	4.0	49	10
76565	5.0	49	10
76566	6.0	49	10



**768 Hex Metric Terminator Impact Bits,
1/4" Power - 2 bit pack**

Item	Hex	Insert	Power
No.	Inch	mm	pkg.
76863	3.0	49	2
76864	4.0	49	2
76865	5.0	49	2
76866	6.0	49	2


**76894 7 Pc. Bit Buddy Set With
Terminator Impact Power Bits - 49mm**

76894 Set includes the following bits:

- Hex Inch: 5/32, 3/16, 7/32, 1/4"
- Hex Metric: 4, 5, 6mm

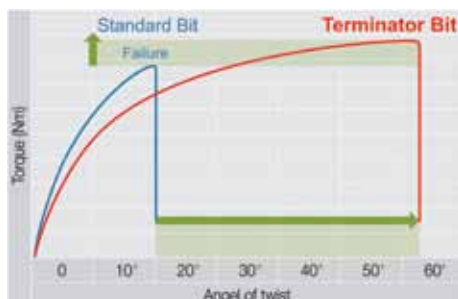1/4" Drive Insert & Power Bits


**Up To 30X Performance
Over Standard Screwdriver Bits**


**76893 7 Pc. Bit Buddy Set With
Terminator Impact Insert Bits - 29mm**

76893 Set includes the following bits:

- Hex Inch: 5/32, 3/16, 7/32, 1/4"
- Hex Metric: 4, 5, 6mm

**91247 Empty Bit Buddy Case Holds
Terminator Impact Insert Bits**

91247 Holds 7 Impact Bits

**91313 Empty Bit Buddy Case Holds
Terminator Impact Power Bits**

91313 Holds 7 Impact Bits

Wiha Bit Holders

Quick Release



714 ClicFix Bit Holder, Magnetic, For Insert Bits

Item				
No.	Size	Size	mm	Inch
71490	1/4"	1/4"	60	2.4
71491	1/4"	1/4"	75	2.9

Quick Release



714 CentroFix Bit Holder For Power Bits

Item				
No.	Size	Size	mm	Inch
71480	1/4"	1/4"	60	2.3

Wiha Impact Bit Holding Sockets



720 Impact Bit Holding Socket With Retaining Ring

For 1/4" drive bits.

Item				
No.	Bit	mm	Drive	lbs.
72001	1/4	25	1/4"	.05
72002	1/4	30	3/8"	.10
72003	1/4	35	1/2"	.21

72090 3 Piece Bit Holding Socket Set

for use with 1/4" Insert bits

Drive:		lbs.
1/4", 3/8", 1/2"		.40

Long Blade Sockets & Sets



771 Hex Metric Sockets

1/4" Drive 6" Long Bit Socket

Item				
No.	Size	Inch	mm	lbs.
77140	2.5	6.0		.13
77142	3.0	6.0		.13
77144	4.0	6.0		.13
77146	5.0	6.0		.13
77148	6.0	6.0		.13

77192 5 Pc. Hex Metric Socket Blade Set

Metric: 2.5, 3.0, 4.0, 5.0, 6.0mm

	lbs. .70
--	----------

Long Blade Sockets & Sets



771 Hex Inch Sockets 1/4" Drive 6" Long Bit Socket

Item				
No.	Size	Inch	lbs.	
77128	3/32	6.0	.12	
77130	7/64	6.0	.12	
77132	1/8	6.0	.12	
77134	9/64	6.0	.12	
77136	5/32	6.0	.12	
77138	3/16	6.0	.12	
77139	7/32	6.0	.12	
77141	1/4	6.0	.12	

77191 8 Piece Hex Inch Socket Blade Set

Inch: 3/32, 7/64, 1/8, 9/64, 5/32,

3/16, 7/32, 1/4"  wt. .97



771 Hex Inch Sockets 3/8" Drive 6" Long Bit Socket

Item				
No.	Size	Inch	lbs.	
77165	3/32	6.0	.18	
77167	7/64	6.0	.18	
77169	1/8	6.0	.18	
77171	9/64	6.0	.18	
77173	5/32	6.0	.18	
77175	3/16	6.0	.18	
77177	7/32	6.0	.18	
77179	1/4	6.0	.18	



77198 22 Piece Hex & TORX® Long Blade Socket Set, 1/4" Drive

Inch Hex: 3/32, 7/64, 1/8, 9/64, 5/32,

3/16, 7/32, 1/4"

Metric Hex: 2.5, 3.0, 4.0, 5.0, 6.0mm

TORX®: T8, T9, T10, T15, T20, T25, T27, T30, T40

	lbs. 2.82
---	-----------

Wiha Sockets



713 Hex Sockets 1/4" Square drive socket. Replaceable bit.

1/4" bits CVM steel.

Item				
No.	Inch	mm	lbs.	
71371	1/16	38	.05	
71370	5/64	38	.05	
71372	3/32	38	.05	
71374	7/64	38	.05	
71376	1/8	38	.05	
71378	9/64	38	.05	
71380	5/32	38	.05	
71382	3/16	38	.05	
71384	7/32	38	.05	
71386	1/4	38	.05	

Wiha Sockets



713 Hex Sockets 3/8" Square drive socket. Replaceable bit.
1/4" bits CVM tool steel.

Item			
No.	Inch	mm	lbs.
71375	1/8	42	.09
71377	9/64	42	.09
71379	5/32	42	.09
71381	3/16	42	.09
71383	7/32	42	.09
71385	1/4	42	.09
71388	5/16	42	.10
71390	3/8	42	.10



713 Hex Metric Sockets 1/4" Square drive socket. Replaceable bit. 1/4" bits CVM steel.

Item			
No.	mm	mm	lbs.
71301	1.5	38	.04
71302	2.0	38	.04
71305	2.5	38	.04
71313	3.0	38	.04
71314	4.0	38	.04
71317	5.0	38	.05
71319	6.0	38	.05
71327	8.0	38	.05
71340	10.0	38	.05



713 Hex Metric Sockets 3/8" Square drive socket. Replaceable bit.
1/4" bits CVM steel.

Item			
No.	mm	mm	lbs.
71300	2.0	42	.09
71316	2.5	42	.09
71341	3.0	42	.09
71331	4.0	42	.09
71323	5.0	42	.09
71325	6.0	42	.09
71320	8.0	42	.10
71322	10.0	42	.11



713 Hex Metric Sockets 5/16" Square drive socket. Replaceable bit.
5/16" bits CVM steel.

5/16 dia. 50M steel.

Item			
No.	mm	mm	lbs.
71332	12.0	75	.22



Replaceable bit

761 Security Hex Inch Sockets

3/8" Square drive socket. 1/4" bits CVM steel.

Item			
No.	Inch	mm	lbs.
76164	5/64	42	.09
76165	3/32	42	.09
76166	7/64	42	.09
76167	1/8	42	.09
76168	9/64	42	.09
76169	5/32	42	.09
76170	3/16	42	.09
76171	7/32	42	.09
76172	1/4	42	.09

761 Security Hex Metric Sockets

3/8" Square drive socket. 1/4" bits CVM steel.

Item			
No.	mm	mm	lbs.
76132	2.0	42	.09
76133	2.5	42	.09
76134	3.0	42	.09
76135	4.0	42	.09
76136	5.0	42	.09
76137	6.0	42	.09
76138	8.0	42	.09



717 Ball End Hex Sockets 1/4" Square drive socket. Replaceable bit.
1/4" bits CVM steel.

Item			
No.	Inch	mm	lbs.
71761	3/32	38	.09
71762	7/64	38	.09
71763	1/8	38	.09
71764	9/64	38	.09
71765	5/32	38	.09
71766	3/16	38	.09
71767	7/32	38	.09
71768	1/4	38	.09




717 Ball End Hex Metric Sockets

1/4" Square drive socket. Replaceable bit.
1/4" bits CVM steel.

Item			
No.	mm	mm	lbs.
71771	1.5	51	.11
71772	2.0	51	.11
71773	2.5	51	.11
71774	3.0	51	.11
71775	4.0	51	.11
71776	5.0	51	.12
71777	6.0	51	.12

Wiha Socket Sets On Molded Rails

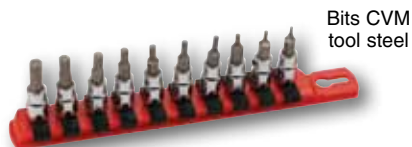


71391 10 Piece Hex Inch Socket Set

1/4" Square drive replaceable bit socket.

Item No. 

71391 lbs. Set includes the following:

.48 1/16, 5/64, 3/32, 7/64, 1/8
9/64, 5/32, 3/16, 7/32, 1/4"

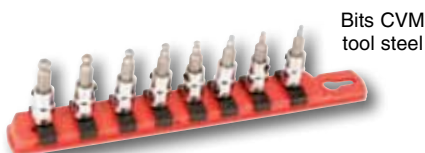

71798 8 Pc. Ball End Hex Inch Socket Set

1/4" Square Drive Replaceable Bit Socket.

Item No. 

71798 lbs. Set includes the following:

.72 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"




71398 7 Pc. Ball End Hex Inch Socket Set

1/4" Square Drive Replaceable Bit Socket.

Item No. 

71398 lbs. Set includes the following:

.48 3/32, 1/8, 9/64, 5/32,
3/16, 7/32, 1/4"

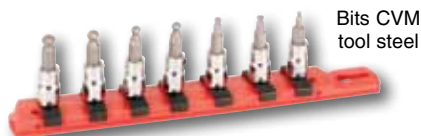

71797 7 Pc. Ball End Hex Metric Sockets

1/4" Square Drive Replaceable Bit Socket.

Item No. 

71797 lbs. Set includes the following:

.72 3.0, 4.0, 5.0, 6.0mm



71392 8 Piece Hex Inch Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No. 

71392 lbs. Set includes the following:

.78 1/4, 5/16, 3/8"

Bits CVM
tool steel



71393 5 Piece Hex Inch Socket Set


3/8" Square Drive Replaceable Bit Socket.

Item No. 

71393 lbs. Set includes the following:

.54 1/4, 5/16, 3/8"

Bits CVM
tool steel

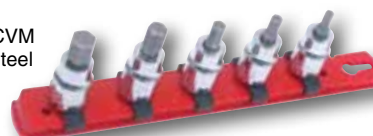

71394 5 Piece Hex Metric Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No. 

71394 lbs. Set includes the following:

.56 8.0, 10.0mm

Bits CVM
tool steel




71996 9 Piece Hex Metric Socket Set

1/4" & 3/8" Sq. Dr. Replaceable Bit Socket

Item No. 

71996 lbs. Set includes the following:

.66 1/4": 1.5, 2.0, 2.5, 3.0, 4.0mm
3/8": 5.0, 6.0, 8.0, 10.0mm

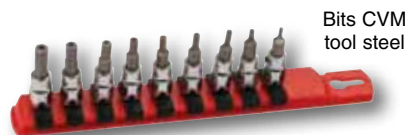

71999 9 Pc. Security Hex Inch Socket Set

3/8" Square Drive Replaceable Bit Socket.

Item No. 

71999 lbs. Set includes the following:

.86 5/64, 3/32, 7/64, 1/8,
9/64, 5/32, 3/16, 7/32, 1/4"



71989 7 Pc. Security Hex Metric Sockets

3/8" Square Drive Replaceable Bit Socket.

Item No. 

71989 lbs. Set includes the following:


.74 2.0, 2.5, 3.0, 4.0, 5.0,
6.0, 8.0mm

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
13650 22	26415 28	27509 26	28503 24	31890 22	33452 10
13651 22	26416 29	27510 26	28504 24	32302 21	33453 11
13652 22	26419 29	27513 26	28505 24	32303 21	33454 10
13653 22	26420 28	27515 26	28506 24	32304 21	33456 11
13654 22	26423 29	27520 26	28507 24	32305 21	33458 10
13655 22	26425 28	27525 26	28508 24	32306 21	33459 11
13656 22	26427 29	27530 26	28509 24	32308 21	33462 11
13657 22	26430 28	27535 26	28511 24	32366 21	33465 11
13658 22	26431 29	27537 26	28513 24	33401 11	33468 11
13659 22	26436 29	27539 26	28515 24	33402 11	33471 11
13662 22	26439 29	27541 26	28517 24	33403 11	33474 11
13663 22	26440 28	27543 26	28518 24	33404 11	33477 11
13664 22	26441 27	27545 26	28519 24	33405 11	33478 21
13665 22	26443 27	27547 26	28521 24	33406 11	33480 11
13666 22	26445 27	27549 26	28523 24	33407 11	33481 21
13667 22	26447 27	27590 26	28525 24	33408 11	33482 21
13668 22	26449 27	27591 26	28545 24	33409 11	33483 21
13669 22	26455 27	28000 30	28546 24	33410 11	33484 11
13670 22	26457 27	28001 30	28547 24	33411 11	33485 21
13671 22	26459 27	28003 27	28548 24	33412 11	33486 21
13672 22	26461 27	28004 27	28549 24	33413 11	33487 21
13673 22	26463 27	28005 27	28550 24	33414 11	33488 11
13690 22	26465 27	28006 27	28551 24	33415 11	33489 10
13691 22	26467 27	28007 27	28552 24	33416 11	33490 21
13693 22	26490 29	28008 27	28553 24	33417 11	33492 11
13694 22	26491 28	28021 30	28554 24	33418 10	33493 11
26307 28	26493 27	28023 30	28555 24	33419 11	33494 10
26309 28	26499 29	28024 30	28556 24	33420 10	33496 10
26313 28	26900 30	28025 30	28557 24	33421 11	33498 10
26315 28	26901 30	28026 30	28558 24	33422 10	33499 10
26316 28	26913 30	28027 30	28559 24	33423 11	35104 19
26320 28	26914 30	28028 30	28560 24	33424 10	35108 19
26323 28	26915 30	28029 30	28587 24	33425 11	35112 19
26325 28	26916 30	28033 30	28588 24	33426 10	35116 19
26327 28	26917 30	28034 30	28916 25	33427 11	35120 19
26330 28	26918 30	28035 30	28917 25	33428 10	35124 19
26331 28	26919 30	28036 30	28918 25	33429 11	35128 19
26333 28	26920 30	28037 30	28919 25	33430 10	35132 19
26336 28	26921 30	28116 23	28920 25	33432 10	35136 19
26340 28	26923 30	28117 23	28921 25	33433 10	35140 19
26341 27	26924 30	28118 23	28922 25	33434 11	35143 19
26343 27	26925 30	28119 23	28923 25	33435 11	35144 19
26345 27	26926 30	28120 23	28924 25	33436 11	35145 19
26347 27	26927 30	28122 23	28931 25	33437 11	35146 19
26349 27	26928 30	28123 23	28933 25	33438 11	35147 19
26351 27	26929 30	28124 23	28935 25	33439 10	35150 19
26353 27	26932 30	28149 23	28937 25	33440 10	35152 19
26363 27	26933 30	28150 23	28938 25	33441 21	35153 19
26367 27	26934 30	28151 23	28939 25	33442 10	35155 19
26369 27	26935 30	28192 23	28940 25	33443 21	35156 19
26371 27	26936 30	28298 32	31805 22	33444 10	35159 19
26390 28	26937 30	28299 32	31807 22	33445 21	35162 19
26391 28	26961 27	28486 23	31809 22	33446 10	35165 19
26392 27	26989 30	28487 23	31811 22	33447 21	35168 19
26393 27	26999 30	28488 23	31813 22	33448 10	35171 19
26399 28	27505 26	28501 24	31815 22	33449 21	35174 19
26413 28	27507 26	28502 24	31817 22	33450 10	35175 19

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
35176 19	35247 18	35341 20	36941 5	46740 15	66930 5
35177 19	35248 18	35342 20	36942 5	46750 15	66936 4
35178 19	35249 18	35343 20	36943 5	46760 15	66937 5
35179 19	35250 18	35345 20	36944 7	46780 15	66938 5
35180 19	35251 17	35346 20	36945 7	46786 15	66944 4
35191 19	35252 17	35347 20	36946 7	46793 14	66945 4
35192 19	35253 17	35348 20	36947 7	46794 14	66946 4
35193 19	35254 17	35390 20	36948 5	46796 15	66947 4
35194 19	35255 17	35391 20	36949 5	46797 14	66950 4
35195 16	35256 17	35392 20	36950 7	46799 15	66952 4
35196 16	35257 17	35393 20	36951 5	54001 9	66953 4
35197 16	35258 17	36696 6	36952 7	54002 9	66955 4
35198 16	35259 17	36710 12	36953 7	54003 9	66956 4
35200 18	35260 18	36713 12	36954 5	54004 9	66959 4
35201 17	35261 17	36715 13	36955 7	54005 9	66962 4
35202 17	35270 18	36716 12	36956 7	54006 9	66965 4
35203 18	35280 18	36719 12	36957 5	54007 9	66968 4
35204 17	35282 18	36720 13	36958 5	54008 9	66971 4
35205 18	35284 18	36723 12	36959 7	54009 9	66982 6
35206 17	35285 18	36725 13	36960 5	54010 9	66988 6
35208 17	35286 18	36726 12	36961 5	54012 8	66990 4
35210 17	35288 18	36728 12	36962 7	54014 8	66991 4
35211 17	35290 18	36730 13	36963 5	54016 8	66992 4
35212 17	35291 18	36732 12	36965 7	54018 8	66993 5
35213 18	35295 17	36734 12	36968 7	54020 9	66994 5
35214 17	35297 17	36736 12	36971 7	54022 8	66995 5
35215 18	35301 20	36738 12	36988 6	54024 8	66996 6
35216 18	35302 20	36740 13	36989 20	54025 9	66997 16
35217 17	35303 20	36742 12	36990 7	54030 9	66998 5
35218 18	35304 20	36744 12	36991 7	54040 8	70170 36
35219 17	35305 20	36750 13	36992 7	54042 9	70171 36
35220 18	35306 20	36760 13	36993 7	54050 8	70172 36
35221 17	35307 20	36780 13	36995 6	54052 9	70173 36
35222 18	35308 20	36786 13	36996 16	54060 8	70174 36
35223 17	35309 20	36790 13	36997 16	54062 9	70175 36
35224 18	35310 20	36791 12	36998 5	54080 8	70176 36
35225 18	35311 20	36792 13	38014 34	54082 9	71300 39
35226 18	35312 20	36793 12	38056 32	54086 8	71301 39
35227 17	35313 20	36794 12	38057 32	54088 9	71302 39
35228 18	35314 20	36904 7	38058 32	54090 8	71303 35
35230 18	35316 20	36908 7	46702 14	54091 8	71304 33
35231 17	35317 20	36911 6	46704 14	54092 9	71305 39
35232 18	35318 20	36912 7	46706 14	54094 9	71306 35
35233 17	35319 20	36913 6	46708 14	54095 9	71307 33
35234 18	35320 20	36914 6	46710 14	54097 9	71308 35
35235 17	35321 20	36915 6	46712 14	62994 29	71309 35
35236 18	35330 20	36916 7	46714 14	62995 29	71310 33
35237 17	35331 20	36917 6	46715 15	66904 4,5	71311 33
35238 18	35332 20	36918 6	46716 14	66908 4,5	71312 35
35239 17	35333 20	36919 6	46718 14	66912 4,5	71313 39
35240 18	35334 20	36920 7	46720 15	66916 4	71314 39
35241 17	35335 20	36921 6	46722 14	66918 5	71315 35
35242 18	35336 20	36922 6	46724 14	66920 4	71316 39
35243 17	35337 20	36924 7	46725 15	66922 5	71317 39
35244 18	35338 20	36928 7	46726 14	66924 4	71318 35
35245 18	35339 20	36936 7	46728 14	66926 5	71319 39
35246 18	35340 20	36940 5	46730 15	66928 4	71320 39

Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page	Item No. Page
71321 35	71387 35	71936 36	74317 36	75330 31	76574 37
71322 39	71388 39	71938 36	74318 36	75332 31	76575 37
71323 39	71390 39	71939 36	74319 33	75340 31	76823 37
71324 35	71391 40	71940 36	74325 36	75342 31	76824 37
71325 39	71392 40	71941 36	74330 36	75350 31	76825 37
71326 35	71393 40	71942 36	74340 36	75352 31	76826 37
71327 39	71394 40	71943 36	74341 36	75354 31	76830 37
71328 35	71396 35	71944 36	74342 36	75356 31	76831 37
71329 35	71397 35	71945 36	74343 36	75358 31	76832 37
71330 35	71398 40	71946 36	74344 36	75360 31	76833 37
71331 39	71399 33	71955 36	74345 36	75362 31	76834 37
71332 39	71480 38	71956 36	74346 36	75364 31	76835 37
71333 35	71490 38	71960 36	74347 36	75366 31	76863 37
71336 35	71491 38	71970 36	74348 36	75368 31	76864 37
71339 35	71701 37	71971 36	74349 36	75370 31	76865 37
71340 39	71702 37	71972 36	74350 36	75372 31	76866 37
71341 39	71703 37	71973 36	74351 36	75395 31	76870 37
71342 35	71704 37	71974 36	74352 36	75800 31	76871 37
71343 33	71705 37	71975 36	74353 36	75801 31	76872 37
71345 35	71706 37	71976 36	74354 36	75900 31	76873 37
71346 33	71707 37	71977 36	74355 36	75901 31	76874 37
71348 35	71708 37	71978 36	74356 36	75983 31	76875 37
71349 33	71711 37	71979 36	74357 36	76132 39	76893 37
71351 35	71712 37	71980 36	74360 36	76133 39	76894 37
71352 33	71713 37	71981 36	74361 36	76134 39	77128 38
71353 35	71714 37	71982 36	74362 36	76135 39	77130 38
71354 33	71715 37	71983 36	74363 36	76136 39	77132 38
71356 35	71716 37	71984 36	74364 36	76137 39	77134 38
71358 33	71717 37	71985 36	74365 36	76138 39	77136 38
71359 35	71718 37	71989 40	74366 36	76164 39	77138 38
71360 35	71719 37	71995 34	74369 33	76165 39	77139 38
71361 35	71720 37	71996 40	74371 33	76166 39	77140 38
71362 35	71721 37	71998 34	74373 33	76167 39	77141 38
71363 35	71722 37	71999 40	74375 33	76168 39	77142 38
71364 35	71723 37	72001 38	74377 33	76169 39	77144 38
71365 35	71724 37	72002 38	74379 33	76170 39	77146 38
71366 35	71725 37	72003 38	74380 36	76171 39	77148 38
71367 35	71761 39	72090 38	74381 36	76172 39	77165 38
71368 35	71762 39	72388 36	74382 36	76523 37	77167 38
71369 35	71763 39	73301 35	74383 36	76524 37	77169 38
71370 38	71764 39	73302 35	74384 36	76525 37	77171 38
71371 38	71765 39	73303 35	74385 36	76526 37	77173 38
71372 38	71766 39	73304 35	74386 36	76530 37	77175 38
71373 35	71767 39	73305 35	74387 36	76531 37	77177 38
71374 38	71768 39	73306 35	74388 36	76532 37	77179 38
71375 39	71771 39	73307 35	74986 34	76533 37	77191 38
71376 38	71772 39	73308 35	74989 34	76534 37	77192 38
71377 39	71773 39	73309 35	74999 34	76535 37	77198 38
71378 38	71774 39	74301 33	75096 31	76563 37	79246 33
71379 39	71775 39	74305 33	75307 31	76563 37	79256 33
71380 38	71776 39	74307 33	75309 31	76564 37	79266 33
71381 39	71777 39	74311 36	75313 31	76565 37	79276 33
71382 38	71797 40	74312 36	75315 31	76566 37	79446 34
71383 39	71798 40	74313 36	75320 31	76570 37	91118 26
71384 38	71930 36	74314 36	75322 31	76571 37	91247 37
71385 39	71932 36	74315 36	75325 31	76572 37	91256 37
71386 38	71934 36	74316 36	75327 31	76573 37	

(800) 494-6104
 fax: (800) 494-7456
 email: cservice@wihatools.com

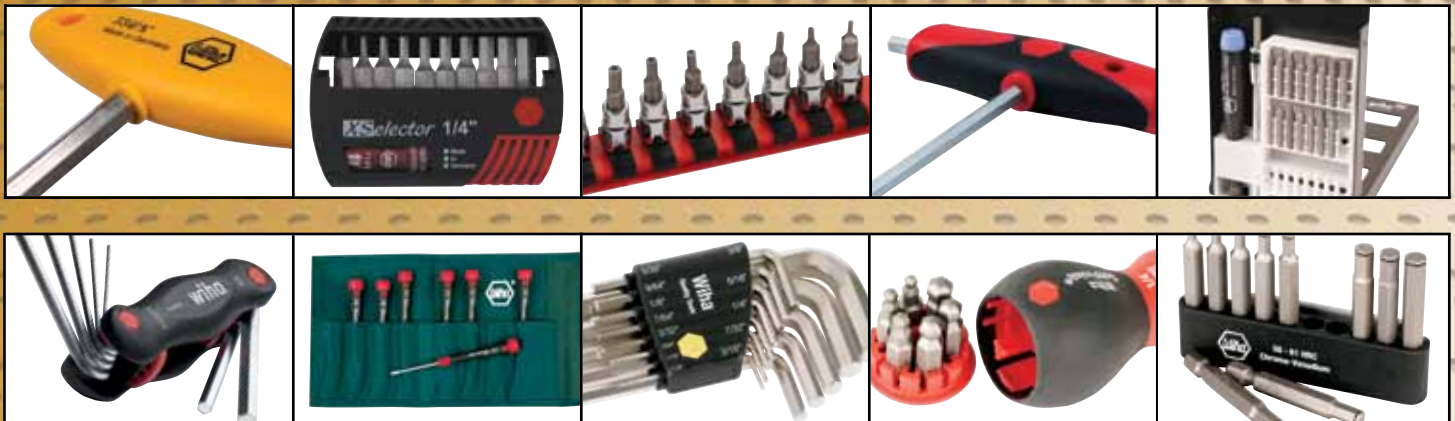

Wiha Quality Tools

1348 Dundas Circle
 Monticello, MN 55362
 tel: 763.295.6591
 fax: 763.295.6598

Wiha Tools Canada Ltd.

www.wihatools.ca
 Brampton, ONT L6T 4X4
 tel: 866.494.0096 or 763.295.6591
 fax: 763.295.6598

To:

Catalog Item No. 99934.wo
 version - 5/15/13

Subject to change
 without notice

©2013 Willi Hahn Corporation




99060.wo - Product Guide



99004.wo - Shop Tools Catalog



99914.wo - TORX Catalog

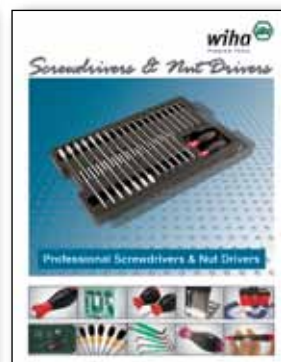

99002.wo - Screwdrivers Catalog



99919.wo - Insulated Catalog



99001.wo - TorqueControl Catalog



99951.wo - Bits Catalog



99006.wo - Tech Tools Catalog



99945.wo - ESD Catalog



99977.wo - Pliers/Crimpers Catalog