

# SPECIFICATION

# Commercial MIL-DTL-5015

A new range of high reliability, rugged, RoHS-compliant Circular Connectors released by Harwin to meet the high standards of MIL-DTL-5015, yet priced to be cost-effective for commercial and industrial applications.

Designed for use in harsh and demanding environments, the high specification, cadmium- and hexavalent chromium-free range features free plug, panel mount and cable connector orientations in a number of popular shell and layout options.

### Features

- ❖ Intermateable with MIL-DTL-5015
- ❖ Low cost, highly durable & rugged connector system
- ❖ Solder termination
- ❖ Full environmental sealing with the use of backshells and sealing gaskets, exceeds IP-67

- ❖ Threaded and polarised coupling
- ❖ Zinc & Black Chromate-plated shells
- ❖ COTS applications where MIL Spec is not mandatory

### Materials

|                     |  |
|---------------------|--|
| Outer Shell:        | Aluminium Alloy, Zinc with Black Chromate finish |
| Inner Contacts:     | Copper Alloy, Silver finish                      |
| Insulator, Grommet: | Polychloroprene                                  |

### Environmental

|                             |   |
|-----------------------------|---|
| Operating Temperature:      | -55°C to +125°C                             |
| Vibration sensitivity:      | 10Hz to 500Hz,<br>98mm/s <sup>2</sup> (10G) |
| Shock severity:             | 490m/s <sup>2</sup> (50G) for 11ms          |
| Water Resistance (sealing): | 1.8m for 48 hours<br>- exceeds IP67         |

### Electrical

|                        |  |
|------------------------|--|
| Current Rating:        | 13A  |
| Voltage Rating:        | 10SL shell: 500V AC, 700V DC<br>12S shell: 500V AC, 700V DC<br>14S shell: 200V AC, 250V DC |
| Voltage proof:         | 10SL shell: 2,000V AC<br>12S shell: 2,000V AC<br>14S shell: 1,000V AC                      |
| Insulation Resistance: | 5,000 MΩ min.  |

### Mechanical

|             |                |
|-------------|----------------|
| Durability: | 500 operations |
| Wire size:  | 16 to 22 AWG   |

All preferred sizes of this range are held in stock. Check [www.harwin.com](http://www.harwin.com) for availability.

## HOW TO ORDER

**C90 - 310X# XXXX-X X**

### SERIES CODE

### TYPE

|              |                                   |
|--------------|-----------------------------------|
| <b>3101F</b> | Cable connector with backshell    |
| <b>3102R</b> | Panel mount connector with gasket |
| <b>3106F</b> | Straight plug with backshell      |

### CONTACT GENDER


|          |        |
|----------|--------|
| <b>P</b> | Male   |
| <b>S</b> | Female |

### SHELL SIZE

|               |                               |
|---------------|-------------------------------|
| <b>10SL-3</b> | Thread 5/8-24UNEF, 3 contacts |
| <b>10SL-4</b> | Thread 5/8-24UNEF, 2 contacts |
| <b>12S-3</b>  | Thread 3/4-20UNEF, 2 contacts |
| <b>14S-2</b>  | Thread 7/8-20UNEF, 4 contacts |
| <b>14S-6</b>  | Thread 7/8-20UNEF, 6 contacts |

## CONTACT CONFIGURATION

Contact numbering is shown looking onto the mating face of the male connector.

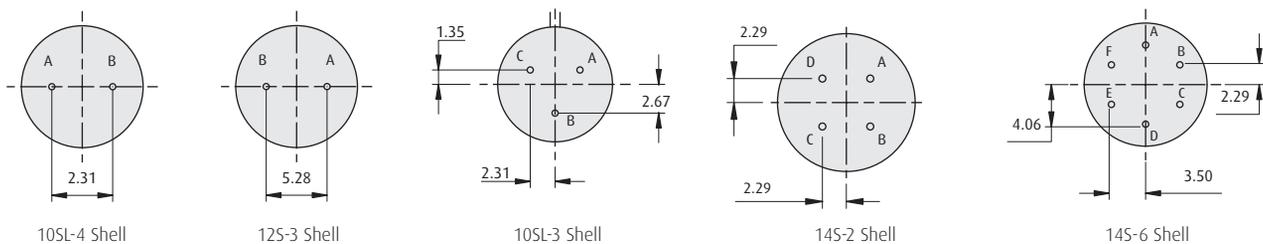

[www.harwin.com](http://www.harwin.com)

All dimensions in mm.



# HARWIN


# Commercial MIL-DTL-5015

## Cable Connector & Straight Plug


- ❖ Male & Female Circular Connectors intermateable with MIL-DTL-5015.
- ❖ Rugged connector system for harsh environments.
- ❖ Cable assembly service available.
- ❖ Exceeds IP-67.



### CABLE CONNECTOR

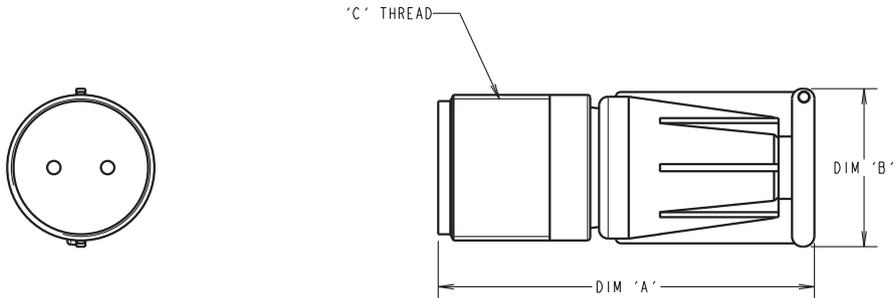

### STRAIGHT PLUG

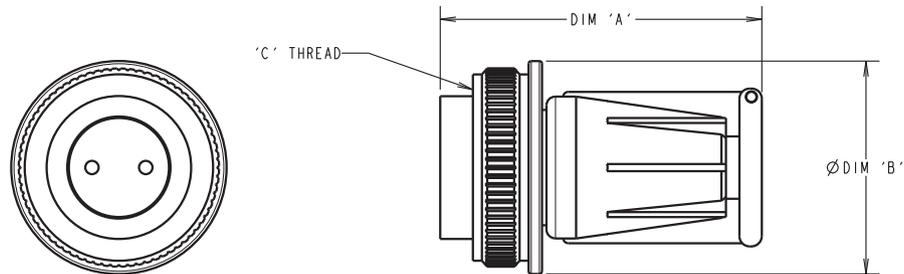

### CALCULATION

| SHELL SIZE    | THREAD*          | DIMENSION |        |         |        |         |         |
|---------------|------------------|-----------|--------|---------|--------|---------|---------|
|               |                  | ØA max.   | B max. | ØC min. | D max. | ØE max. | ØF min. |
| <b>10SL-3</b> | 5/8-24UNEF-2A/2B | 24.61     | 16.66  | 11.38   | 24.61  | 24.61   | 11.33   |
| <b>10SL-4</b> | 5/8-24UNEF-2A/2B | 24.61     | 16.66  | 11.38   | 22.20  | 24.61   | 11.33   |
| <b>12S-3</b>  | 3/4-20UNEF-2A/2B | 26.97     | 19.43  | 14.15   | 22.70  | 26.97   | 14.10   |
| <b>14S-2</b>  | 7/8-20UNEF-2A/2B | 29.63     | 22.60  | 17.32   | 27.00  | 29.36   | 17.15   |
| <b>14S-6</b>  | 7/8-20UNEF-2A/2B | 29.63     | 22.60  | 17.32   | 27.00  | 29.36   | 17.15   |

\*2A class for external threads, 2B class for internal threads

All dimensions in mm.

[www.harwin.com](http://www.harwin.com)







# Commercial MIL-DTL-5015



## Panel Mount Connector, Receptacle Style

- ❖ Male & Female Circular Connectors intermateable with MIL-DTL-5015.
- ❖ Features screw holes for panel mounting.
- ❖ Gaskets provide additional sealing.
- ❖ 13A power.

### MALE

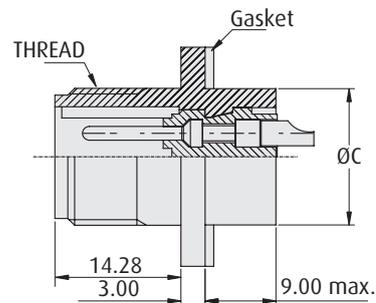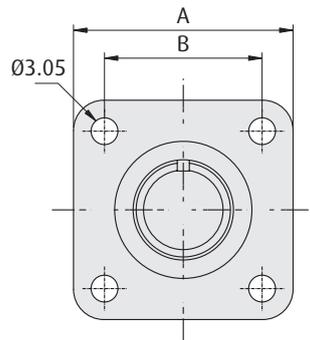

### FEMALE

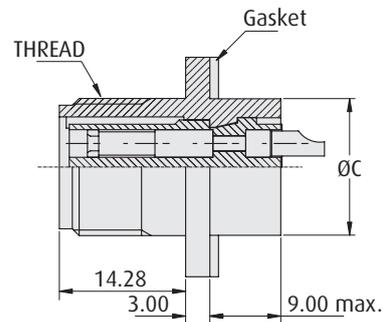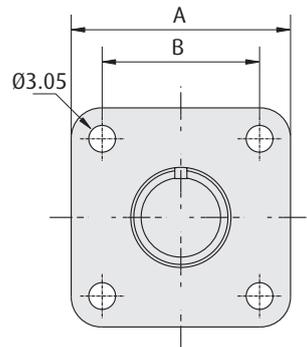

### CALCULATION

| SHELL SIZE    | THREAD        | DIMENSION |         |        |
|---------------|---------------|-----------|---------|--------|
|               |               | A ±0.79   | B ±0.12 | C max. |
| <b>10SL-3</b> | 5/8-24UNEF-2A | 25.40     | 18.26   | 19.35  |
| <b>10SL-4</b> | 5/8-24UNEF-2A | 25.40     | 18.26   | 19.35  |
| <b>12S-3</b>  | 3/4-20UNEF-2A | 27.79     | 20.62   | 19.86  |
| <b>14S-2</b>  | 7/8-20UNEF-2A | 30.18     | 23.01   | 23.01  |
| <b>14S-6</b>  | 7/8-20UNEF-2A | 30.18     | 23.01   | 23.01  |

[www.harwin.com](http://www.harwin.com)

All dimensions in mm.



**HARWIN**

# Commercial MIL-DTL-5015


## Dust Caps & Rubber Bushing

- ❖ Dust cap with external thread for use with Straight Plugs (C90-3106F).
- ❖ Dust cap with internal thread for use with Cable connectors (C90-3101F) and Panel Mount connectors (C90-3102R).
- ❖ Dust caps supplied fitted with chain.
- ❖ Rubber Bushing for use with Cable connectors (C90-3101F) and Straight Plugs (C90-3106).




CIRCULAR CONNECTORS

### DUST CAP – EXTERNAL THREAD

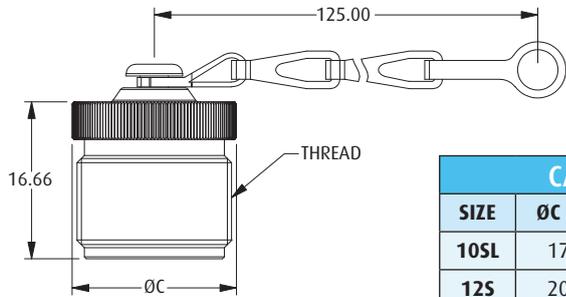


| CALCULATION |        |               |
|-------------|--------|---------------|
| SIZE        | ØC MAX | THREAD        |
| 10SL        | 17.45  | 5/8-24UNEF-2A |
| 12S         | 20.62  | 3/4-20UNEF-2A |
| 14S         | 23.8   | 7/8-20UNEF-2A |

### RUBBER BUSHING

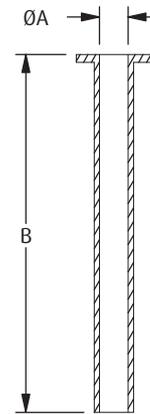

| CALCULATION |      |       |
|-------------|------|-------|
| SIZE        | ØA   | B     |
| 4           | 5.59 | 69.85 |
| 6           | 7.92 | 66.68 |

### DUST CAP – INTERNAL THREAD

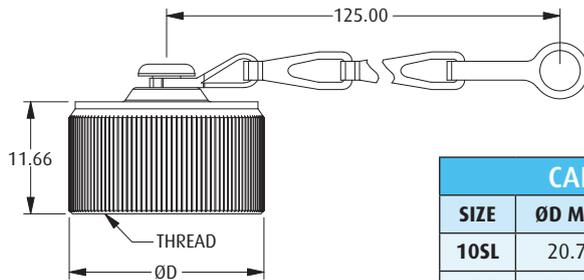

| CALCULATION |        |               |
|-------------|--------|---------------|
| SIZE        | ØD MAX | THREAD        |
| 10SL        | 20.70  | 5/8-24UNEF-2B |
| 12S         | 25.40  | 3/4-20UNEF-2B |
| 14S         | 28.58  | 7/8-20UNEF-2B |

### HOW TO ORDER

**C90 - XXXXX - XXXX**

SERIES CODE

TYPE

|       |                            |
|-------|----------------------------|
| 25042 | Dust Cap - External thread |
| 25043 | Dust Cap - Internal thread |
| 3420  | Rubber Bushing             |

SIZE

|      |   |
|------|---|
| 10SL | For use with 10SL shell size (Dust caps)      |
| 12S  | For use with 12S shell size (Dust caps)       |
| 14S  | For use with 14S shell size (Dust caps)       |
| 4    | For use with 10SL & 12S shell sizes (Bushing) |
| 6    | For use with 14S shell size (Bushing)         |

All dimensions in mm.

[www.harwin.com](http://www.harwin.com)

