



# Heyco® CPV Solar Bulkhead Connectors



With Integral Sealing Ring for Creating a Liquid Tight Seal Through a Panel



PART NO.	DESCRIPTION	PART DIMENSIONS							
		A		B		C		D	
Black		Max O.A.	Length	Mounted	Length	Wrenching	Flats	Clearance	Hole
		in.	mm.	in.	mm.	in.	mm.	in.	mm.
S6360	CPV-P-BH	2.08	52,8	1.47	37,3	.98	24,9	.875	22,2
S6362	CPV-N-BH	1.44	36,5	.83	21,0				



- Bulkhead connectors mate with Heyco CPV Solar Connectors creating a liquid tight seal through the panel.
- Provided with an assembled metal locknut.
- Integral sealing ring ensures a superior seal at the mounting hole location, every time.
- Crimp to stranded wire 14 to 10 gauge for internal connections.
- Polycarbonate construction for good chemical and impact resistance.
- Disconnection (PN S6390) and crimping tools (PN S6392 for 10 AWG wire and PN S6393 for 12 AWG wire) available. See page 1-5 & 1-6.
- RoHS and REACH compliant.
- UL recognized under File E344722.
- TUV certification No. R60033714.
- Patent pending.

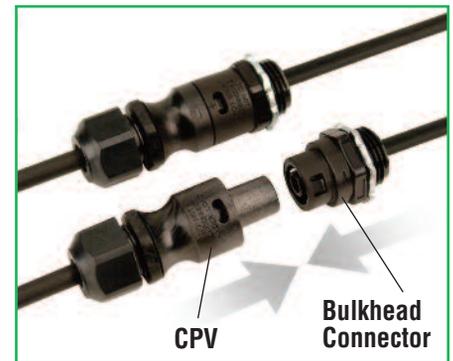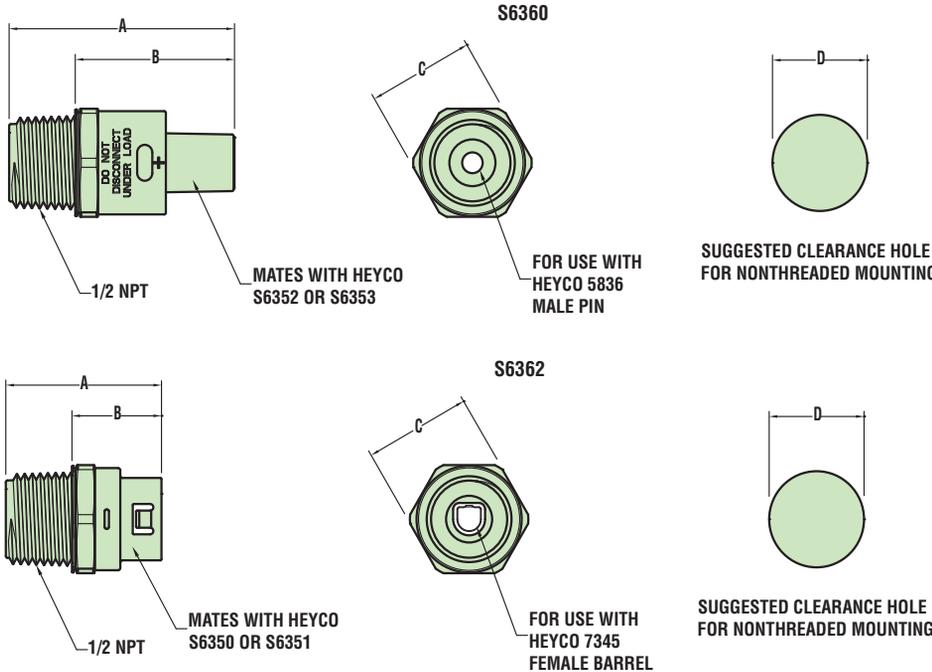

Material	Polycarbonate
Certifications	Recognized under the Component Program of Underwriters' Laboratories File E344722. Certification Number R60033714
Flammability Rating	VO
Temperature Rating	-40°F (-40°C) to 221°F (105°C)
IP Rating	IP 65 & IP 67

Quick Specs