

**ETA-USA**

HIGH QUALITY SWITCHING POWER SUPPLIES

CE DECLARATION OF CONFORMITY

US ETA Inc. dba ETA-USA; located at 16170 Vineyard Blvd Unit 180, Morgan Hill, CA. 95037 USA

Phone Number: +1-408-778-2793 Email: info@eta-usa.com

Declare that the DoC is issued under our sole responsibility and belongs to the following product.

Model No.**Description**

AOPS-15-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 15 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS -30-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 30 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-50-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 50 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-75-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 75 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-100-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 100 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-150-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 150 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-300-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 300 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-600-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 600 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-1000-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 1,000 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48
AOPS-1500-xx	AC/DC Power Supply, AC85~265VAC (DC 127~370V) input , rated at 1,500 watts maximum output power, to be installed inside of apparatus where xx can be 3.3, 5, 9, 12, 15, 24 or 48

Object of declaration**AC/DC power adapter in a black plastic enclosure matching the outline drawing below**

The following harmonized standards and technical specifications have been applied:

Image on Page 2

- EN 62368-1:2020+A11:2020
- EN 55022: 2010
- EN 55024: 2010

The object of the declaration is in conformity with the relevant Union harmonization legislation where applicable

- 2011/65/EU ROHS
- Low Voltage Directive (2014/35/EU)
- EU tier 2 Efficiency

ETA-USA
 16170 Vineyard Blvd. #180
 Morgan Hill, CA 95037
 Phone: (408) 778-2793 Fax: (408) 779-2753
 www.eta-usa.com



ETA-USA

HIGH QUALITY SWITCHING POWER SUPPLIES

Signed on Behalf of
ETA-USA, Morgan Hill, CA.95037
2/05/2020

Keon Safakish
Operations Manager

AOPS15



AOPS-75



AOPS100




AOPS150



AOPS-300



AOPS600

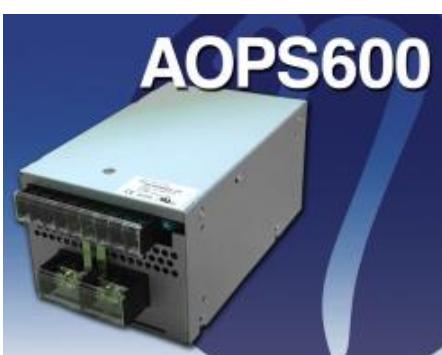

AOPS1000



ETA-USA

16170 Vineyard Blvd. #180

Morgan Hill, CA 95037

Phone: (408) 778-2793 Fax: (408) 779-2753

www.eta-usa.com