

Test Report



Report No. A224025207220100201

Page 1 of 4

Company Name GLOBAL CONNECTOR TECHNOLOGY LTD
Shown on Report
Address UNIT 301, 3RD FLOOR, BLOCK B, SEA VIEW ESTATE ,4-6 WATSON
ROAD, NORTH POINT, HK

The following sample(s) and sample information was/were submitted and identified by/on the behalf of the client

Sample Name USB Type C Receptacle, SMT Type, Top-mount, Horizontal 6Pin
Model No. USB4736-XX-A
Sample Receiving State Normal
Sample Received Date May 7, 2024
Testing Period May 7, 2024-May 13, 2024

Test Requested

No.	Test Item
1	IPX7

Test Result(s): Please see the following pages.

Approved by

Roger Xiao

Approved Signatory

Date

May 13, 2024

No. RE9E3B9E62

Centre Testing International Group Co., Ltd.

Hongwei Industrial Zone, Bao'an 70 District, Shenzhen, Guangdong, China



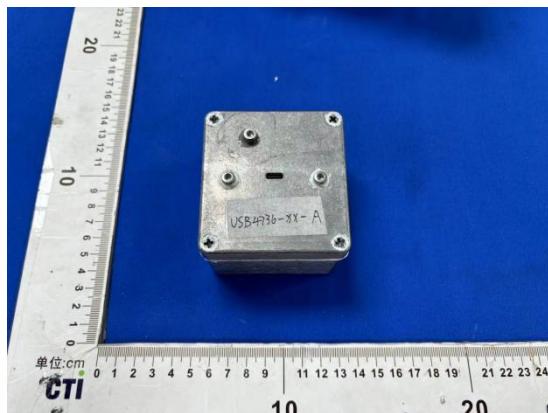
Test Report

Report No. A224025207220100201

Page 2 of 4

Tested Sample(s)

Sample No.	Sample Name	Type	Quantity
A2240252072201002	USB Type C Receptacle, SMT Type, Top-mount, Horizontal 6Pin	USB4736-XX-A	1pc

Sample Photo(s)

A2240252072201002

Test Report

Report No. A224025207220100201

Page 3 of 4

Test Item: IPX7**1. Test Equipment**

Equipment Name	Model
Waterproof grade testing machine	JX1040

2. Environmental Conditions

Temperature:26.1°C; Humidity:69%RH

3. Test Standard: IEC 60529:2013**4. Test Condition**

The lowest point of the sample is located 1000 mm below the surface of the water.

Test duration: 30min

5. Test Result(s)

Sample No.	Criterion	Test result (Visual inspection)	Conclusion
A2240252072201002	No water enters the sample	No water enters the sample	Pass

Sample Photo(s) after the test

A2240252072201002

Remark: The testing data and result(s) in this report is(are) just for scientific research, education, internal quality control and product development etc.

Test Report

Report No. A224025207220100201

Page 4 of 4

Statement:

1. This report is considered invalid without approved signature, special seal and the seal on the perforation;
2. Company Name and Address shown on Report, the sample(s) and sample Information was/were provided by the applicant who should be responsible for the authenticity which CTI hasn't verified;
3. The result(s) shown in this report refer(s) only to the sample(s) tested;
4. Without written approval of CTI, this report can't be reproduced except in full;
5. In case of any discrepancy between the English version and Chinese version of the testing reports(if generated), the Chinese version shall prevail.

*** End of Report ***

