

PHOENIX CONTACT DIN Rail Terminal Blocks

RoHS Compliant This page of product is RoHS compliant.

MT MICRO MINIATURE DIN RAIL TERMINAL BLOCKS

Micro DIN rail terminal block for NS 15 DIN Rail. Screw clamp connections.
• RoHS compliant per Phoenix documentation

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
MT Micro Miniature Feed-Thru DIN Rail Terminal Blocks														
651-3100305		A	MT 1.5	Gray	30-14	300	15A	23.5	22.0	4.2	2.69	2.58	2.38	2.27
651-3003363		A	MT 1.5 BU	Blue	30-14	300	15A	23.5	22.0	4.2	2.71	2.64	2.47	2.27
651-3001679		B	MT 1.5 QUATTRO	Gray	30-14	300	15A	30.0	33.5	4.2	5.19	4.98	4.60	4.34
651-3001682		C	MT 1.5 TWIN	Gray	30-14	300	15A	30.0	28.0	4.2	4.65	4.47	4.12	3.90
651-3025532		C	MT 1.5 TWIN BU	Blue	30-14	300	15A	30.0	28.0	4.2	4.65	4.47	4.12	3.90
651-1414129		D	MTTB 1.5	Gray	30-14	300	15A	41.0	44.0	4.2	6.64	6.46	6.04	5.55
MT Micro Miniature Ground DIN Rail Terminal Blocks														
651-3100318		-	MT 1.5 PE	Gr/Yel	30-14	-	-	23.5	22.0	4.2	8.42	8.08	7.45	7.12
651-3001695		-	MT 1.5 QUATTRO PE	Gr/Yel	30-14	-	-	30.0	28.0	4.2	12.52	12.18	11.39	10.47
651-3001705		-	MT 1.5 TWIN PE	Gr/Yel	30-14	-	-	30.0	33.5	4.2	11.26	10.95	10.24	9.42

Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Color	Description	Price Each			
Mfr.	Mfr. Part No.				1	10	50	100
651-3100321		D-MT 1.5	Gray	End Cover for MT 1.5	.78	.77	.719	.662
651-3025529		D-MT 1.5 BU	Blue	End Cover for MT 1.5 BU	.81	.792	.74	.681
651-3002982		D-MT 1.5 QUATTRO	Gray	End Cover for MT 1.5 QUATTRO	1.44	1.40	1.31	1.20
651-3002979		D-MT 1.5 TWIN	Gray	End Cover for MT 1.5 TWIN	1.36	1.32	1.24	1.14
651-3002678		DG-MTTB 1.5	Gray	Spacer Cover for MTTTB 1.5	1.59	1.55	1.45	1.33
651-3002665		D-MTTB 1.5	Gray	End Cover for MTTTB 1.5	1.32	1.28	1.20	1.10
651-3002681		DP-MTTB 1.5	Gray	Spacer Plate for MTTTB 1.5	1.48	1.44	1.35	1.24

MBK MINIATURE DIN RAIL TERMINAL BLOCKS

RoHS compliant per Phoenix documentation
The "larger" miniature terminal block for NS 15 DIN rail. Screw clamp connections.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
Feed-Thru														
651-1413036		E	MBK 3/E Z	Gray	28-12	600	20A	32.0	28.0	5.2	3.31	3.19	2.94	2.76
651-1402940		F	MBK 5/E Z	Gray	26-10	600	30A	32.0	28.0	6.2	3.19	3.10	2.89	2.66
651-1414064		G	MBKKB 2.5	Gray	30-12	300	20A	48.0	62.0	5.2	6.19	6.02	5.60	5.18
Ground														
651-1413117		-	MBK 3/E Z PE	Gr/Yel	28-12	-	-	31.5	28.0	5.2	7.64	7.34	6.77	6.41
651-0452043		-	MBK 5/E Z PE	Gr/Yel	26-10	-	-	32.0	28.0	5.2	7.52	7.21	6.65	6.65

Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Color	Description	Price Each			
Mfr.	Mfr. Part No.				1	10	50	100
651-1413227		ATP-MBK	Gray	Partition Plate	1.66	1.61	1.51	1.38
651-1415021		DMBK/E	Gray	End Cover for 3 and 5/ E Z	1.00	.974	.91	.837
651-1401158		EB 2-5 N	Red	2 Position Insertion Bridge	.98	.957	.93	.87
651-1401145		EB 3-5 N	Red	3 Position Insertion Bridge	1.43	1.38	1.34	1.26
651-1401132		EB 10-5 N	Red	10 Position Insertion Bridge	3.86	3.62	3.33	3.23
651-1413052		D-MBKKB 2.5	Gray	End Cover	1.27	1.24	1.16	1.06
651-1413065		DP-MBKKB 2.5	Gray	Spacer Plate	1.13	1.10	1.03	.948

OTTA BOLT CONNECTION DIN RAIL TERMINAL BLOCKS

Bolt connection terminal blocks for ring lug terminals. Unique hinged cover wings which hold the terminal nuts.
* Includes 4mm female test connector

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Phoenix Type	Color	Ring Lug Size	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
Feed-Thru														
651-0790530		H	OTTA 2.5	Gray	M3	600	20A	45.5	43.5	9.0	8.59	8.27	7.63	7.18
651-0790433		I	OTTA 6	Gray	M4	600	30A	52.0	43.5	9.0	7.21	7.01	6.51	6.03
* 651-0790462		J	OTTA 6-T-P/P	Gray	M4	600	30A	52.0	69.0	11.0	17.51	16.97	15.63	14.29
Ground														
651-0790556		-	OTTA 2.5 PE	Gr/Yel	M3	-	-	45.5	43.5	9.0	18.38	17.46	16.08	14.70
651-0790527		-	OTTA 6 PE	Gr/Yel	M4	-	-	52.0	43.5	11.0	20.32	18.71	17.11	16.04

End Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Color	Description	Price Each			
Mfr.	Mfr. Part No.				1	10	50	100
651-0790569		D-OTTA 2.5	Gray	End Cover for OTTA 2.5	1.80	1.75	1.64	1.50
651-0790417		D-OTTA 6	Gray	End Cover for OTTA 6	1.68	1.63	1.53	1.40
651-0790459		D-OTTA 6-T	Gray	End Cover for OTTA 6-T	1.68	1.63	1.53	1.40

MTK KNIFE DISCONNECT DIN RAIL TERMINAL BLOCKS

** Feed-through terminal block without knife disconnect
• RoHS Compliant per Phoenix documentation.


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
651-3101016		K	MTK	Gray	28-12	300	10A	51.5	46	5.2	8.72	8.37	8.01	7.37
651-3104013		K	MTK-P/P	Gray	28-12	300	10A	51.5	46	5.2	9.77	9.51	8.89	8.17
** 651-3100017		L	MTKD	Gray	28-12	300	10A	51.5	46	5.2	4.90	4.81	4.50	4.14
651-3004032		M	UK 5-MTK-P/P	Gray	22-12	600	15A	58.5	51	6.2	11.63	11.16	10.28	9.73
651-2775210		N	UDK 4-MTK-P/P	Gray	22-10	600	10A	47	63.5	6.2	11.46	11.00	10.13	9.58
651-2800004		O	UKK 5-MTK-P/P	Gray	26-12	300	15A	68	80	6.2	17.23	16.76	15.67	14.41

Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Color	Description	Price Each			
Mfr.	Mfr. Part No.				1	10	50	100
651-3101029		D-MTK	Gray	End Cover for MTK	1.28	1.23	1.13	1.09
651-3101223		ATS-MTK	Gray	Partition Plate for MTK	1.48	1.44	1.35	1.24
651-3004210		ATP-UK 5-MTK	Gray	Partition Plate for UK 5-MTK	1.64	1.60	1.50	1.38
651-2775113		D-UDK 4	Gray	End Cover for UDK 4-MTK	1.91	1.86	1.74	1.60
651-3100266		TP-UDMTK 5	Gray	Partition Plate for UDMTK 5	1.41	1.33	1.22	1.18

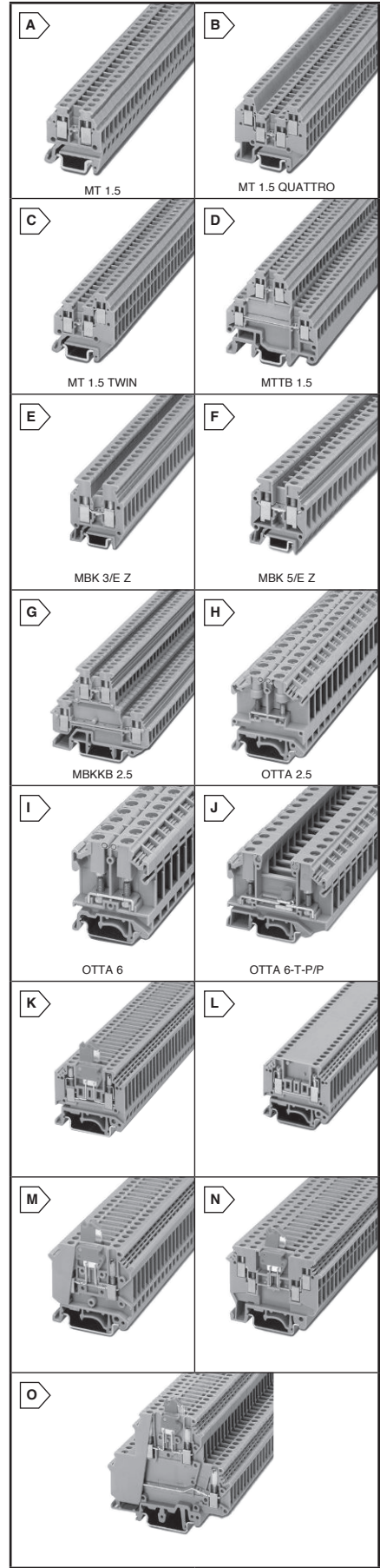

Terminal Blocks Phoenix Contact