

NICHICON Aluminum Electrolytic Capacitors



nichicon UVR 85°C GENERAL PURPOSE SERIES

Specifications:

- Operating temperature range: -40°C ~ +85°C (6.3 ~ 400V), -25°C ~ +85°C (450V)
- Voltage range: 6.3 ~ 450V
- Capacitance range: 0.1 ~ 33000µF
- Capacitance tolerance: ±20% at 120Hz, 20°C
- Endurance: 2000 hours @ 85°C

Application note:


- A higher voltage capacitor may be used in a lower voltage application.



LEAD-FREE



RoHS Compliant

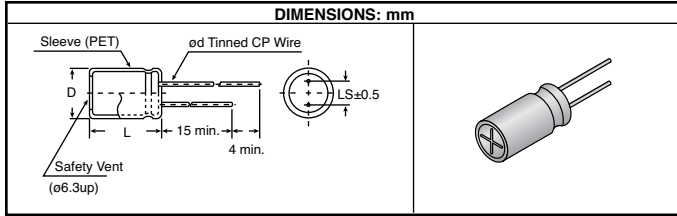

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Nichicon Part No.	Value (µF)	Case Size D x L (mm) Max.	LS (mm)	Price Each			
					1	10	100	500
6.3 Volt								
647-UVR0J101MDD	UVR0J101MDD	100	5 x 11	2.0				
647-UVR0J221MDD	UVR0J221MDD	220	5 x 11	2.0				
647-UVR0J331MED	UVR0J331MED	330	6.3 x 11	2.5				
647-UVR0J471MED	UVR0J471MED	470	6.3 x 11	2.5				
647-UVR0J102MPD	UVR0J102MPD	1000	8 x 11.5	3.5				
647-UVR0J222MPD	UVR0J222MPD	2200	10 x 20	5.0				
647-UVR0J332MPD	UVR0J332MPD	3300	10 x 20	5.0				
647-UVR0J682MHD	UVR0J682MHD	6800	12.5 x 25	5.0				
647-UVR0J103MHD	UVR0J103MHD	10000	16 x 25	7.5				
647-UVR0J153MHD	UVR0J153MHD	15000	16 x 35.5	7.5				
647-UVR0J223MHD	UVR0J223MHD	22000	18 x 40	7.5				
10 Volt								
647-UVR1A101MDD	UVR1A101MDD	100	5 x 11	2.0				
647-UVR1A221MED	UVR1A221MED	220	6.3 x 11	2.5				
647-UVR1A331MED	UVR1A331MED	330	6.3 x 11	2.5				
647-UVR1A471MED	UVR1A471MED	470	6.3 x 11	2.5				
647-UVR1A102MPD	UVR1A102MPD	1000	10 x 12.5	5.0				
647-UVR1A222MPD	UVR1A222MPD	2200	10 x 20	5.0				
647-UVR1A332MHD	UVR1A332MHD	3300	12.5 x 20	5.0				
647-UVR1A472MHD	UVR1A472MHD	4700	12.5 x 25	5.0				
647-UVR1A682MHD	UVR1A682MHD	6800	16 x 25	7.5				
647-UVR1A103MHD	UVR1A103MHD	10000	16 x 35.5	7.5				
647-UVR1A153MHD	UVR1A153MHD	15000	18 x 35.5	7.5				
16 Volt								
647-UVR1C100MDD	UVR1C100MDD	10	5 x 11	2.0				
647-UVR1C220MDD	UVR1C220MDD	22	5 x 11	2.0				
647-UVR1C330MDD	UVR1C330MDD	33	5 x 11	2.0				
647-UVR1C470MDD	UVR1C470MDD	47	5 x 11	2.0				
647-UVR1C101MDD	UVR1C101MDD	100	5 x 11	2.0				
647-UVR1C221MED	UVR1C221MED	220	6.3 x 11	2.5				
647-UVR1C331MPD	UVR1C331MPD	330	8 x 11.5	3.5				
647-UVR1C471MPD	UVR1C471MPD	470	8 x 11.5	3.5				
647-UVR1C102MPD	UVR1C102MPD	1000	10 x 16	5.0				
647-UVR1C222MHD	UVR1C222MHD	2200	12.5 x 20	5.0				
647-UVR1C332MHD	UVR1C332MHD	3300	12.5 x 25	5.0				
647-UVR1C472MHD	UVR1C472MHD	4700	16 x 25	7.5				
647-UVR1C682MHD	UVR1C682MHD	6800	16 x 35.5	7.5				
647-UVR1C103MHD	UVR1C103MHD	10000	18 x 35.5	7.5				
25 Volt								
647-UVR1E100MDD	UVR1E100MDD	10	5 x 11	2.0				
647-UVR1E220MDD	UVR1E220MDD	22	5 x 11	2.0				
647-UVR1E330MDD	UVR1E330MDD	33	5 x 11	2.0				
647-UVR1E470MDD	UVR1E470MDD	47	5 x 11	2.0				
647-UVR1E101MED	UVR1E101MED	100	6.3 x 11	2.5				
647-UVR1E221MPD	UVR1E221MPD	220	8 x 11.5	3.5				
647-UVR1E331MPD	UVR1E331MPD	330	10 x 12.5	5.0				
647-UVR1E471MPD	UVR1E471MPD	470	10 x 12.5	5.0				
647-UVR1E102MPD	UVR1E102MPD	1000	10 x 20	5.0				
647-UVR1E222MHD	UVR1E222MHD	2200	12.5 x 25	5.0				
647-UVR1E332MHD	UVR1E332MHD	3300	16 x 25	7.5				
647-UVR1E472MHD	UVR1E472MHD	4700	16 x 31.5	7.5				
647-UVR1E682MHD	UVR1E682MHD	6800	18 x 35.5	7.5				
35 Volt								
647-UVR1V100MDD	UVR1V100MDD	10	5 x 11	2.0				
647-UVR1V220MDD	UVR1V220MDD	22	5 x 11	2.0				
647-UVR1V330MDD	UVR1V330MDD	33	5 x 11	2.0				
647-UVR1V470MDD	UVR1V470MDD	47	5 x 11	2.0				
647-UVR1V101MED	UVR1V101MED	100	6.3 x 11	2.5				
647-UVR1V221MPD	UVR1V221MPD	220	10 x 12.5	5.0				
647-UVR1V331MPD	UVR1V331MPD	330	10 x 12.5	5.0				
647-UVR1V471MPD	UVR1V471MPD	470	10 x 16	5.0				
647-UVR1V102MHD	UVR1V102MHD	1000	12.5 x 20	5.0				
647-UVR1V222MHD	UVR1V222MHD	2200	16 x 25	7.5				
647-UVR1V332MHD	UVR1V332MHD	3300	16 x 35.5	7.5				
647-UVR1V472MHD	UVR1V472MHD	4700	18 x 35.5	7.5				
50 Volt								
647-UVR1HR33MDD	UVR1HR33MDD	0.33	5 x 11	2.0				
647-UVR1HR47MDD	UVR1HR47MDD	0.47	5 x 11	2.0				
647-UVR1H010MDD	UVR1H010MDD	1.0	5 x 11	2.0				
647-UVR1H2R2MDD	UVR1H2R2MDD	2.2	5 x 11	2.0				
647-UVR1H3R3MDD	UVR1H3R3MDD	3.3	5 x 11	2.0				
647-UVR1H4R7MDD	UVR1H4R7MDD	4.7	5 x 11	2.0				
647-UVR1H100MDD	UVR1H100MDD	10	5 x 11	2.0				
647-UVR1H220MDD	UVR1H220MDD	22	5 x 11	2.0				
647-UVR1H330MDD	UVR1H330MDD	33	5 x 11	2.0				
647-UVR1H470MED	UVR1H470MED	47	6.3 x 11	2.5				
647-UVR1H101MPD	UVR1H101MPD	100	8 x 11.5	3.5				

Leakage Current:

6.3V ~ 100V	160V ~ 450V
After 1 minute application of rated voltage, leakage current is not more than 0.03CV or 4 (µA), whichever is greater.	After 1 minute application of rated voltage, CV ≤ 1000: I = 0.1CV + 40µA or less.
After 2 minutes application of rated voltage, leakage current is not more than 0.01CV or 3 (µA), whichever is greater.	After 1 minutes application of rated voltage, CV > 1000: I = 0.04CV + 100µA or less.

For quantities of 1000 and up, call for quote.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Nichicon Part No.	Value (µF)	Case Size D x L (mm) Max.	LS (mm)	Price Each			
					1	10	100	500
50 Volt (cont.)								
647-UVR1H221MPD	UVR1H221MPD	220	10 x 12.5	5.0				
647-UVR1H331MPD	UVR1H331MPD	330	10 x 16	5.0				
647-UVR1H471MHD	UVR1H471MHD	470	12.5 x 20	5.0				
647-UVR1H102MHD	UVR1H102MHD	1000	12.5 x 25	5.0				
647-UVR1H222MHD	UVR1H222MHD	2200	16 x 35.5	7.5				
647-UVR1H332MHD	UVR1H332MHD	3300	18 x 35.5	7.5				
63 Volt								
647-UVR1J100MDD	UVR1J100MDD	10	5 x 11	2.0				
647-UVR1J220MDD	UVR1J220MDD	22	5 x 11	2.0				
647-UVR1J330MED	UVR1J330MED	33	6.3 x 11	2.5				
647-UVR1J470MED	UVR1J470MED	47	6.3 x 11	2.5				
647-UVR1J101MPD	UVR1J101MPD	100	10 x 12.5	5.0				
647-UVR1J221MPD	UVR1J221MPD	220	10 x 16	5.0				
647-UVR1J331MPD	UVR1J331MPD	330	10 x 20	5.0				
647-UVR1J471MHD	UVR1J471MHD	470	12.5 x 20	5.0				
647-UVR1J102MHD	UVR1J102MHD	1000	16 x 25	7.5				
647-UVR1J222MHD	UVR1J222MHD	2200	18 x 35.5	7.5				
100 Volt								
647-UVR2A0R1MDD	UVR2A0R1MDD	0.1	5 x 11	2.0				
647-UVR2AR33MDD	UVR2AR33MDD	0.33	5 x 11	2.0				
647-UVR2AR47MDD	UVR2AR47MDD	0.47	5 x 11	2.0				
647-UVR2A010MDD	UVR2A010MDD	1.0	5 x 11	2.0				
647-UVR2A2R2MDD	UVR2A2R2MDD	2.2	5 x 11	2.0				
647-UVR2A3R3MDD	UVR2A3R3MDD	3.3	5 x 11	2.0				
647-UVR2A4R7MDD	UVR2A4R7MDD	4.7	5 x 11	2.0				
647-UVR2A100MED	UVR2A100MED	10	6.3 x 11	2.5				
647-UVR2A220MED	UVR2A220MED	22	6.3 x 11	2.5				
647-UVR2A330MPD	UVR2A330MPD	33	8 x 11.5	3.5				
647-UVR2A470MPD	UVR2A470MPD	47	10 x 12.5	5.0				
647-UVR2A101MPD	UVR2A101MPD	100	10 x 20	5.0				
647-UVR2A221MHD	UVR2A221MHD	220	12.5 x 25	5.0				
647-UVR2A331MHD	UVR2A331MHD	330	12.5 x 25	5.0				
647-UVR2A471MHD	UVR2A471MHD	470	16 x 25	7.5				
647-UVR2A102MHD	UVR2A102MHD	1000	18 x 40	7.5				
160 Volt								
647-UVR2C010MED	UVR2C010MED	1.0	6.3 x 11	2.5				
647-UVR2C4R7MED	UVR2C4R7MED	4.7	6.3 x 11	2.5				
647-UVR2C100MPD	UVR2C100MPD	10	8 x 11.5	3.5				
647-UVR2C220MPD	UVR2C220MPD	22	10 x 16	5.0				
647-UVR2C330MPD	UVR2C330MPD	33	10 x 20	5.0				
647-UVR2C470MHD	UVR2C470MHD	47	12.5 x 20	5.0				
647-UVR2C101MHD	UVR2C101MHD	100	12.5 x 25	5.0				
647-UVR2C221MHD	UVR2C221MHD	220	16 x 35.5	7.5				
647-UVR2C331MHD	UVR2C331MHD	330	18 x 40	7.5				
647-UVR2C471MRD	UVR2C471MRD	470	22 x 40	10.0				
250 Volt								
647-UVR2E010MED	UVR2E010MED	1.0	6.3 x 11	2.5				
647-UVR2E2R2MED	UVR2E2R2MED	2.2	6.3 x 11	2.5				
647-UVR2E3R3MPD	UVR2E3R3MPD	3.3	8 x 11.5	3.5				
647-UVR2E4R7MPD	UVR2E4R7MPD	4.7	8 x 11.5	3.5				
647-UVR2E100MPD	UVR2E100MPD	10	10 x 16	5.0				
647-UVR2E220MHD	UVR2E220MHD	22	12.5 x 20	5.0				
647-UVR2E330MHD	UVR2E330MHD	33	12.5 x 20	5.0				
647-UVR2E470MHD	UVR2E470MHD	47	12.5 x 25	5.0				
647-UVR2E101MHD	UVR2E101MHD	100	16 x 31.5	7.5				
647-UVR2E221MRD	UVR2E221MRD	220	20 x 40	10.0				
350 Volt								
647-UVR2V010MED	UVR2V010MED	1.0	6.3 x 11	2.5				
647-UVR2V2R2MPD	UVR2V2R2MPD	2.2	8 x 11.5	3.5				
647-UVR2V3R3MPD	UVR2V3R3MPD	3.3	10 x 12.5	5.0				
647-UVR2V4R7MPD	UVR2V4R7MPD	4.7	10 x 12.5	5.0				
647-UVR2V100MPD	UVR2V100MPD	10	10 x 20	5.0				
647-UVR2V220MHD	UVR2V220MHD	22	12.5 x 25	5.0				
647-UVR2V330MHD	UVR2V330MHD	33	16 x 25	7.5				
647-UVR2V470MHD	UVR2V470MHD	47	16 x 35.5	7.5				
647-UVR2V101MHD	UVR2V101MHD	100	18 x 40	7.5				