

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0529961370](#)
Status: **Active**
Overview: [ffc_fpc_smt](#)
Description: 1.00mm (.039") Pitch FFC/FPC Connector, Right Angle, SMT, ZIF, Top Contact Style, 13 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)

[Product Specification PS-52996-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	FFC/FPC Connectors
Series	52996
Overview	ffc_fpc_smt
Product Name	N/A

Physical

Circuits (Loaded)	13
Circuits (maximum)	13
Contact Position	Top
Durability (mating cycles max)	30
Entry Angle	90° Angle
Mated Height	2.70mm (.106")
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
PCB Thickness - Recommended	0.80mm (.031")
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.00mm (.039")
Pitch - Termination Interface	1.00mm (.039")
Plating min - Mating	1.016µm (40µ")
Plating min - Termination	1.016µm (40µ")
Polarized to PCB	No
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-20°C to +85°C
Termination Interface: Style	Surface Mount
Wire/Cable Type	FPC only

Electrical

Current - Maximum per Contact	1A
Voltage - Maximum	125V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Product Specification	PS-52996-001, RPS-52996-001
Sales Drawing	SD-52996-001, SD-52996-002

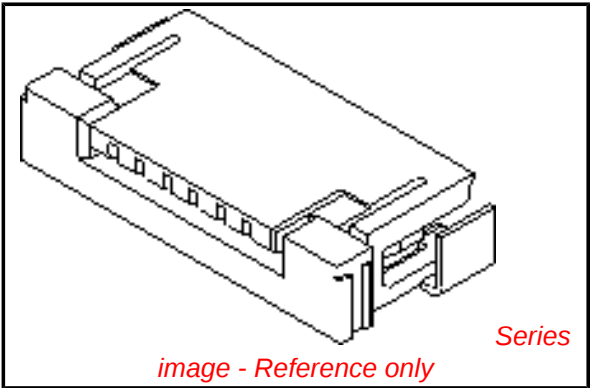


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series
[52996Series](#)