


DIMENSIONS: mm

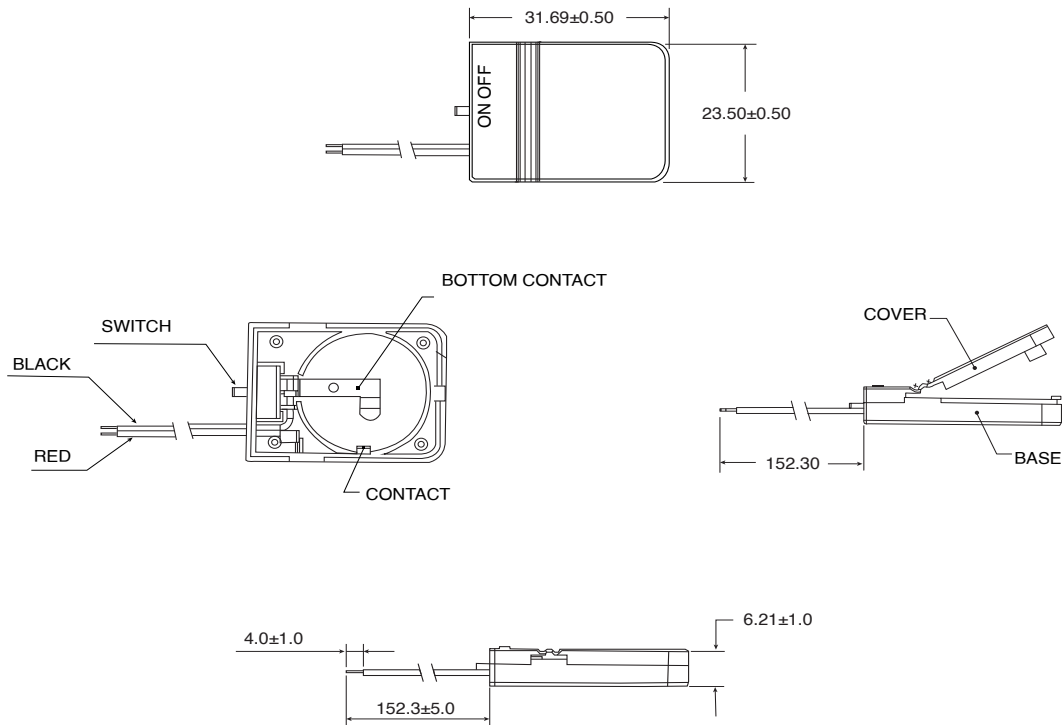

SPECIFICATIONS	
Description:	ENCLOSURE FOR SINGLE SIZE 2032
Wire :	UL1007 AWG 26
Black & Red :	152.3mm±5mm
Strip & Tin :	4mm±1mm
Holder Material :	PP RESIN, BLACK COLOR
Contact Material :	0.15mm PHOSPHOR BRONZE NICKEL PLATED
Battery Size/Type :	CR2032
No. of Cell Compartments :	1
RoHS Complaint	