

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731130104](#)
Status: **Active**
Description: HPD High-Density D-Sub Receptacle Housing, Crimp, Front or Rear Panel Mount, 62 Circuits

Documents:
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family D-Sub Products
Series [173113](#)
Exclude SD Check Yes
IP Rating IP20
Product Category Receptacle
Product Literature Order No 987651-6881
Product Name HPD
Type High Density
UPC 889056614832

Physical
Circuits (Loaded) 0
Circuits (maximum) 62
Color - Resin Black
Gender Female
Lock to Mating Part No
Material - Frame Tin-plated Steel
Material - Resin Thermoplastic
Net Weight 9.700/g
Number of Rows 3
Packaging Type Carton
Panel Mount Front or Rear
Panel Mount Method Flange
Pitch - Mating Interface 1.98mm
Pitch - Termination Interface 1.98mm
Polarized to Mating Part Yes
Ports 1
Shielded Yes
Waterproof / Dustproof No
Waterproof / Dustproof Type IP20

Electrical
Current - Maximum per Contact 5.0A

Material Info
Engineering Number FL37-62S7

Reference - Drawing Numbers
Sales Drawing 1731090036-000

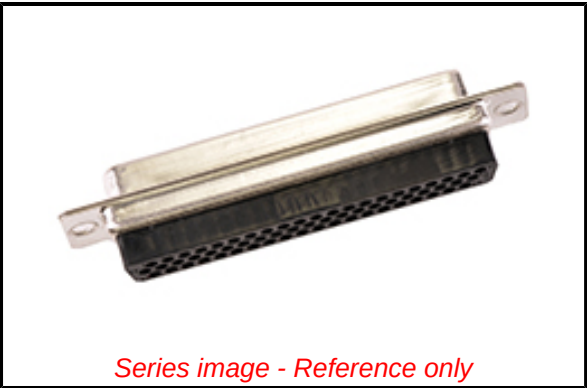

EU ELV
Not Reviewed

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[173113](#) Series

Mates With
D-sub, Size 4, 62 position, Plug

Use With
HPD High-Density Female Crimp Contacts
[1731120226](#) , [1731120227](#) , [1731120228](#)