


DIALIGHT PART NUMBER	V <sub>F</sub> (V)		I <sub>F</sub> (mA)		LED COLOR	LED EPOXY COLOR	LED CHIP	PEAK WAVELENGTH (nm)	LUMINOUS INTENSITY I <sub>v</sub> (mcd)		DIM "A"	7-DIGIT PART NO.
	TYP	MAX	TYP	MAX					MIN	TYP		
558-0201-810F	2.1	3.0	10*	25	GREEN	GREEN DIFF.	GaP	563	5.6	16.0	.111	558-0201

REV	ECN NO	REVISIONS	DRN	CKD	APP	DATE
A	—	NEW RELEASE	JTD	MES	NO	1-4-12

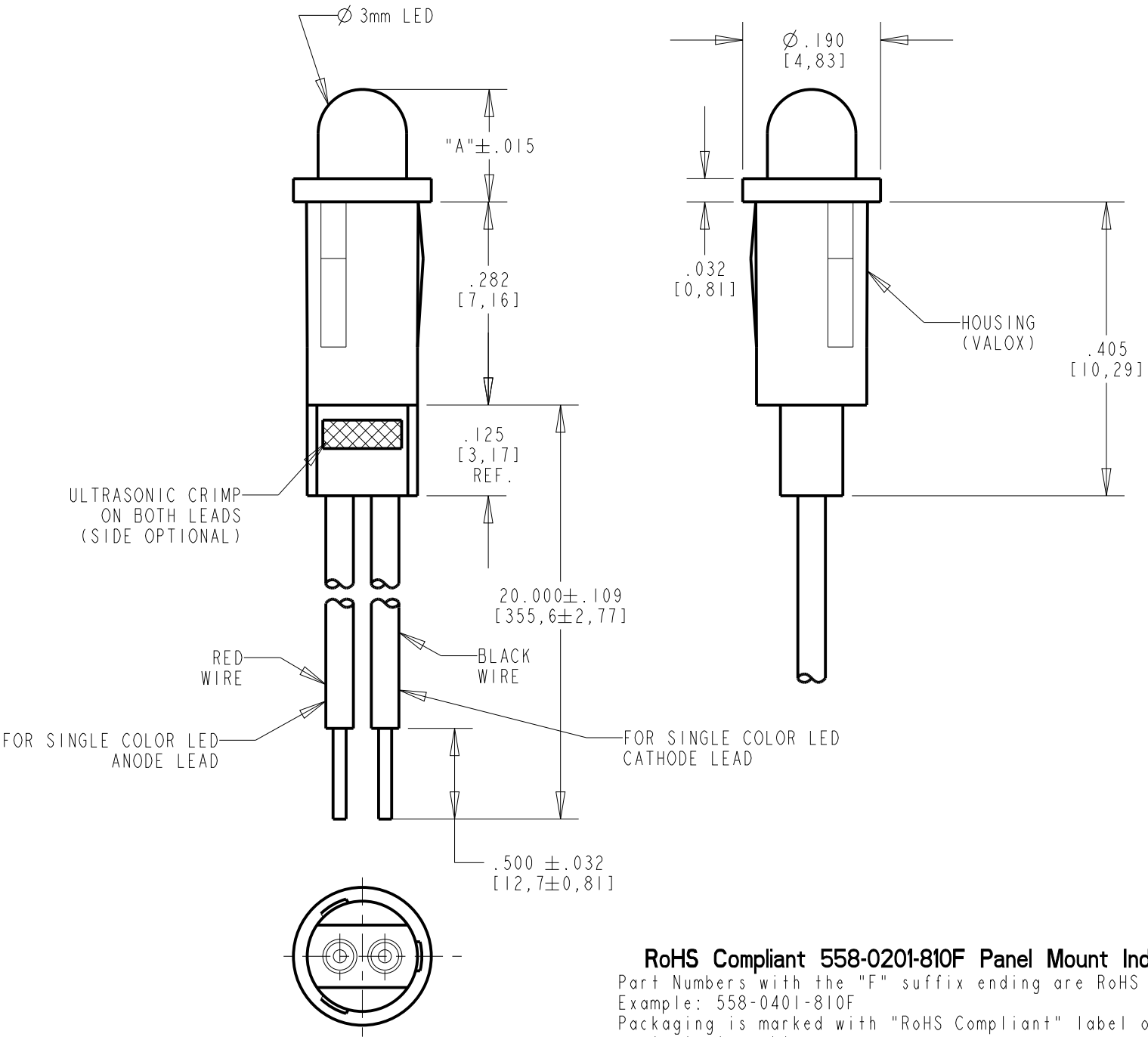

**RoHS Compliant 558-0201-810F Panel Mount Indicator**  
Part Numbers with the "F" suffix ending are RoHS Compliant.  
Example: 558-0401-810F  
Packaging is marked with "RoHS Compliant" label or equivalent markings.

- NOTES:
- \* REQUIRES EXTERNAL RESISTOR.
  - LEAD WIRES: AWG #26 PRE-TINNED, STRANDED.
  - RECOMMENDED MOUNTING HOLE: .155/.158 DIA. ON PANELS .031 THRU .062 THICK.
  - THIS ASSEMBLY CONTAINS ELECTROSTATIC DISCHARGE SENSITIVE DEVICES (ESDS). MAINTAIN ALL PRECAUTIONARY MEASURES DURING ASSEMBLY, HANDLING AND STORAGE IN ACCORDANCE WITH IPC-A-610.
  - DIALIGHT PART NUMBERS: 558-XXXX-810F.



**ATTENTION:**  
**OBSERVE PRECAUTIONS FOR**  
**HANDLING ELECTROSTATIC**  
**SENSITIVE DEVICES**

THIS DRAWING AND THE CONTENTS HEREIN ARE CONFIDENTIAL AND THE SOLE PROPERTY OF DIALIGHT. REPRODUCTION OF THIS DRAWING OR CONSTRUCTION OF ANY PARTS WITHIN THIS DRAWING ARE FORBIDDEN WITHOUT THE WRITTEN CONSENT OF DIALIGHT.		
SCALE: DRAWING SCALE	DRAWING NUMBER	REV
ALL DIM'S IN: INCHES (MM)	C-17948	A
TOLERANCES: UNLESS OTHERWISE SPECIFIED	TITLE .156" MOUNTING HOLE, SNAP-IN	
FRACTIONS: ±1/64	PMI, RoHS COMPLIANT	
DECIMALS (.XX): ±.02	MATERIAL	
DECIMALS (.XXX): ±.015		
ANGLES: ±1°		
FINISH:	Dialight	1501 ROUTE 34 SOUTH
	1501 ROUTE 34 SOUTH	FARMINGDALE, NJ 07727
FSCM 83330	SHEET 1 OF 1 FAMILY TABLE:	