

Corporate Home |  **Electronic Components** | Segments | Who We Are


Worldwide 



Our commitment. Your advantage.

Products **Documentation** **Resources** **My Account** **Customer Support**

8-55860-3 Product Details

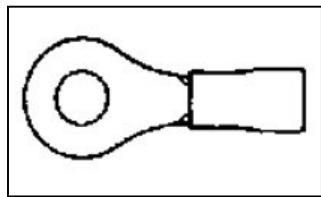

8-55860-3

TE Part Number: 8-55860-3



Ring and Spade Tongue Terminals



Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire
- Wire Range = 3.00-6.00² [12-10] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

 [Previous](#) [1](#) ... [16](#) **[17]** [18](#) [19](#) [20](#) [Next](#) 

Quick Links

-  [Check Pricing & Availability](#)
-  [Search for Tooling](#)
-  [Product Feature Selector](#)
-  [Compare Products](#)
-  [Contact Us About This Product](#)
-  [Request Samples](#) **NEW!**

 **Live Product Chat**

Documentation & Additional Information

Product Drawings:

- [TERMINAL, RING TONGUE, SEALABLE](#) (PDF, English)

Catalog Pages/Data Sheets:

- [PRE-INSULATED SEALED TERMINALS AND SPLICES](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 6.10 [.240] Max.
- Stud Size = 3/8 [9.53]
- [Stud Diameter \(mm \[in\]\)](#) = 9.53 [0.375]
- Shape = RING-088
- [Heavy Duty](#) = Yes
- [Material](#) = Copper
- [Finish](#) = Tin
- Sealed = Yes
- Tongue Material Thickness (mm [in]) = 1.07 [0.042]
- Insulation Material = Polyolefin

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 3.00-6.00² [12-10]
- Wire Range (CMA) = 5,180 – 13,100

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece
- Packaging Quantity = 25

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)

[Home](#) | [Customer Support](#) | [Suppliers](#) | [Site Map](#) | [Privacy Policy](#) | [Browser Support](#)
© 2008 Tyco Electronics Corporation All Rights Reserved