





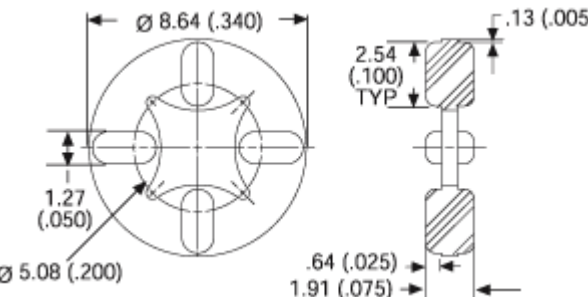


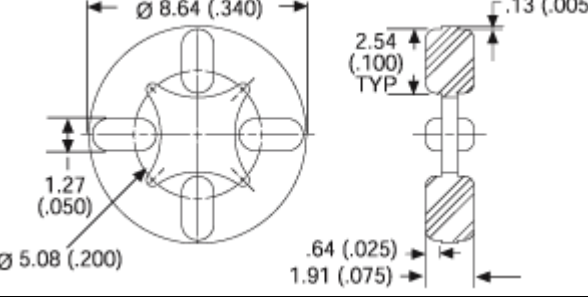


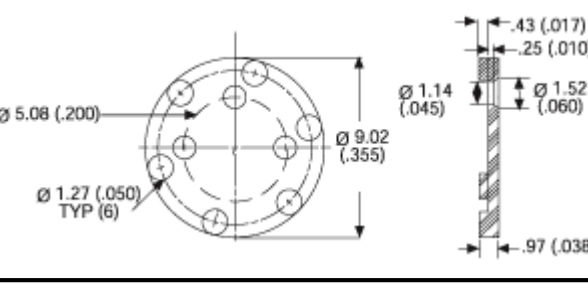


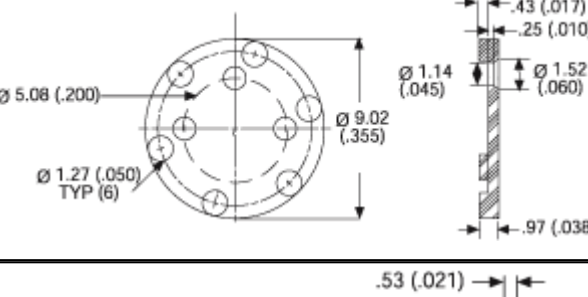

 
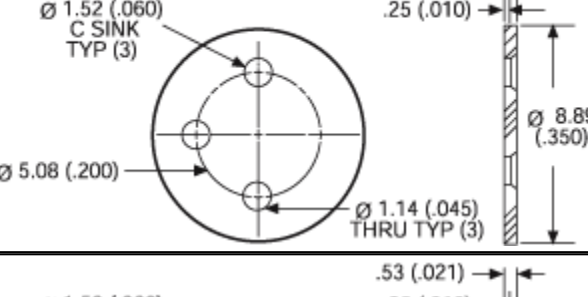

 
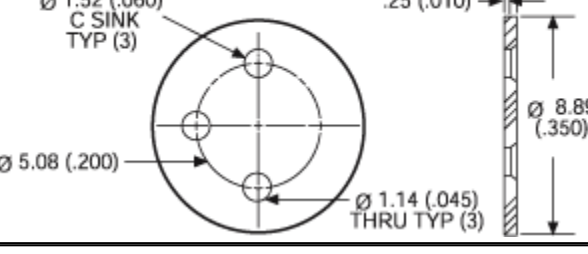
Accessories



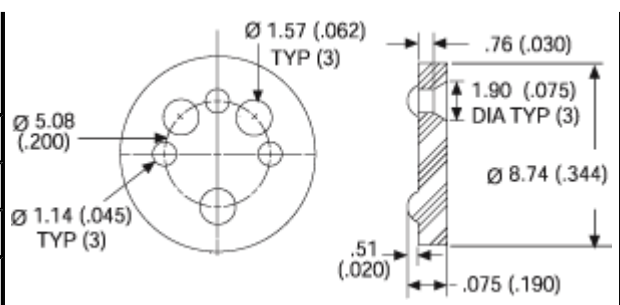


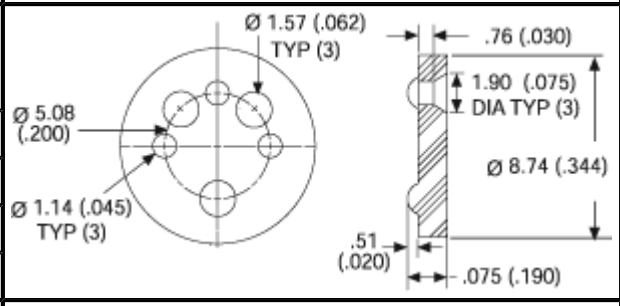

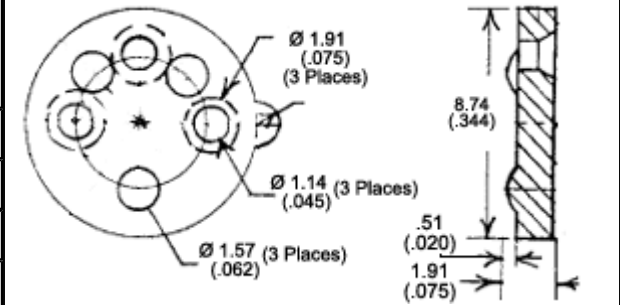

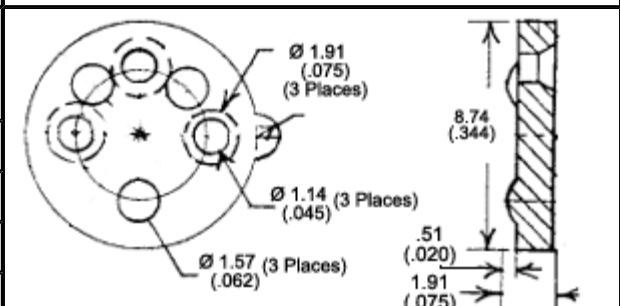

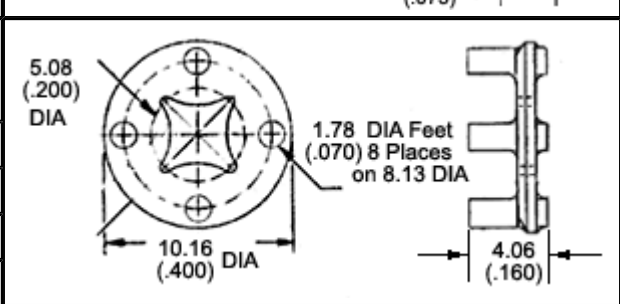

Standard Mounting Pads

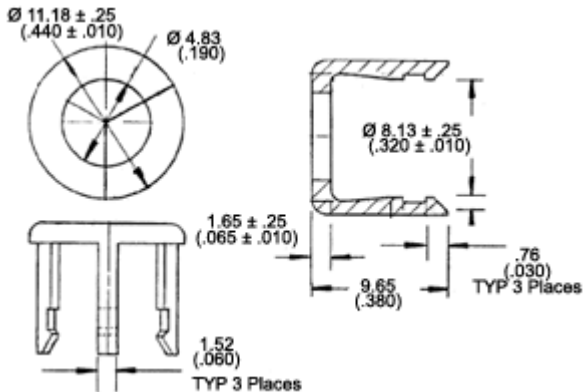

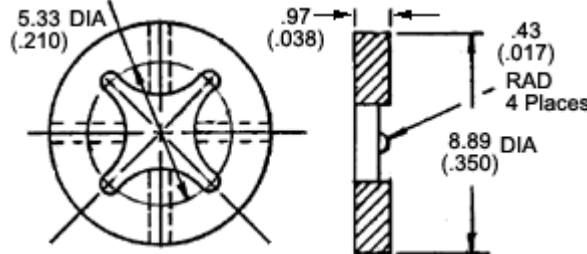
The following Mounting Pads are for use with TO-5	
7717-167DAPG RoHS ✓ Compliant (DAP) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 3.18 (0.125)	
7717-167NG RoHS ✓ Compliant (nylon) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 3.18 (0.125)	
7717-161DAPG RoHS ✓ Compliant (DAP) Leads: 4-Mar Outside Diameter mm (in): 8.64 (0.340) Thickness: 1.91 (0.075)	
7717-161NG RoHS ✓ Compliant (nylon) Leads: 4-Mar Outside Diameter mm (in): 8.64 (0.340) Thickness: 1.91 (0.075)	
7717-159NG RoHS ✓ Compliant (nylon) Leads: 5	

Outside Diameter mm (in): 9.53 (0.375) Thickness: 5.59 (0.220)	
7717-158TG RoHS Compliant (Teflon) Leads: 4 Outside Diameter mm (in): 9.91 (0.390) Thickness: 0.25 (0.010)	
7717-131DAPG RoHS Compliant (DAP) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.97 (0.038)	
7717-131NG RoHS Compliant (nylon) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.97 (0.038)	
7717-114NG RoHS Compliant (nylon) Leads: 4 Outside Diameter mm (in): 9.02 (0.355) Thickness: 1.17 (0.046)	
7717-4DAPG RoHS Compliant Product Change Notice (DAP) Leads: 4 Outside Diameter mm (in): 9.53 (0.375)	

Thickness: 1.91 (0.075)	
7717-4NG (nylon) Leads: 4 Outside Diameter mm (in): 9.53 (0.375) Thickness: 1.91 (0.075)	
7717-5DAPG (DAP) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 3.18 (0.125)	
7717-5NG (nylon) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 3.18 (0.125)	
7717-15DAPG (DAP) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.51 (0.020)	
7717-15NG (nylon) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.51 (0.020)	

<p>7717-3DAPG RoHS  Compliant Product Change Notice </p> <p>(DAP)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p>7717-3NG RoHS  Compliant Product Change Notice </p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p>7717-79DAPG RoHS  Compliant Product Change Notice </p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 9.02 (0.355)</p> <p>Thickness: 0.97 (0.038)</p>	
<p>7717-79NG RoHS  Compliant Product Change Notice </p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 9.02 (0.355)</p> <p>Thickness: 0.97 (0.038)</p>	
<p>7717-178DAPG RoHS  Compliant Product Change Notice </p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.53 (0.021)</p>	
<p>7717-178NG RoHS  Compliant Product Change Notice </p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.53 (0.021)</p>	

<div> <div>RoHS  Compliant</div> <div>Product Change Notice </div> </div> 7717-86DAPG (DAP) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 1.91 (0.075)	
<div> <div>RoHS  Compliant</div> <div>Product Change Notice </div> </div> 7717-86NG (nylon) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 1.91 (0.075)	
<div> <div>RoHS  Compliant</div> </div> 7717-22NG (nylon) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 1.91 (0.075)	
<div> <div>RoHS  Compliant</div> </div> 7717-22DAPG (DAP) Leads: 3 Outside Diameter mm (in): 8.71 (0.343) Thickness: 1.91 (0.075)	
<div> <div>RoHS  Compliant</div> </div> 7717-238NG (nylon) Leads: 4-Mar Outside Diameter mm (in): 10.16 (0.400) Thickness: 4.06 (0.160)	
<div> <div>RoHS  Compliant</div> </div> 7717-300NG (nylon) Leads: Universal	

Outside Diameter mm (in): 11.18 (0.440)	
Thickness: 9.65 (0.380)	
7717-94NG RoHS  Compliant	
(nylon)	
Leads: 4-Mar	
Outside Diameter mm (in): 8.89 (0.350)	
Thickness: 0.97 (0.038)	