

7128DG

TO-220, TO-220-single gauge (0.020")



Copper channel style heat sink with integrated clip

This non-electronic component is functionally unaffected by the normal soldering or reflow processes used for semiconductor circuits. The heat resistance time or heat resistance temperature is not applicable for the component.


Height: 29.21

Mount Orientation: Vertical

Finish: Tin Plated

RoHS: compliant

Thermal Resistance: 19.20

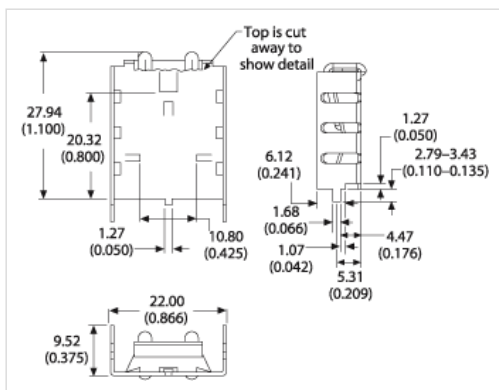

X Dim: 10.69 (0.421) | Y Dim: 4.67 (0.184) | Z Dim: 2.92 (0.115)

