


Rail Mounted Clips

Please note that these clips are intended solely for use with Aavid Thermalloy Max Clip Extrusion Profiles.

Part Number: MAX01NG Low force clip RoHS  Compliant Product Change Notice 	
Force: 22 N [4.9 lbs]	
Width: 10 mm [0.39 in]	
Thickness: 0.5 mm [0.02 in]	
Part Number: MAX01-HNG High force clip RoHS  Compliant Product Change Notice 	
Force: 80 N [18.0 lbs]	
Width: 10 mm [0.39 in]	
Thickness: 0.7 mm [0.03 in]	
Part Number: MAX02NG Standard force clip RoHS  Compliant Product Change Notice 	
Force: 35 N [7.9 lbs]	
Width: 12 mm [0.47 in]	
Thickness: 0.5 mm [0.02 in]	
Part Number: MAX02-HNG High force clip RoHS  Compliant Product Change Notice 	
Force: 60 N [13.5 lbs]	
Width: 13 mm [0.51 in]	
Thickness: 0.6 mm [0.02 in]	
Part Number: MAX03NG Standard force clip RoHS  Compliant Product Change Notice 	
Force: 45 N [10.1 lbs]	
Width: 15 mm [0.59 in]	
Thickness: 0.5 mm [0.02 in]	

Part Number: MAX03-HNG

High force clip

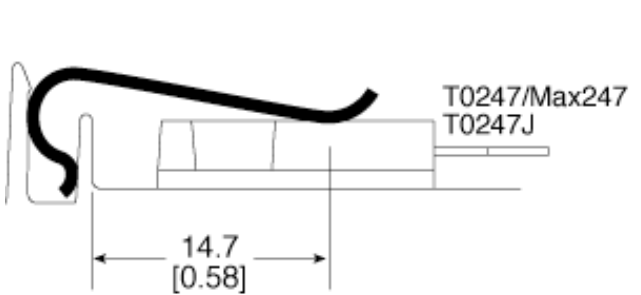


Force: 80 N [18.0 lbs]

Width: 18 mm [0.71 in]

Thickness: 0.6 mm [0.02 in]

Part Number: MAX04NG

Standard force clip

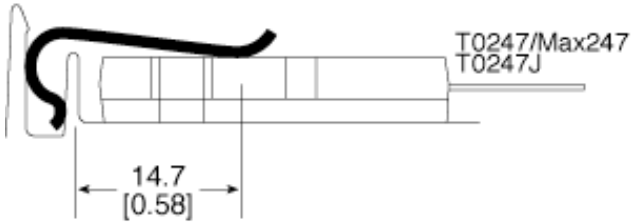


Force: 60 N [13.5 lbs]

Width: 20 mm [0.79 in]

Thickness: 0.5 mm [0.02 in]

Part Number: MAX09NG

Short standard force clip

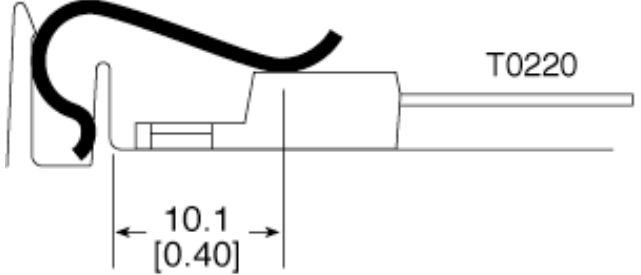


Force: 45 N [10.1 lbs]

Width: 10 mm [0.39 in]

Thickness: 0.5 mm [0.02 in]

Part Number: MAX10NG

Long standard force clip

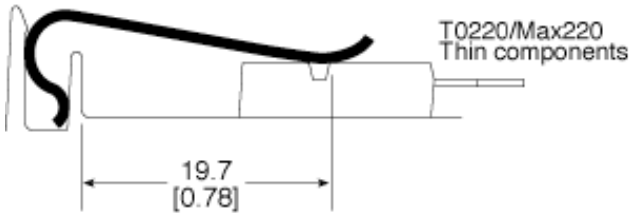


Force: 40 N [9.0 lbs]

Width: 12 mm [0.47 in]

Thickness: 0.6 mm [0.02 in]

Part Number: MAX12NG

Low force clip

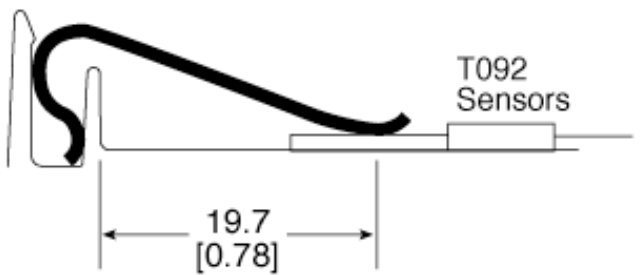


Force: 25 N [5.6 lbs]

Width: 6 mm [0.24 in]

Thickness: 0.6 mm [0.02 in]

Part Number: MAX11NG







Extra long standard force clip

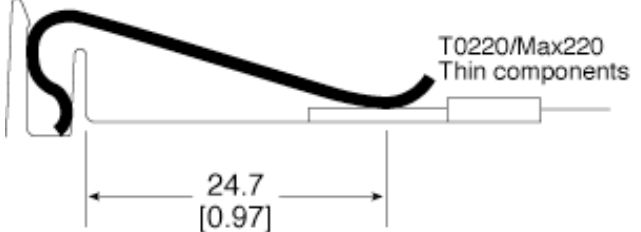

Force: 40 N [9.0 lbs]

Width: 12 mm [0.47 in]

Thickness: 0.6 mm [0.02 in]

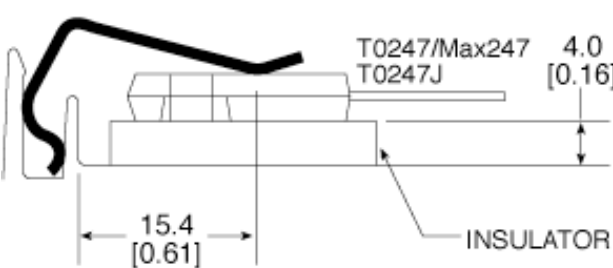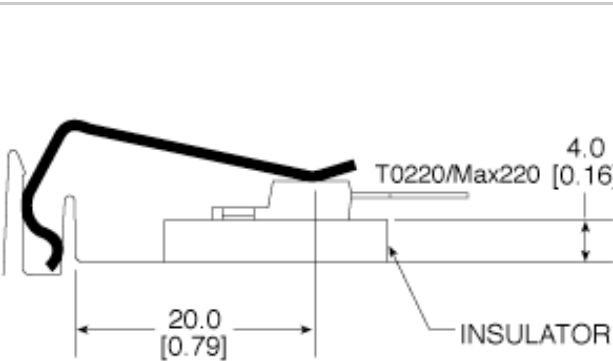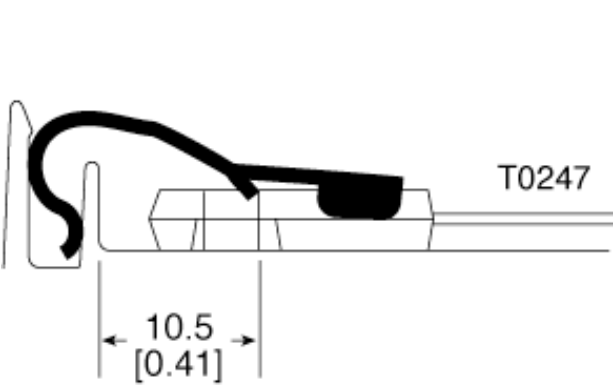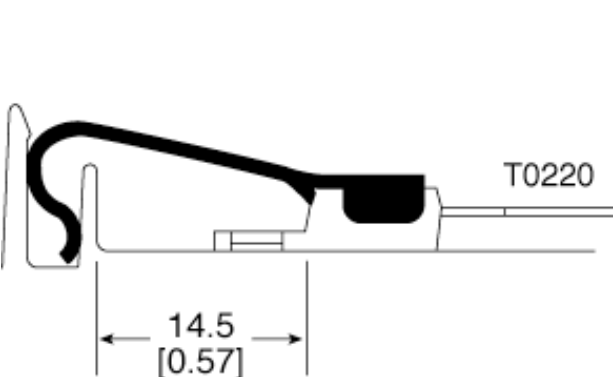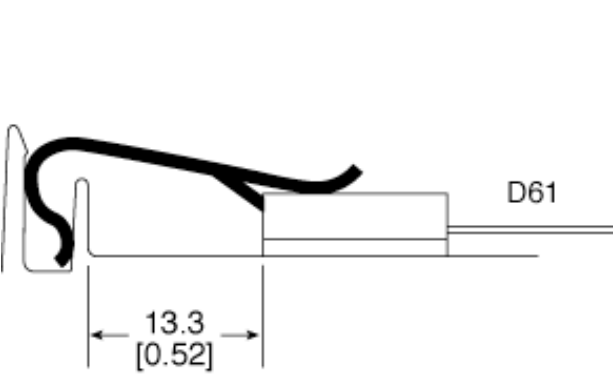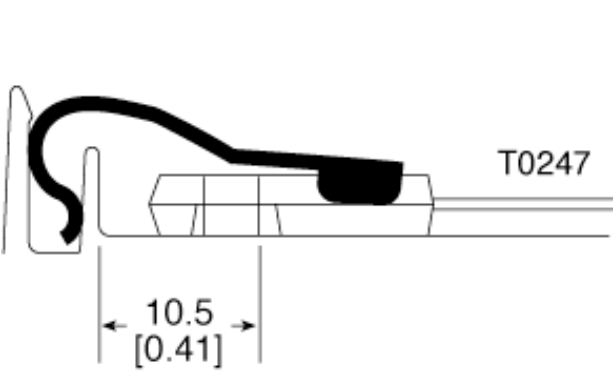Part Number: MAX23NG High force clip for use with thick insulator RoHS  Compliant	
Force: 100 N [22.5 lbs]	
Width: 18 mm [0.71 in]	
Thickness: 0.6 mm [0.02 in]	
Part Number: MAX20NG Standard force clip for use with thick insulator RoHS  Compliant	
Force: 47 N [10.6 lbs]	
Width: 12 mm [0.47 in]	
Thickness: 0.6 mm [0.02 in]	
Part Number: MAX13NG Standard force clip with locating features RoHS  Compliant	
Force: 45 N [10.1 lbs]	
Width: 17 mm [0.67 in]	
Thickness: 0.5 mm [0.02 in]	
Part Number: MAX14NG Low force clip with locating features RoHS  Compliant	
Force: 20 N [4.5 lbs]	
Width: 13 mm [0.51 in]	
Thickness: 0.5 mm [0.02 in]	
Part Number: MAX15NG Standard force clip with locating features RoHS  Compliant	
Force: 60 N [13.5 lbs]	
Width: 18 mm [0.71 in]	
Thickness: 0.6 mm [0.02 in]	
Part Number: MAX16NG Standard force clip with locating features RoHS  Compliant	
Force: 45 N [10.1 lbs]	
Width: 17 mm [0.67 in]	
Thickness: 0.5 mm [0.02 in]	