



Guide Sets


Guide Sets

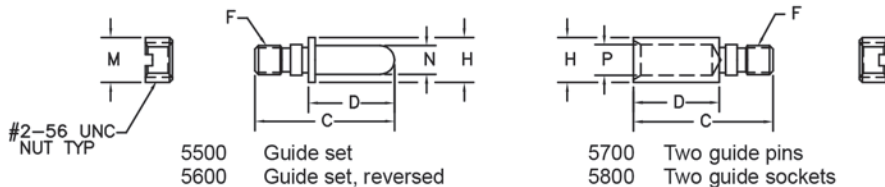


Long Guide Sets

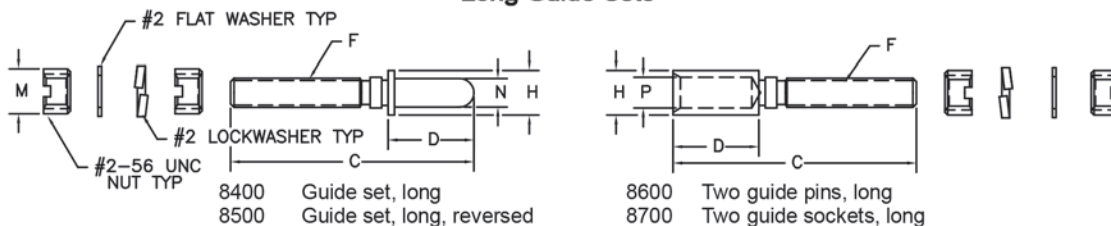

Polarized Guide Sets

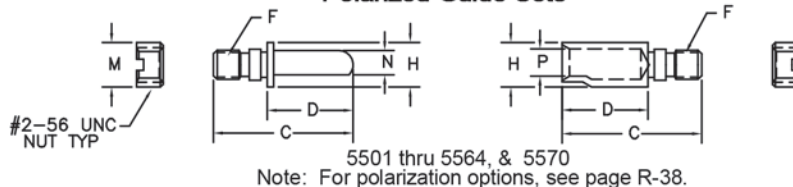

Universal Test Guide Sets

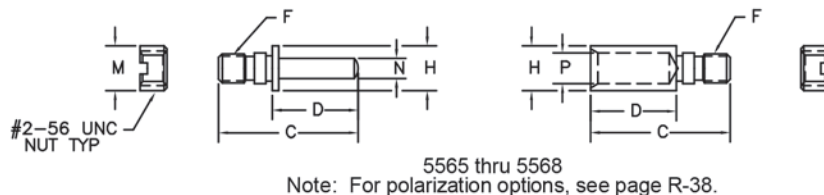

DIMENSIONS											
HARDWARE TYPE	A	C	D	E	F	H	K	L	M	N	P
1900/2000/2900/3000	—	.390	.240	—	#2-56 UNC TH'D	.125 DIA	—	—	.125 DIA	—	—
5100 THRU 5400	.700	.750		.031 x .031 SLOT			.125 DIA	.156 DIA	—	—	—
5500 THRU 5800	—	.390		—			—	—	.125 DIA	.080 DIA	.088 DIA
5501 THRU 5564	—			—			—	.068		.076	
5565 THRU 5568	—			—			—	.056 SQ		.088 DIA	
5900 THRU 6200	.200	.500		5/64 INT HEX			—	.140 DIA	—	—	—
6400 THRU 6700	.490	.750		.031 x .031 SLOT			.125 DIA	.156 DIA	—	—	—
6800 THRU 7100	.545			—					—	—	
7200 THRU 7500	.490			5/64 INTERNAL HEX					—	—	—
7600 THRU 7900	.545			—					—	—	
8000 THRU 8300	.700			—					—	—	
8400 THRU 8700	—	.680		—			—	.125 DIA	.080 DIA	.088 DIA	
8800 THRU 9100	—			—			—	—	—	—	

Hardware Only

HARDWARE TYPE	PART NUMBER
5500 or 5600	RM000-000-000-5500 (or -5600)
5501 - 5532	RM000-000-000-5501 (thru -5532)
5533 - 5548	RM000-000-000-5533 (thru -5548)
5549 - 5564	RM000-000-000-5549 (thru -5564)
5565 or 5566	RM000-000-000-5565 (or -5566)
5568	RM000-000-000-5568
5567	RM000-000-000-5567

HARDWARE TYPE	PART NUMBER
5570	RM000-000-000-5570
5700	RM000-000-000-5700
5800	RM000-000-000-5800
8400 or 8500	RM000-000-000-8400 (or -8500)
8600	RM000-000-000-8600
8700	RM000-000-000-8700

To order connector without hardware, place "-0256" in hardware designation area of catalog number

Example: RM322-152-221-0256