
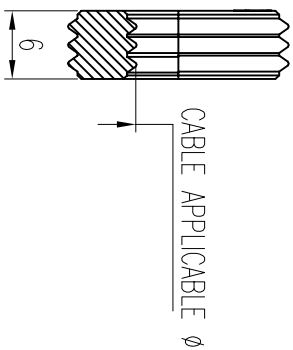
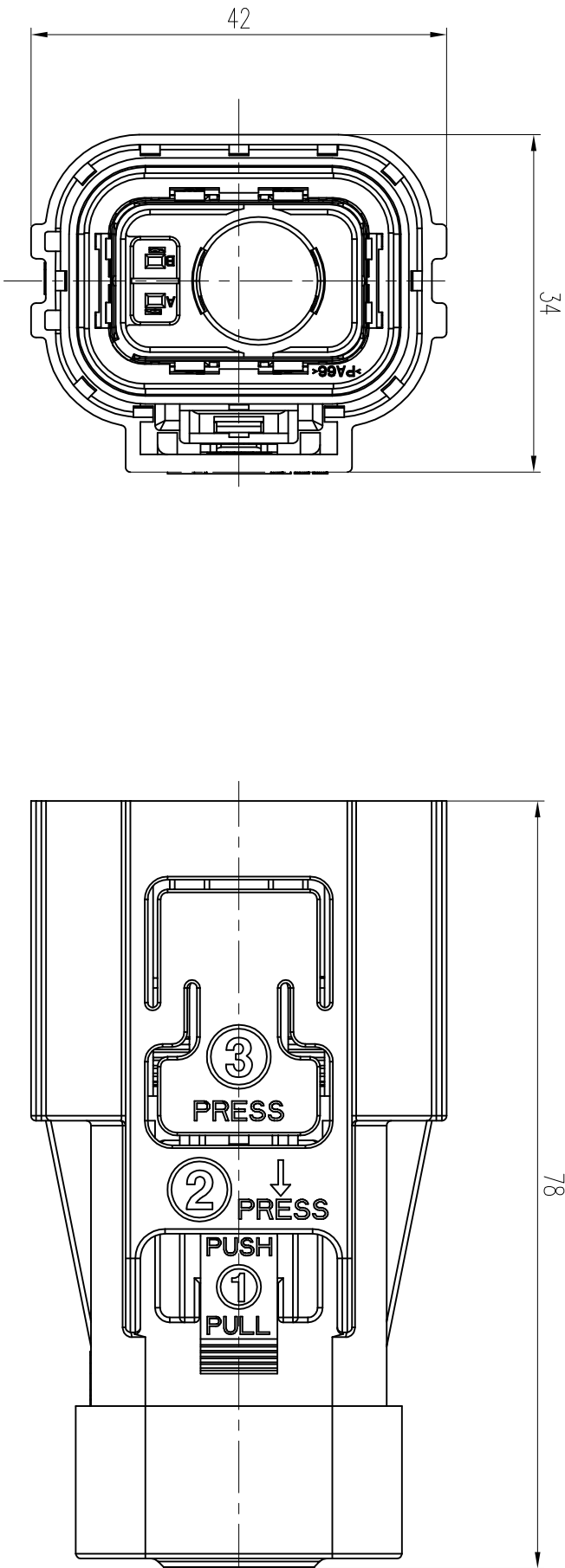


REV	ECN	DESCRIPTION	DATE	MODIFIED
1		PRE-RELEASE	2013.09.16	
2		UPDATE	2013.11.01	G.TANG
3		UPDATE	2013.12.01	G.TANG
4		UPDATE	2014.08.18	Eric

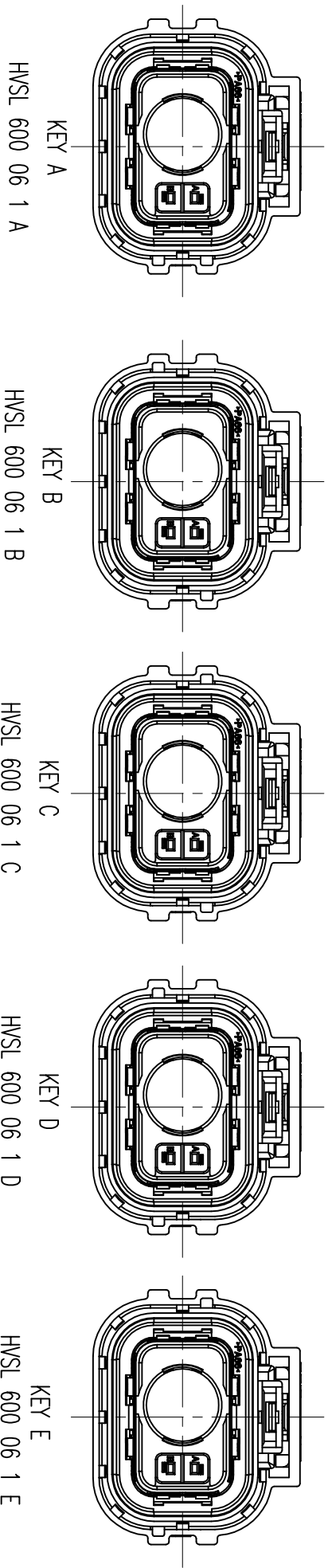

***TECHNICAL PARAMETERS**

Material
Housing : PA66 UL94-V0
Contacts: Copper alloy,Silver plated
Shield: Copper alloy
Seal: Rubber: Silicone

Mechanical data
Operating Temperature: -40~+125°C
Durability: 50 cycles
Contact Type: Crimping
IP67,IP2XB

Electrical data
Withstand Voltage:3000V AC r.m.s
Rated Current : up to 120A
Rated Voltage:630V
Insulation Resistance: >200MΩ
Contact Resistance: < 0.5mΩ
Suited to fit 25mm² cable
Shielded

***NOTES:**
1.DEFAULT PACKING ARE NOT INCLUDING CONTACT AND CABLE SEAL, PLEASE REF. TABLE BELOW FOR THE CORRECT SELECTION.

OPTION FOR CONTACT	OPTION FOR CABLE SEAL(DEPENDS ON DIAMETER OF CABLE)			
MAIN CONTACT	HVL CONTACT	Ø12	Ø11	Ø10
C420003620	C310003614	C270003607	C2700036071	C2700036072

DIMENSIONS		TOLERANCES		PROJECTION		Amphenol Pcd Shenzhen 			
------------	--	------------	--	------------	--	---	--	--	--