



HIRSCHMANN

A BELDEN BRAND

Product information CA 3 W LD


Industrial Connecting Solutions: Circular Connectors: MIL, DIN, Universal Connectors: Signal and Power (CA series): Cable socket and panel-mounted socket: CA 3 W LD

<https://e-catalog.beldensolutions.com:443/link/57078-24228-256281-256284-24359-24360-36072/en/conf/ui/state>

Name		CA 3 W LD
		
		Angled cable socket, integrated strain relief
Delivery informations		
Availability		available
Product description		
Description		Angled cable socket, integrated strain relief
Type		CA 3 W LD
Order No.		934 129-100
Number of contacts		3 + PE
Cable gland		M 22x2
Cable diameter		6 mm to 12 mm
Conductor size		max. 2.5 mm ²
Housing Color		black
Technical data		
Pin dimensions		2 mm
Rated voltage		AC 400 V / DC 250 V
Rated current		DC 10 A / AC 16 A
Contact resistance		<= 3 mOhm
Type of termination		screw
Material		
Contact surface material		Ag
Contact bearer material		PA 66-GF 25
Housing material		PA 66-GF 25
O-Ring		NBR
Environmental conditions		
Protection class (IEC 60529)		IP 67
Pollution severity		3
Temperature range		-40 °C to +90 °C
Inflammability class		
Flammability, UL standard		94 V-0
Approvals		
UL		UL
VDE		VDE
Packing unit		
Packing unit		100 pieces
Scope of delivery and accessories		
Scope of delivery		1 cable socket, not assembled, assembly instructions
Accessories to order separately		can be plugged into CA 3 LS, CA 3 GS; cap CA 00 SD 3, order no. 831 532-400

Picture

Drawing

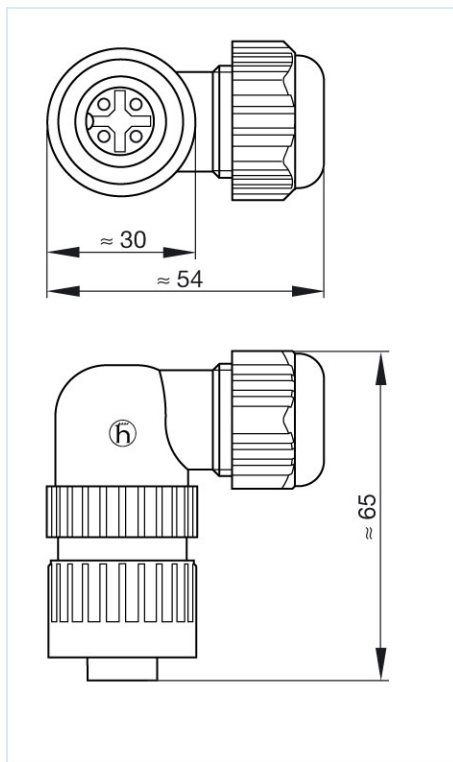

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.