

# CRSP Series Non-lighted Single-pole Rocker Switches

**Approvals**

UL recognized, CSA certified. Load rating: 20A 125/250 VAC. 1 HP, 125/250 VAC. 14A 14VDC, VDE approval 15A. Dielectric strength: 1250 volts (live parts to ground). Life: 35,000 operations at maximum rating. Insulation resistance: 5 megohms.

**Low Level Control**

For low level/dry circuit applications (<100 ma) contact factory for part number (Gold plated contacts).

**High Inrush**

125 Amp inrush capability (AgNi contacts).

**Terminals**

Style A - 1/4-inch quick-connect with fine silver contacts (gold plating available).

**Mechanical Features**

100,000 mechanical operations


 
 
 

**Markings**

Letters, numbers and symbols can be applied to rocker actuator or to integral nylon bezel; see inside back cover for details.

**Mounting**

Snap-in type panel mounting for ease of installation without additional mounting hardware.

| Circuit | Switching                               |  |  |  |
|---------|-----------------------------------------|--|--|--|
| 1       | SPST Maintained                         |  |  |  |
| 2       | SPDT Maintained                         |  |  |  |
| 3       | SPDT Maintained Center Off              |  |  |  |
| 4       | SPST (Momentary) Normally Open          |  |  |  |
| 5       | SPDT (Momentary) Normally Closed        |  |  |  |
| 6       | SPDT (Momentary) Transfer               |  |  |  |
| 7       | SPDT Maintained Center Off (Momentary)  |  |  |  |
| 8       | SPDT (Momentary) Center Off (Momentary) |  |  |  |

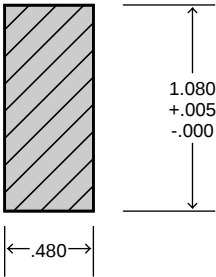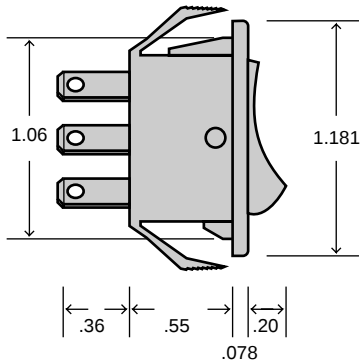

Panel Cut Out  
Panel Thickness 1/32" - 3/16"

**Ordering Information:**

CRSP



 
**Circuit**

- 1=SPST Maintained
- 2=SPDT Maintained
- 3=SPDT Maintained Center Off
- 4=SPST (Momentary) Normally Open
- 5=SPST (Momentary) Normally Closed
- 6=SPDT (Momentary) Transfer
- 7=SPDT Maintained Center Off (Momentary)
- 8=SPDT (Momentary) Center Off (Momentary)



**Terminal Option**

- A=Fine Silver (Normal Duty)
- G=Gold Plated Contacts
- H=High Inrush Contacts



**Actuator Color**

- 7=White
- 9=Black
- 12=Red



**Housing Color**

- M9=Matte Black
- (For other colors contact factory)



**Accessories (Optional)**

- T=Boot



Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.



Phone (203) 272-2794 • Fax (203) 272-3492 • <http://www.osloswitch.com>

MADE IN U.S.A.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## CW Industries:

[CRSP1G9M9](#) [CRSP1A7M9](#) [CRSP8A7M9](#) [CRSP3H12M9](#) [CRSP7A7M9](#) [CRSP4A12M9](#) [CRSP3A7M9](#)  
[CRSP2H12M9](#) [CRSP3A12M9](#) [CRSP6H9M9](#) [CRSP1A9M9](#) [CRSP2A8-7M9E](#) [CRSP8A9M9](#) [CRSP6A9M9](#)  
[CRSP4H9M9](#) [CRSP3A26-12M9E](#) [CRSP1H9M9](#) [CRSP5A12M9](#) [CRSP6A12M9](#) [CRSP2A7M9](#) [CRSP3G9M9](#)  
[CRSP4A7M9](#) [CRSP4A9M9](#) [CRSP5A9M9](#) [CRSP2A9M9](#) [CRSP6A7M9](#) [CRSP7A9M9](#) [CRSP3A9M9](#) [CRSP3A9M9-T](#)  
[CRSP8A12M9](#)