


Datasheet revision 1.0

Generic Dual Row 0.635mm Pitch 40-Pin to DIP-40 Adapter


| REF. | DIMENSIONS |       |      |        |       |      |
|------|------------|-------|------|--------|-------|------|
|      | mm         |       |      | inches |       |      |
|      | MIN.       | TYP.  | MAX. | MIN.   | TYP.  | MAX. |
| A    |            | 0.50  |      |        |       |      |
| B    |            | 8.00  |      |        |       |      |
| C    |            | 0.335 |      |        |       |      |
| D    |            | 0.30  |      |        |       |      |
| E    |            | 0.635 |      |        |       |      |
| F    |            |       |      |        | 0.300 |      |
| G    |            |       |      |        | 0.100 |      |
| H    |            |       |      |        | 0.025 |      |

Top View (SMT Footprint)

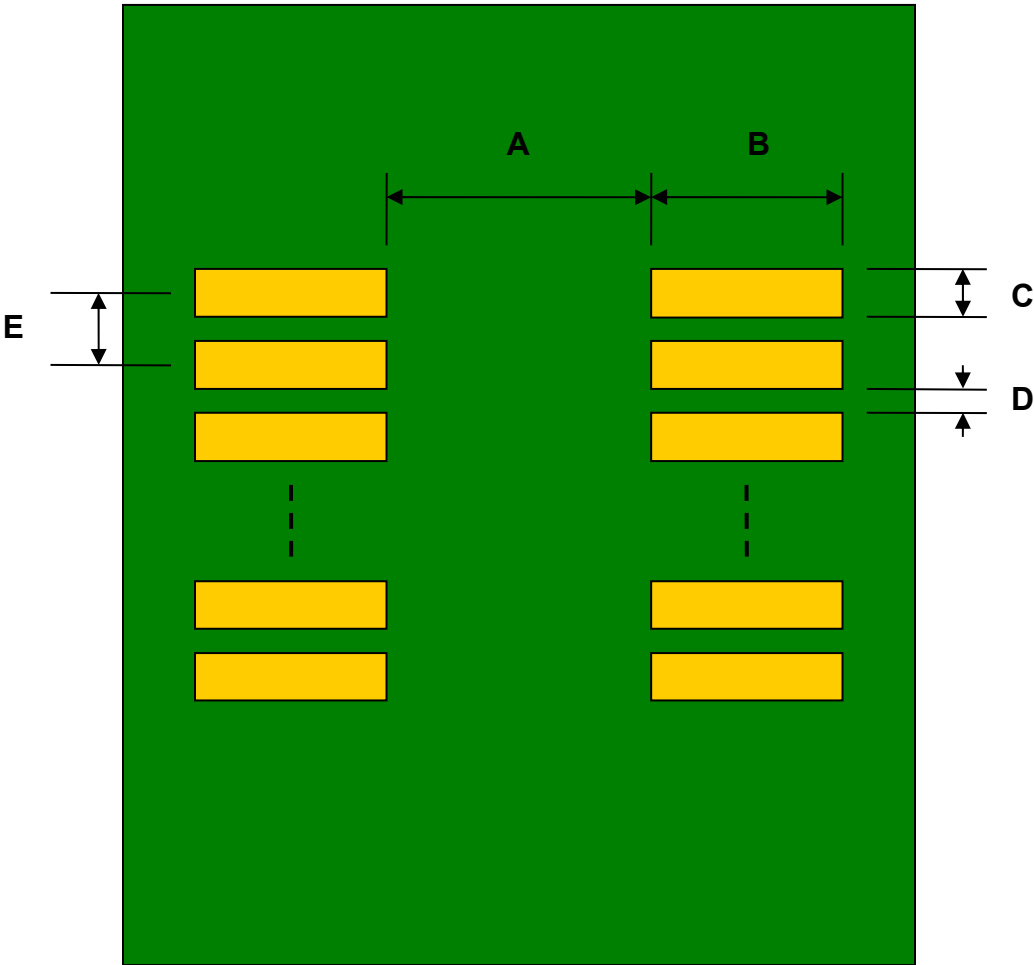


(Representative drawing only - not to scale)

**Bottom View (DIP Pins)**

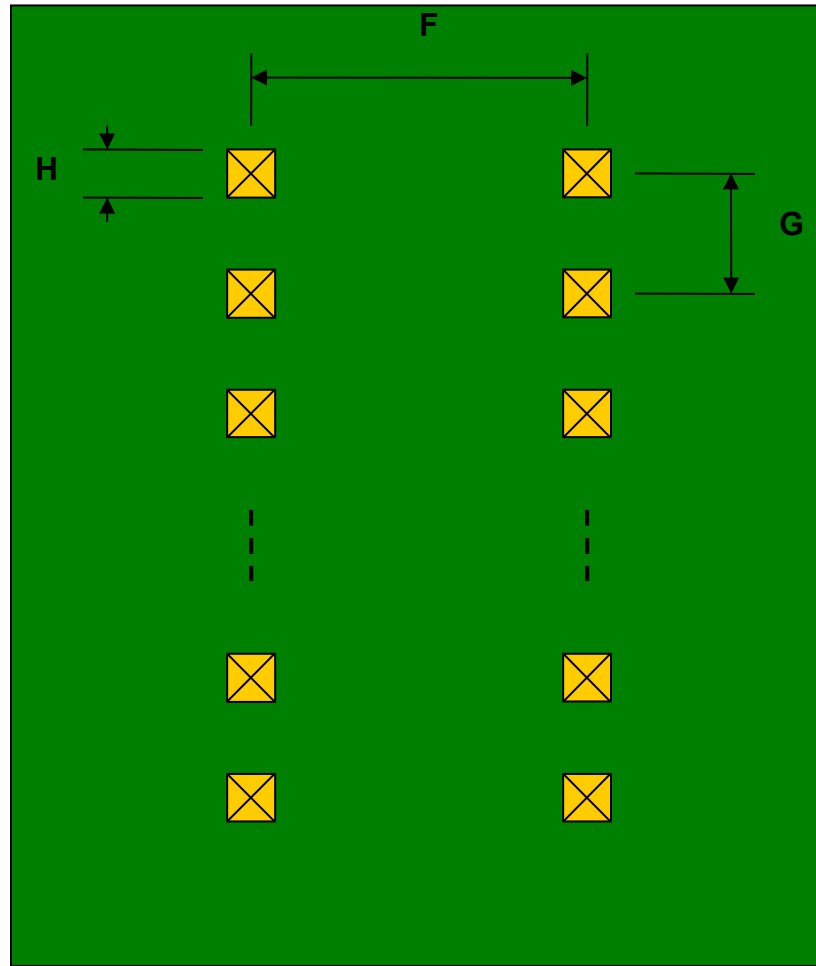

(Representative drawing only - not to scale)

**Side View (DIP Pins)**

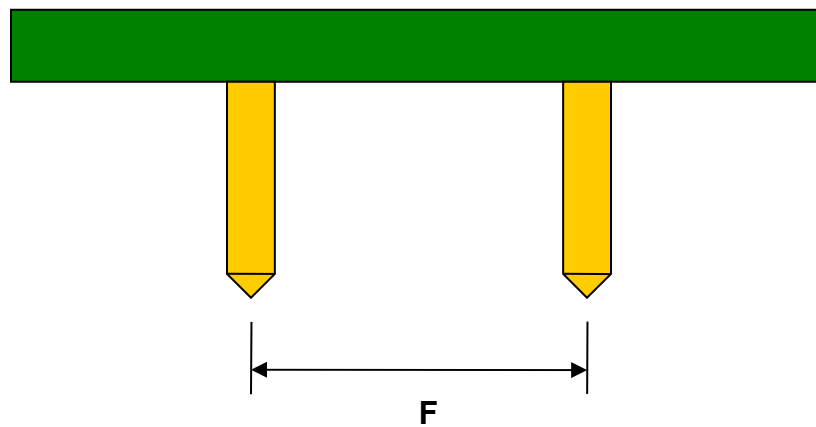

(Representative drawing only - not to scale)