



Solder Trainer Board - many configurations Practice/Training/Kit (100 parts)

Product comes unassembled with 100 parts.

Photos:

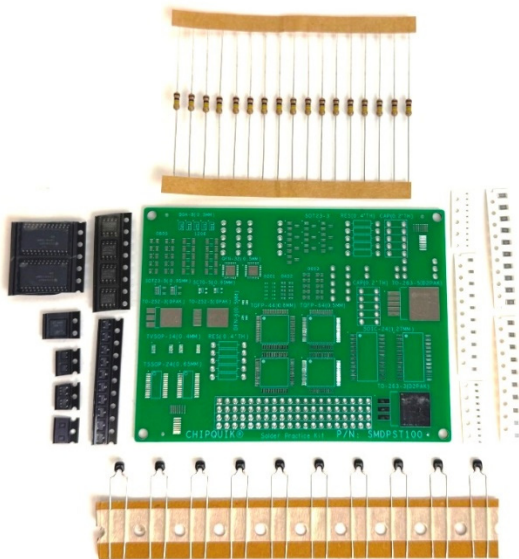

Top

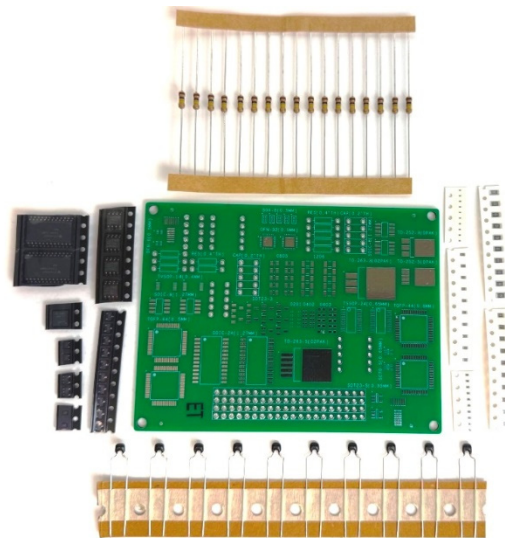

Bottom

Product Highlights

This double-sided practice PCB includes a variety of SMD and TH configurations. Populate the board with an assortment of 100 components (included). All component footprints are clearly marked on board.

Specifications

PCB construction: FR-4 UL94V-0

PCB operating temperature range: -40°C to +130°C (-40°F to +266°F)

PCB reflow maximum temperature: +260°C (500°F)

