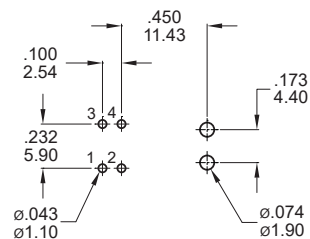
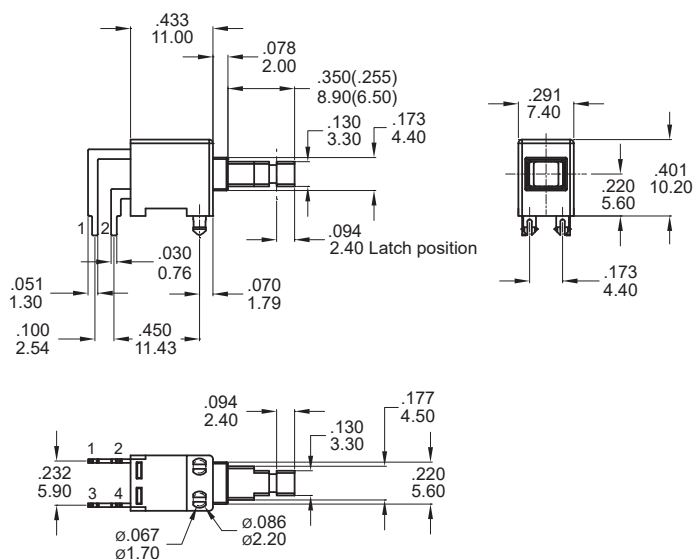
 
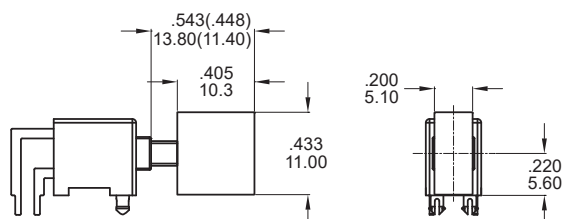


**SPECIFICATIONS****FEATUER:** Non shorting**FUNCTION:** OFF-ON(LOCK)**RATING:** 3A 30VDC**CONTACT RESISTANCE:** 30mΩ MAX**INSULATION RESISTANCE:** 500MΩ min/500V**ELECTRONICS LIFE TEST:** 6,000 cycles**MECHANICAL LIFE TEST:** 30,000 cycles**MATERIALS****CASE:** Glass filled nylon 6/6, Black.**PLUNGER:** Nylon, Black.**HOUSING:** Nylon, Black.**CONTACT / TERMINAL:** Copper, Silver plated.**HOW TO ORDER**

| MODEL NO. | TYPE | CAP TYPE                           | CAP COLOR          |
|-----------|------|------------------------------------|--------------------|
| HB        | 101  | A Rectangle, Nylon<br>B Round, ABS | 1 White<br>2 Black |

EXAMPLE:  
HB-101 (STD)HB-101-  
CAP color  
CAP options**▼ DIMENSION****PCB LAYOUT****SWITCH FUNCTION**

Model name. HB-101

**▼ CAP OPTIONS****A1 Rectangle****B2 Round**