



SPECIFICATIONS

RATING : 100mA max, 42V AC/DC

MECHANICAL LIFE : 1,000,000 cycles

CONTACT RESISTANCE : 100mΩ max. (initial value)

INSULATION RESISTANCE : 1000MΩ min./500VDC

DIELECTRIC STRENGTH : 1,000 VAC (initial value)

FORCE : 3N±0.75N

TRAVEL : 0.6±0.2mm

OPERATING TEMPERATURE RANGE : -25°C~+70°C

MATERIALS

SWITCH HOUSING : PBT

TRANSPARENT ACTUATOR : PC


ACTUATOR : ABS

CONTACT : Stainless

TERMINALS : Brass, Au or Ag plated

TERMINAL SEAL : Epoxy

HOW TO ORDER

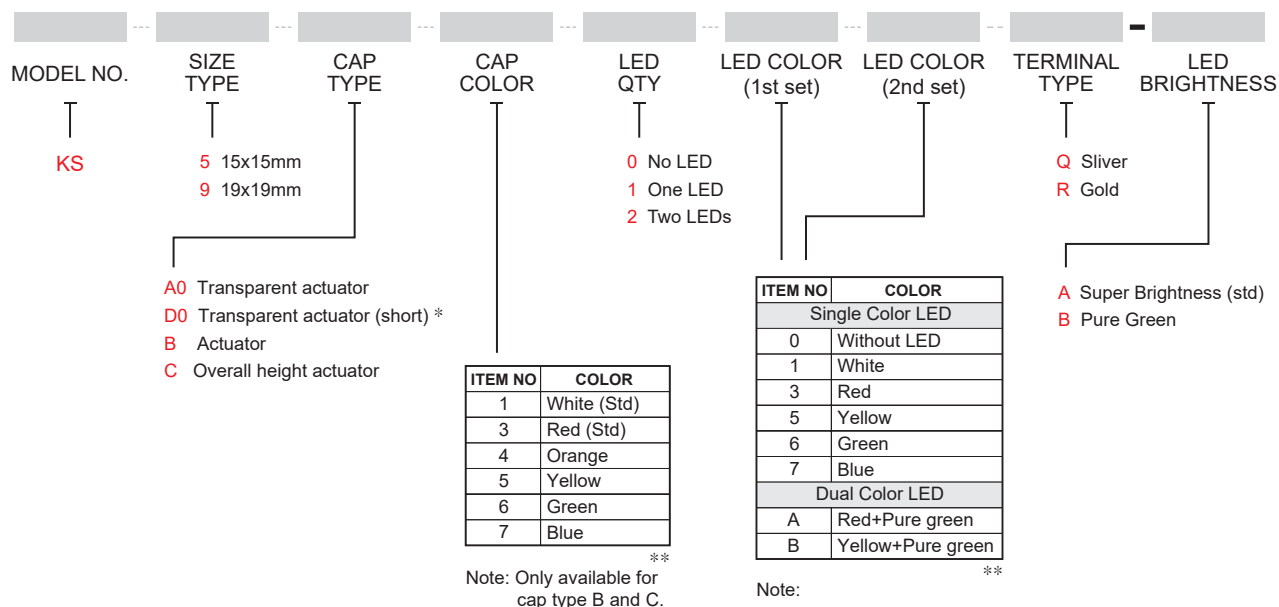

* Standard for size type 5 (15x15mm).

** Except standard color, for other colors information please consult sales representative.

EXAMPLE:

KS5A020□R-A



LED color

KS5B□2□0R-A


LED color

CAP color

▼ CIRCUIT & PCB MOUNTING

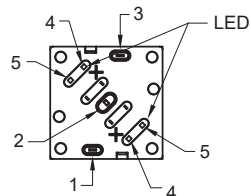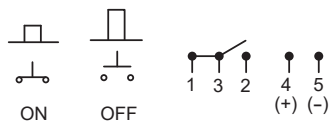


1st set LED

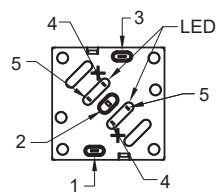


2nd set LED

1st set LED

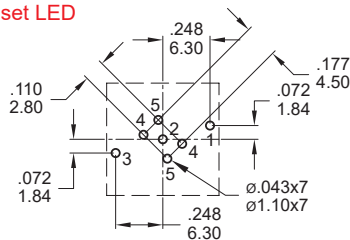


KS5

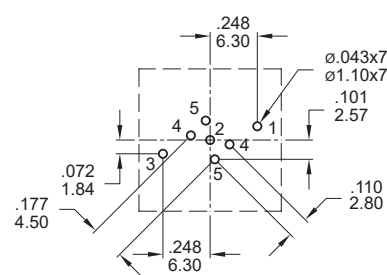


KS9

2nd set LED

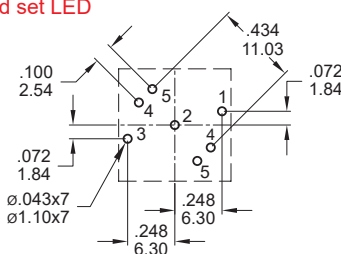



KS5

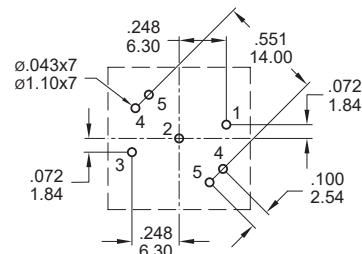



KS9

▼ CAP OPTIONS



A0

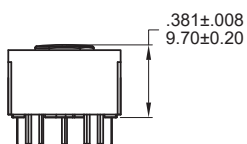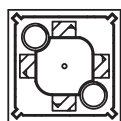



D0 Short

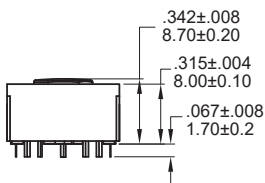 

B


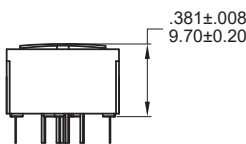
 


C Overall height

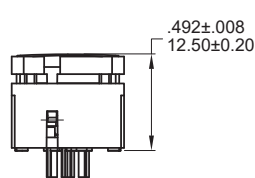 




▼ DIMENSION

KS5 15x15mm

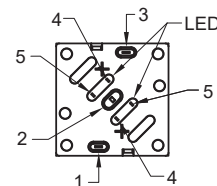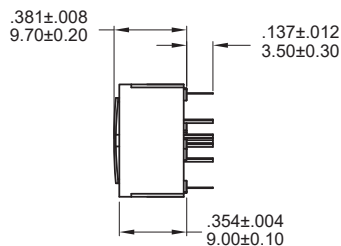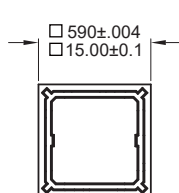

Model name. KS5B3230R-A

KS9 19x19mm

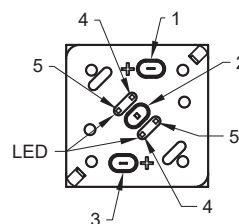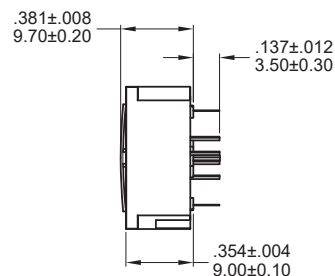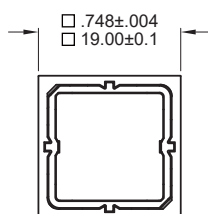

Model name. KS5B6260R-B