


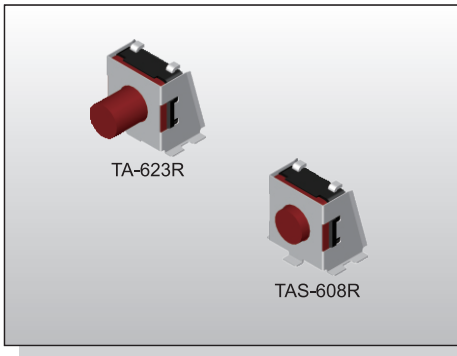

FEATURES

- ※Right angle (SMT type)
- ※Support terminal available
- ※Reflow solderable


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Hair dryers


SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	180±50gf, Brown(N) 260±70gf, Red(R)
Travel	0.45mm
Operating Life	500, 000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

HOW TO ORDER

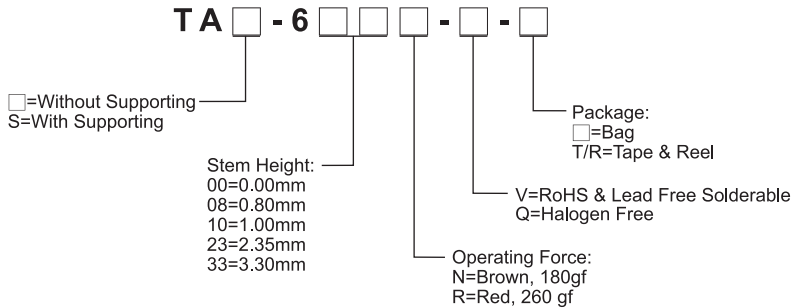

CIRCUIT

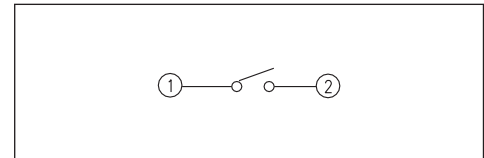

PACKAGE

<Bag>


500 pcs

<Tape & Reel>




TA(S)-600 / 608 / 610 / 623: 700 pcs

TA(S)-633: 500 pcs


TA-6

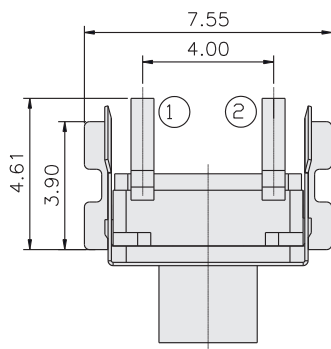




PART. NO.	H
TA-600-Q	0.00
TA-608-Q	0.80
TA-610-Q	1.00
TA-623-Q	2.35
TA-633-Q	3.30

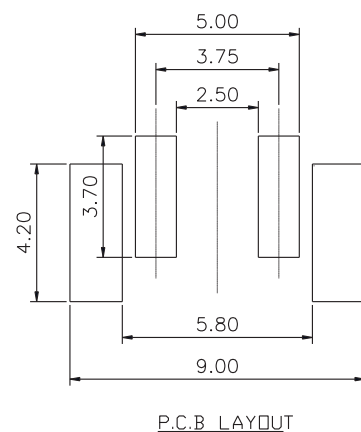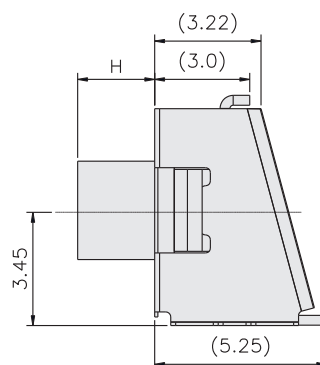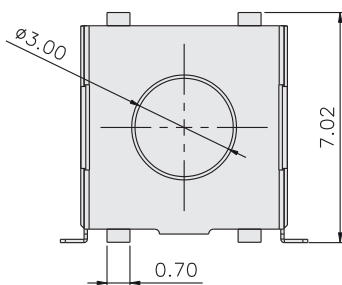

TAS-6

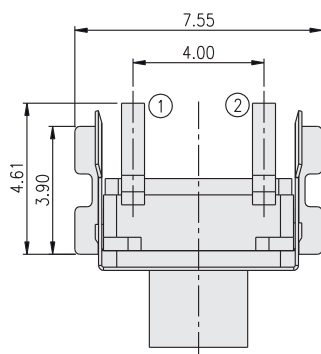

PART NO.	H
TAS-600	0
TAS-608	0.80
TAS-610	1.00
TAS-623	2.35
TAS-633	3.30

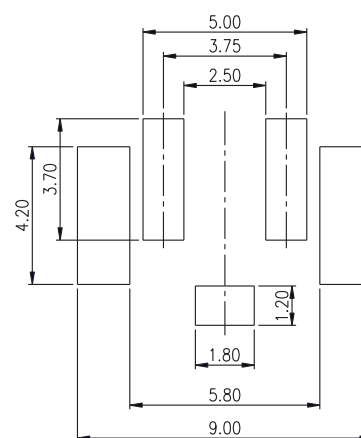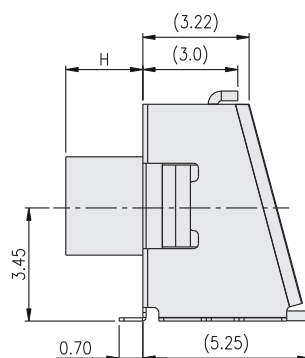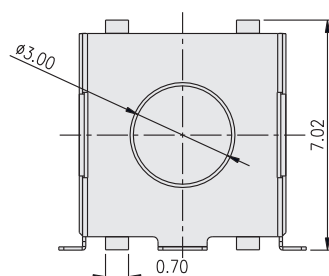

P.C.B. LAYOUT