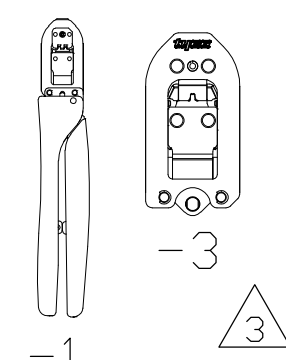
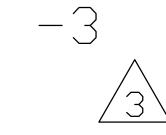
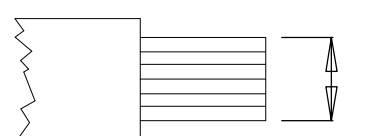
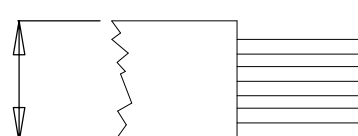
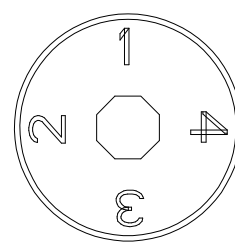
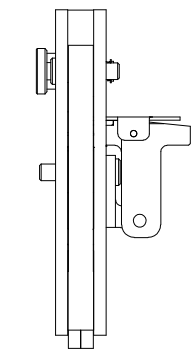
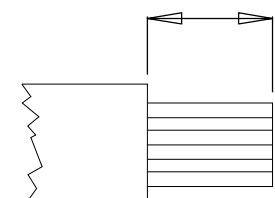
 
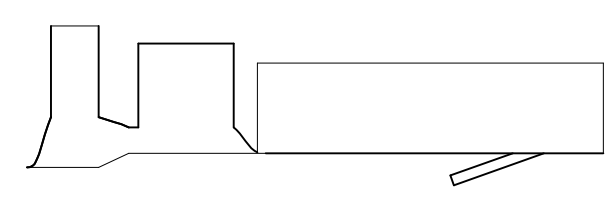
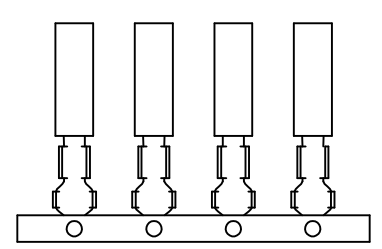


THIS INFORMATION IS CONFIDENTIAL AND PROPRIETARY TO TE CONNECTIVITY. IT IS TO BE USED ONLY FOR THE PURPOSES AND APPLICATIONS SPECIFIED IN THE DRAWING. IT IS NOT TO BE REPRODUCED, COPIED, OR TRANSMITTED IN ANY FORM OR BY ANY MEANS, WITHOUT AUTHORIZATION FROM TE CONNECTIVITY.

THIS INFORMATION IS CONFIDENTIAL AND PROPRIETARY TO TE CONNECTIVITY. IT IS TO BE USED ONLY FOR THE PURPOSES AND APPLICATIONS SPECIFIED IN THE DRAWING. IT IS NOT TO BE REPRODUCED, COPIED, OR TRANSMITTED IN ANY FORM OR BY ANY MEANS, WITHOUT AUTHORIZATION FROM TE CONNECTIVITY.

											USED ON	—
TOOL NUMBER  -1 	WIRE SIZE mm ² [AWG] 	INSULATION DIAMETER mm [in.] 	INSULATION ADJUSTER 	FLIP LOCATOR 	STRIP LENGTH mm [in.] 	CRIMP HEIGHT mm [in.] 	CONTACT PART NUMBERS 		CONTACT DESCRIPTION	APPLIC. SPECIFIC.		
							LOOSE PIECE 	STRIP FORM 				
91509-1 91509-3	0.32-0.89 [22-18]	2.29-3.30 [.090-.130]	YES	NO	4.75 ± 0.38 [.187 ± .015]	1.27 ± 0.05 [.050 ± .002]	42566-[] 60196-3 62228-1 42638-2	42452-[] 60196-[] 62026-1 42373-[]	187 FASTON Contacts	114-2036 and 114-35000		
	1.25-1.42 [16]					1.52 ± 0.08 [.060 ± .003]						
91511-1 91511-3	0.20-0.38 [24-22]	1.02-1.52 [.040-.060]	NO	NO	4.75 ± 0.38 [.187 ± .015]	0.76 ± 0.05 [.030 ± .002]	-	42067-[] 42415-[]	110 FASTON Contacts	114-2036 and 114-35000		
	0.32-0.96 [22-18]	1.52-2.54 [.060-.100]				1.14 ± 0.05 [.045 ± .002]	42922-[]	42635-[]				
91514-1 91514-3	0.32-0.96 [22-18]	1.52-2.54 [.060-.100]	YES	NO	6.35 ± 0.38 [.250 ± .015]	1.40 ± 0.10 [.055 ± .004]	41969-[] 42731-[] 60878-2 61316-1 170187-[]	41772-[] 42640-[] 60294-2 170183-[]	250 FASTON contacts	114-2036 and 114-35000		
		2.29-3.30 [.090-.130]										
91581-1 91581-3	0.50-0.85 [20-18]	2.03-3.05 [.080-.120]	NO	NO	4.5 ± 0.38 [.177 ± .015]	0.97-1.10 [.038-.043]	170042-[] 172799-[]	170015-[] 170033-[]	110 FASTON Contacts	114-2036 and 114-35000		
						1.42-1.55 [.056-.061]	170041-[]	170014-[]				
91593-1 91593-3	0.51-0.89 [20-18]	1.90-3.00 [.075-.118]	YES	NO	4.50 ± 0.50 [.177 ± .020]	1.10-1.24 [.043-.049]	170331-[]	170325-[]	187 POSITIVE LOCK FASTON Contacts	114-5041		
	1.25-1.38 [16]	2.40-3.40 [.094-.134]				1.35-1.54 [.053-.061]						
2031929-1 2031929-3	0.32-0.96 [22-18]	1.52-2.54 [.060-.100]	NO	NO	4.75 ± 0.38 [.187 ± .015]	1.14 ± 0.05 [.045 ± .002]	42470-[]	42068-[]	110 FASTON Contacts	114-2036 and 114-35000		
2063247-1 2063247-3	0.31-0.56 (22-20)	2.03-2.65 (.080-.104)	YES	NO	4.78 ± 0.38 (.188 ± .015)	1.37 ± 0.05 (.054 ± .002)	-	42490-[]	187 FASTON Contacts	114-2036		
	0.76-0.89 (18)	2.13-3.05 (.084-.120)				1.57 ± 0.05 (.062 ± .002)						
2063846-1 2063846-3	0.20-0.38 [24-22]	1.02-1.52 [.040-.060]	NO	NO	4.75 ± 0.38 [.187 ± .015]	0.76 ± 0.05 [.030 ± .002]	-	42067-[] 42415-[]	110 FASTON Contacts	114-2036 and 114-35000		
	0.32-0.96 [22-18]	1.52-2.54 [.060-.100]				1.14 ± 0.05 [.045 ± .002]	42470-[]	42068-[]				

-  LIST OF APPLIED CONTACT PART NUMBERS MAY NOT BE COMPLETE AND IS SUBJECT TO CHANGE. FOR CURRENT INFORMATION ON TERMINAL PART NUMBERS, CONTACT THE TOOLING ASSISTANCE CENTER : 1-800-722-1111.
2. AMP, CERTI-CRIMP, and FASTON ARE TRADEMARKS.
-  -1 IS A CERTICRIMP II HAND TOOL ASSEMBLY.
-3 IS A CERTICRIMP II HEAD SUB-ASSEMBLY.
4. THE HAND TOOL INSTRUCTION SHEET, ALSO KNOWN AS AN "IS", FOR MOST CERTI-CRIMP II TOOLS USE IS 408-8547. IF THE TOOL HAS A FLIP LOCATOR USE IS 408-10414.

CERTI-CRIMP II DATA SHEET

DWN	M. YOUNGER	21FEB2012	MATERIAL	-	HEAT TREAT	-					
CHK	B.A.WOLFE	22FEB2012	 TE Connectivity								
APVD	B.A. WOLFE	22FEB2012									
NAME											
CERTI-CRIMP II TOOL DATA SHEET FASTON & POSITIVE LOCK CONTACT FAMILY											
SCALE	-	SIZE	A1	DRAWING NO	1583005	SHEET	1	OF	2	REV	D3

LOC
A
DIST
00

LOC A
DIST 00

4. THE HAND TOOL INSTRUCTION SHEET, ALSO KNOWN AS AN "IS", FOR MOST CERTI-CRIMP II TOOLS USE IS 408-8547. IF THE TOOL HAS A FLIP LOCATOR USE IS 408-10414.

[illegible]