



TL3365 SERIES TACT SWITCH

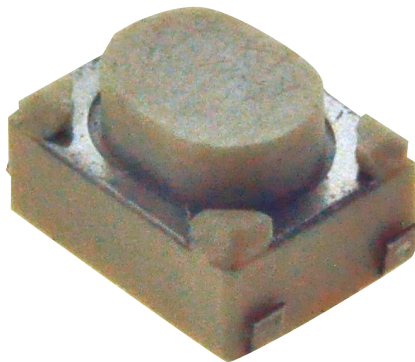

APPLICATIONS / MARKETS



Audio / Visual

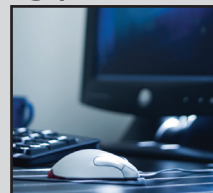

Computer Peripherals



Consumer Electronics



Instrumentation



Telecommunication



Medical Equipment

RoHS

SPECIFICATIONS

Electrical Rating: 50mA @ 12VDC
Electrical Life: 100,000 Cycles
Mechanical Life: 100,000 Cycles
Contact Resistance: 100mΩ Max. Initial
Insulation Resistance: 100M Ω at 100VDC
Dielectric Strength: 250VAC for 1 min.
Operating Temperature: -20°C to 70°C
Storage Temperature: -30°C to 80°C
Operating Force: 180gf, 250gf, or 400gf
Travel: 0.2mm
Contact Arrangement: SPST

FEATURES & BENEFITS

- Ultraminiature
- Surface mount
- Multiple actuation force options

PART NUMBER CONFIGURATOR

Series	Model	Actuator Option	Actuation Force	Contact Material	Termination
TL	3365	A - 2.50mm	F180 - 180 gf F250 - 250 gf F400 - 400 gf	Q - Silver	G - J Lead

Specifications subject to change without notice 3.26.2025



E-SWITCH®

www.e-switch.com

800.867.2717

1

TL3365 SERIES TACT SWITCH

BODY DIMENSIONS

