




Housing

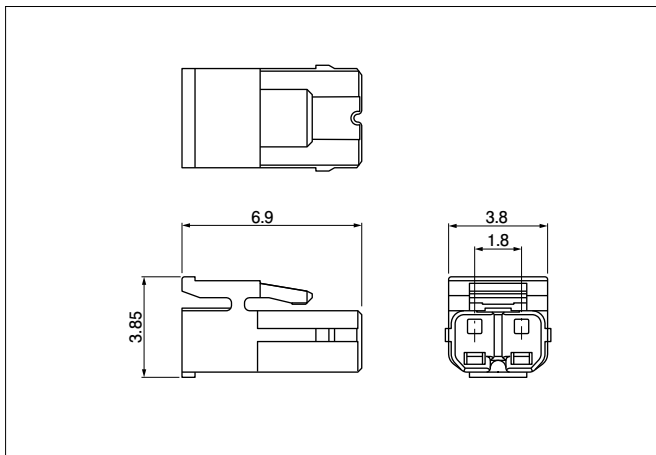


No. of circuits	Model No.	Q'ty/bag
2	SFKR-02V-S	2,000

Material		
PA 66, UL94V-0, natural (white)		

RoHS compliance

Header

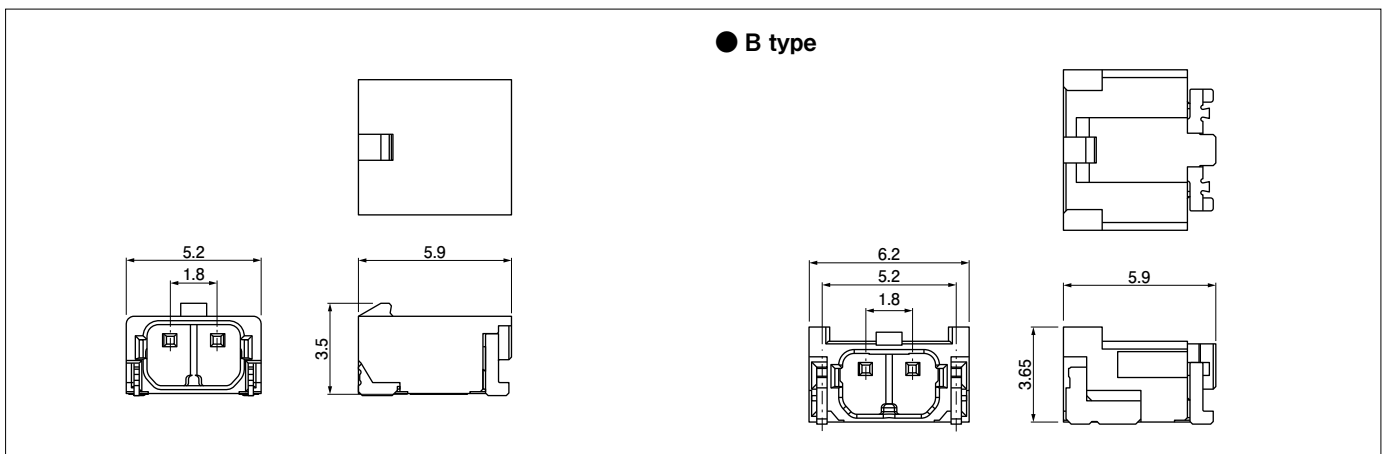

● B type

No. of circuits	Model No.	Q'ty/reel
2	SM02B-SFKH-TF	3,000

Material and Finish		
Press pin: Brass, copper-undercoated, tin-plated (reflow treatment)		
Wafer: PA 6T, UL94V-0, gray		
Solder tail: Brass, copper-undercoated, tin-plated (reflow treatment)		

RoHS compliance

Note: The product listed above is supplied on embossed-tape.

● B type

No. of circuits	Model No.	Q'ty/reel
2	SM02B-SFKBS3-TF	3,000

Material and Finish		
Press pin: Brass, copper-undercoated, tin-plated (reflow treatment)		
Wafer: PA 4T, UL94V-0, natural		
Solder tail: Brass, copper-undercoated, tin-plated (reflow treatment)		

RoHS compliance

Note: The product listed above is supplied on embossed-tape.

SFK CONNECTOR

Model number allocation

Contact

S SFH -001 T - P 0.5

Form: S...Strip form

Series name

Applicable wire range: 001...AWG #26 to #22
002...AWG #30 to #26

Surface finish: T...Tin-plated (reflow treatment)

Material: P...Copper alloy

Terminal size

Housing

SFK R -02 V -S

Series name

Part name: Receptacle

No. of circuits: 2

Flammability: V...UL94V-0

Color: S...Natural (White)

Header

SM 02 B -SFK H -TF

Shape of assembled product:
SM...SMT side entry type

No. of circuits: 2

Part name: Header

Series name

Color: H...Gray

Packaging style: TF...Embossed-taping

Header (B type)

SM 02 B -SFKB S 3-TF

Shape of assembled product:
SM...SMT side entry type

No. of circuits: 2

Part name: Header

Series name

Color: S...Natural

Resin material: PA 4T

Packaging style: TF...Embossed-taping