


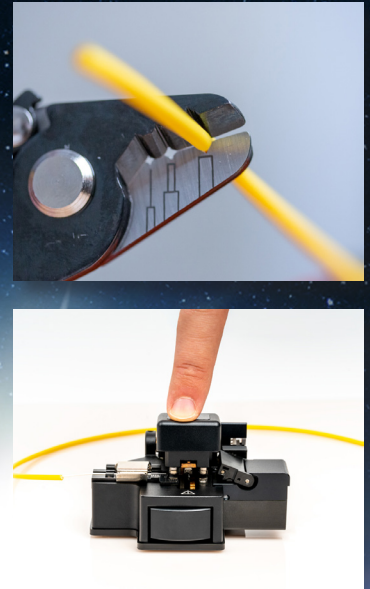

SPARC LINC™



Sparc Rapid Linc Mechanical Connector, LC/UPC, Pack of 10 - SRL-LCU/10

Jonard Tools' Mechanical Connectors for fiber optic cables provide a reliable and efficient solution for connectorizing 250 μm and 900 μm coated fibers. These connectors are ideal for quick field installations, offering a simple, tool-free setup that saves time and enhances productivity. These connectors also feature the following:

- LC/UPC polish for excellent performance and minimal signal loss
- Works with both 250 μm and 900 μm coated fiber cables
- Easy to use with no special tools required, making it ideal for quick fieldwork
- Built to withstand demanding environments, ensuring long-lasting reliability
- INCLUDES: (10) LC/UPC mechanical connectors

SPECIFICATIONS

CONNECTOR TYPE	LC
POLISH TYPE	UPC (Singlemode)
FIBER TYPE	Singlemode
CABLE TYPES	900 μm & 250 μm
INSERTION LOSS	AVG \leq 0.3dB MAX \leq 0.5dB
RETURN LOSS	APC \geq 45dB
OPERATING TEMPERATURE	-20/+85°C
STANDARDS	TIA/EIA 604-3
DIMENSIONS	1.81" x 0.35" x 0.2" (4.6 cm x 0.89 cm x 0.51 cm)
WEIGHT	0.1 lb (45.4 g)
UPC #	810132438691