



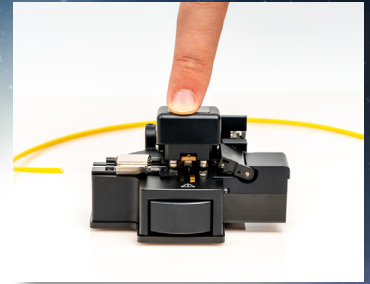

SPARCTM LINE

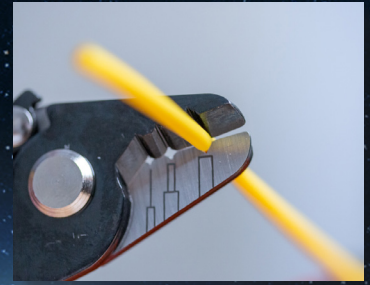

Sparc Rapid Linc Mechanical Connector, SC/APC, Pack of 10 - SRL-SCA/10

Jonard Tools' Mechanical Connectors for fiber optic cables provide a reliable and efficient solution for connectorizing 250 μ m and 900 μ m coated fibers. These connectors are ideal for quick field installations, offering a simple, tool-free setup that saves time and enhances productivity. These connectors also feature the following:

- SC/APC polish for excellent performance and minimal signal loss
- Works with both 250 μ m and 900 μ m coated fiber cables
- Easy to use with no special tools required, making it ideal for quick fieldwork
- Built to withstand demanding environments, ensuring long-lasting reliability
- INCLUDES: (10) SC/APC mechanical connectors

SPECIFICATIONS

CONNECTOR TYPE	SC
POLISH TYPE	APC (Singlemode)
FIBER TYPE	Singlemode
CABLE TYPES	900 μ m & 250 μ m
INSERTION LOSS	AVG \leq 0.3dB MAX \leq 0.5dB
RETURN LOSS	APC \geq 55dB
OPERATING TEMPERATURE	-40/+85°C
STANDARDS	TIA/EIA 604-3
DIMENSIONS	2" x 0.35" x 0.43" (5.08 cm x 0.89 cm x 1.09 cm)
WEIGHT	0.1 lb (45.4 g)
UPC #	810132438523