


DIMENSIONS: mm

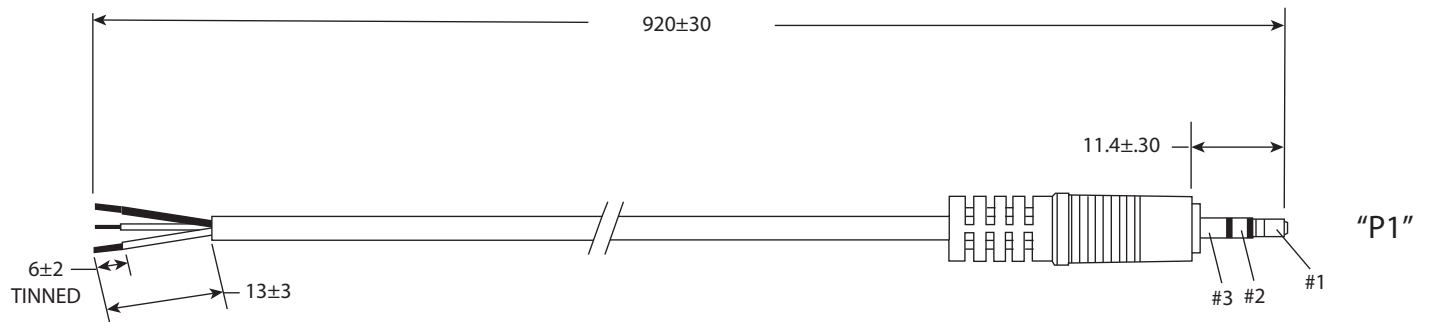

CONNECTION	
P1	COLOR
1	WHITE
2	RED
3	SPIRAL

Specifications:

- Operating Temperature: -10°C~+80°C
- Insulation Resistance: DC/250V 5MΩ MIN.
- Withstand Voltage: AC/250V ,5mA For One Minute.
- Continuity Resistance: 5Ω MAX.
- Continuity Test: 100%
- Tensile Strength: PHN/M Overmold to cable shall withstand 29.4N(3.0Kgf) Pull MIN. For one minute.

Notes:

- RoHS Compliant