


DIMENSIONS: mm

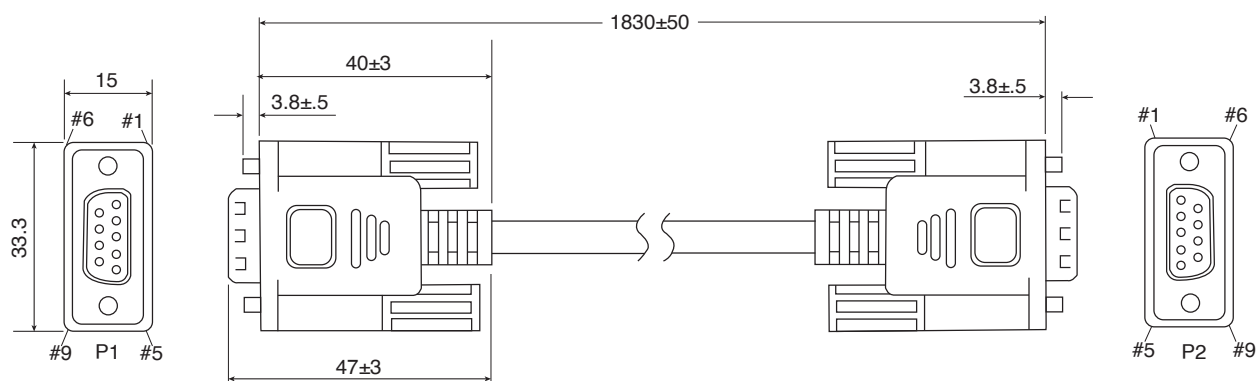

CONNECTION		
P1	WIRE COLOR	P2
1	BLACK	1
2	BROWN	2
3	RED	3
4	YELLOW	4
5	GREEN	5
6	BLUE	6
7	PURPLE	7
8	ORANGE	8
9	GRAY	9

Specifications:

- Operation Temperature : -10°C - +80°C
- Insulation Resistance : DC/250V 5MΩ, for one minute.
- Continuity Resistance : 3Ω (Max)
- Tensile Strength: Overmold to cable shall withstand 10kgf pull, for one minute.

Note: RoHS Compliant