


R13-448

Double Poles of R13-447

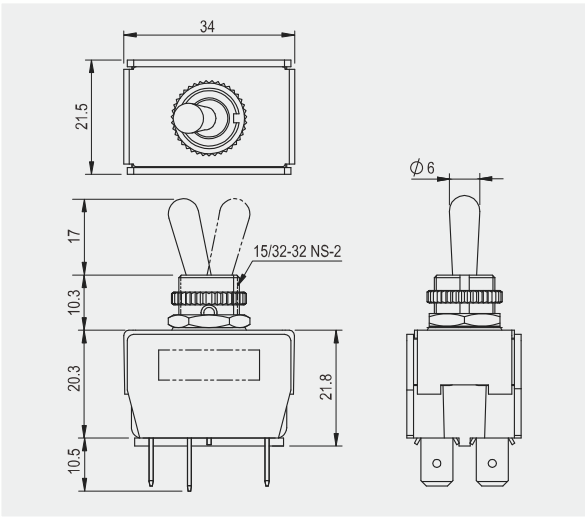

Rating
16(4)A 250V AC (F,S,Q)
12(4)A 250V AC (B,E,K,M,P)
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out
6 mm max

FEATURES

- * MATERIAL: Metal lever is nickel plated metal. Bushing is nylon with glass fiber (UL flame: 94V-0). Frame is nylon (UL flame: 94V-2).
- * Watertight boot (W-72) is optional for lever #1 only.

R13-448

FUNCTION	LEVER	TERMINAL	TERMINAL BARRIER
B 	1 Metal Lever 	0 1 .250" SQ 0 5 SO 0 8 SC 6-32UNC 1 2 SO	A WITHOUT TERMINAL BARRIER B WITH TERMINAL BARRIER
E 	3 Plastic Lever 		
M 			
P 			
F 			DUST AND WATER SEALED IP40 Y IP56
Q 			
K 			
S 			

* () =momentary

