






PCB Dual Phono Jacks

156-4219-E, 156-4221-E

Date Last Revised: 9/9/21

DIMENSIONS: In.

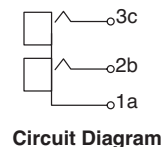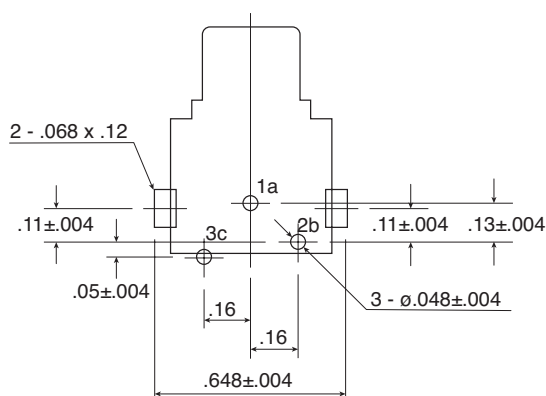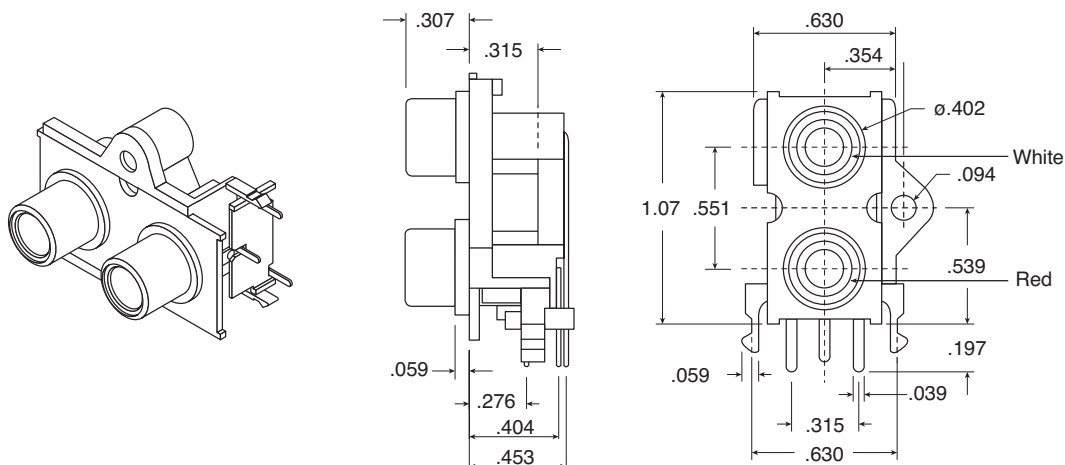

PCB Hole Layout

Specifications:

Type : PCB Dual Phono Vertical Mount

Rated Voltage : DC/AC 34V

Rated Current : DC/AC 2A

Temperature Range : -25° ~ +70°C

Humidity Range : 85% RH max.

Cover : ABS

Base : PBT

Insulator : PBT

Earth Terminal : Cu/Sn Plated

Terminals : Cu/Sn Plated

Insulator Color : Red / White

MOUSER STOCK NO.	Finish
156-4219-E	Cu/Sn Plated
156-4221-E	Gold Plated

Note: RoHS Compliant

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-2032021-1