


Flanged Spade Terminals

159-2230, 159-2236, 159-2238



Flanged Spade Terminals

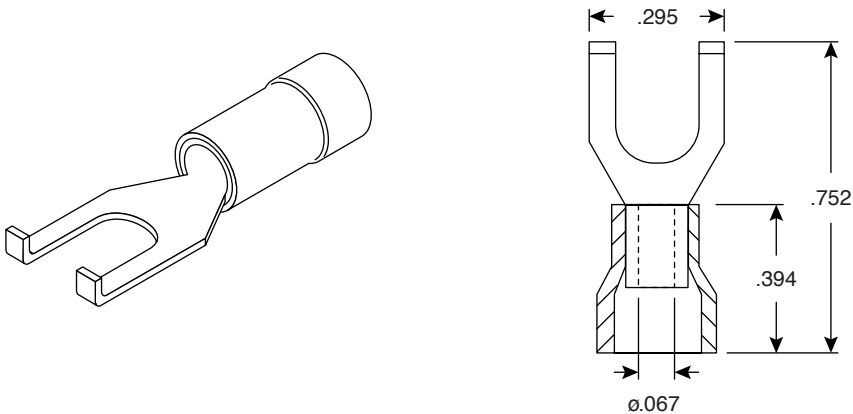

Dimensions: In.

SPECIFICATIONS	
Type:	flanged spade
Acceptable wire size:	22~16AWG
Voltage:	600V max. @ 75°C
Current:	19A max.
Insulation:	vinyl
Material:	copper
Material thickness:	.030"
Insulation color:	red
Stud size:	#6(159-2236), #8(159-2238), #10(159-2230)

Date Last Revised: 5-10-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300735

159-2230, 159-2236, 159-2238