


DC Power Cord 2.5mm

172-7444-E

KOBI CONN

DC Power Cord 2.5mm

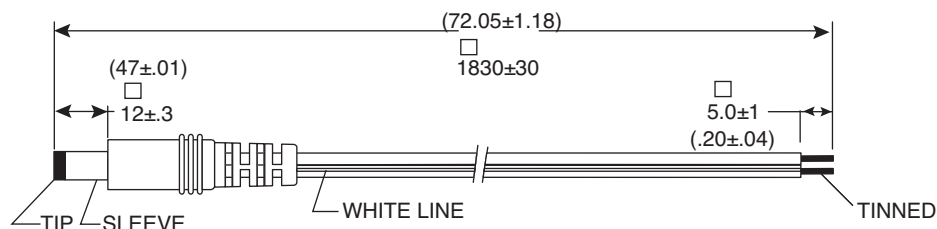

Dimensions: mm(in)

CONNECTIONS	
P1	COLOR
TIP	BLACK/WHITE LINE
SLEEVE	BLACK

ELECTRICAL SPECIFICATIONS	
ITEM	SPECIFICATIONS
1	Operation Temperature: $-10^{\circ}\text{C} \sim +60^{\circ}\text{C}$
2	Insulation Resistance: DC/500OV, 1M Ω Min.
3	Withstand Voltage: AC/25OV 5mA for one minute.
RoHS Compliant	

MATERIAL SPECIFICATIONS	
ITEM	SPECIFICATIONS
1	Tensile Strength: DC Plug overmold to cable shall withstand 8.8LBS (4Kgf) pull for one minute.
RoHS Compliant	

Date Last Revised: 08/19/08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301298

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7444-E