


# DC Power Cable 2.1mm

172-7445-E

KOBI CONN

DC Power Cable 2.1mm

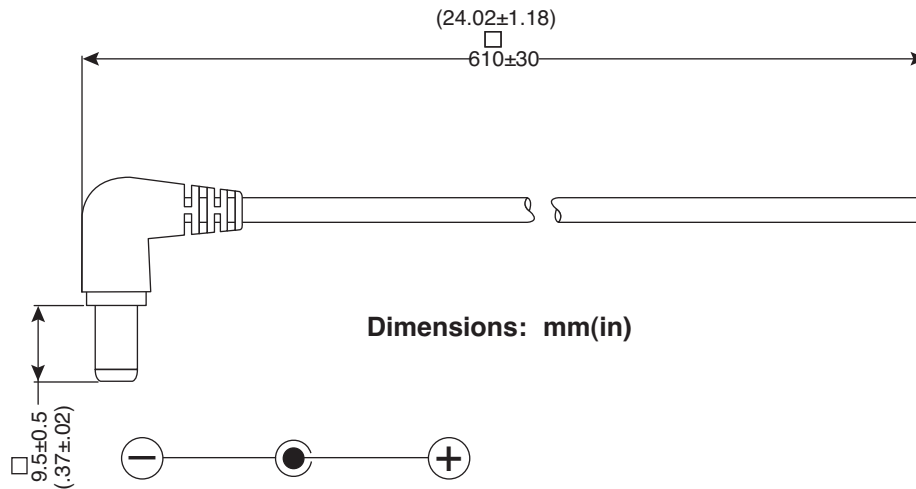

## ELECTRICAL SPECIFICATIONS

| ITEM           | SPECIFICATIONS                                  |
|----------------|-------------------------------------------------|
| 1              | Operation Temperature: -10°C ~ + 80°C           |
| 2              | Insulation Resistance: DC/25OV 5M $\Omega$ Min. |
| 3              | Withstand Voltage: AC/25OV 5mA, for one minute. |
| 4              | CONDUCTOR Resistance: 3 $\Omega$ Max.           |
| RoHS Compliant |                                                 |

## MATERIAL SPECIFICATIONS

| ITEM           | SPECIFICATIONS                                                                           |
|----------------|------------------------------------------------------------------------------------------|
| 1              | Tensile Strength:<br>Overmold to cable shall withstand 11LBS (5kgf) pull for one minute. |
| RoHS Compliant |                                                                                          |

Date Last Revised: 08/19/08

Available from Mouser Electronics  
1-800-346-6873 / [www.mouser.com](http://www.mouser.com)

KC-301299

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7445-E