


2.5mm Right Angle 4 Conductor Cable **KOBI** **CONN**

172-7446-E

2.5mm Right Angle 4 Conductor Cable

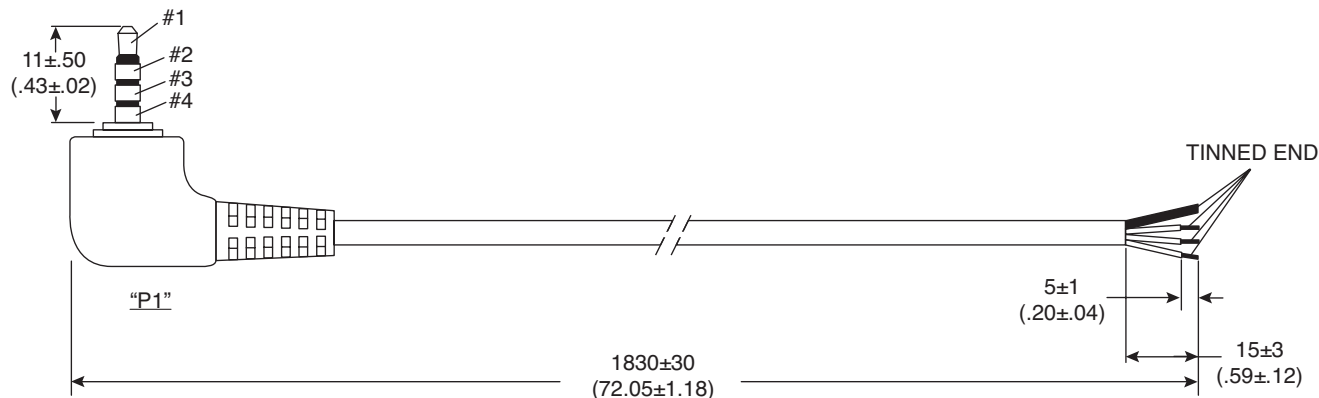

Dimensions: mm(in)

CONNECTION	
P1	WIRE COLOR
1	BLUE
2	WHITE
3	GREEN
4	DRAIN

ELECTRICAL SPECIFICATIONS

ITEM	SPECIFICATIONS
1	Operation Temperature: $0^{\circ}\text{C}^- \sim + 70^{\circ}\text{C}$
2	Storage Temperature: $-10^{\circ}\text{C}^- \sim + 50^{\circ}\text{C}$
3	Temperature Cycle: $50^{\circ}\text{C}/2$ Hours. $-10^{\circ}\text{C}/2$ Hours 3 Cycles.

MATERIAL SPECIFICATIONS

ITEM	SPECIFICATIONS
1	Tensile Strength: Overmold to cable shall withstand 11LBS (5kgf) pull for one minute.
2	Bending Test Both SR.: Load Weight: 500g, Angle: Left: 90° , Right: 90° , Total: 180° Speed: 30 Cycles/Min. The cable must withstand 5000 cycles bending and not broken.
RoHS Compliant	

Date Last Revised: 03/12/12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301300

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7446-E