


Cord Set Stereo

172-8362-E

KOBI CONN

Cord Set Stereo

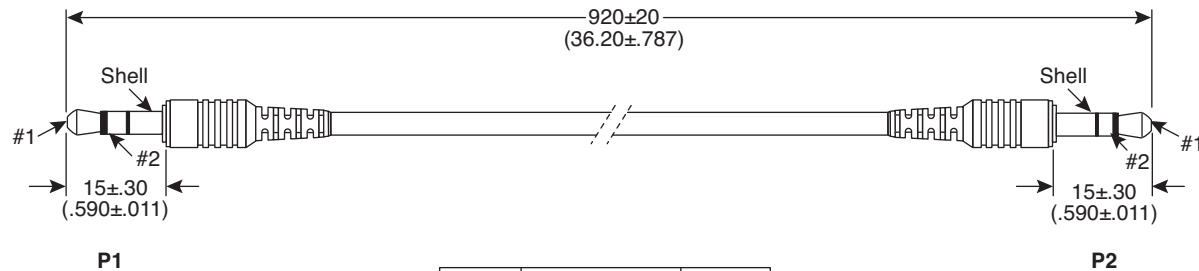

P1	Color	P2
1	White	1
2	Red	2
Shell	Spiral	Shell

Dimensions: mm (in.)

ELECTRICAL SPECIFICATIONS

Operation Temperature:	-10°C +80°C
Insulation Resistance:	DC/250V, 10MΩ Min.
Withstand Voltage:	AC/250V, 5mA for one minute
Continuity Test:	100%

MECHANICAL SPECIFICATIONS

Cable Construction	
Conductor:	26AWG (7/0, 16)x2C, tinned copper wire
Insulation:	PVC, 80°C, VW-1, $\phi 0.8 \pm .05$ mm
Color:	Red, White
Shield:	Spiral (40 ± 0.1) tinned copper wire
Jacket:	PVC, Black Matte Surface, $\phi 3.5 \pm .15$ mm, L=920±20mm
Tensile Strength:	PHN/M/3.5 overmold to cable shall withstand a load of 29.4N (3Kgf) for one minute
RoHS Compliant	

Date Last Revised: 10/24/08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301306

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-8362-E