


IDC DIP Flat Cable Plugs

151-2P14-E, 151-2P16-E, 151-2P24-E





KOBICONN

IDC DIP Flat Cable Plugs

DIMENSIONS: mm

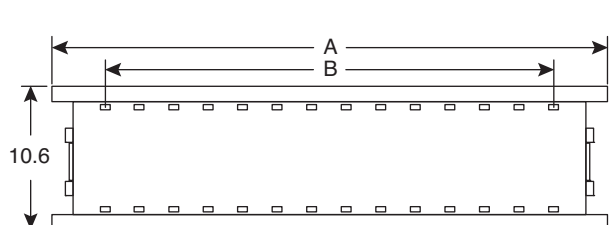

POSITION	A	B
14	23.06	15.24
16	25.60	17.78
24	35.76	27.94

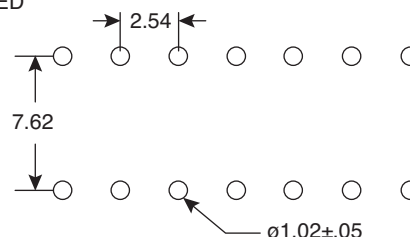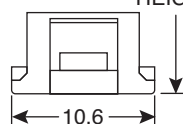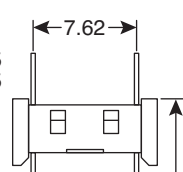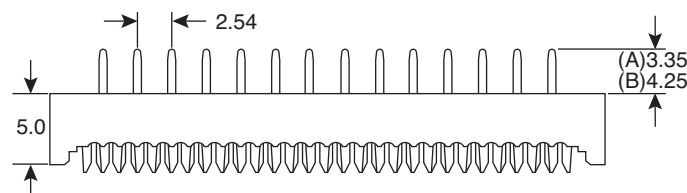

RoHS Compliant

RECOMMENDED P.C.B LAYOUT

ELECTRICAL SPECIFICATIONS

Current Rating:	1 Amp
Contact Resistance:	30mΩ max.
Insulation Resistance:	3000MΩ min.
Dielectric Withstanding Voltage:	Voltage: 500V AC for 1 minute
Operating Temperature:	-40°C to +105°C

MATERIAL

Insulator:	1 Amp
Contact:	Phosphor Bronze

Date Last Revised: 10-05-10

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301391

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

151-2P14-E, 151-2P16-E, 151-2P24-E