


DC Power Cord 2.1mm

172-7443-B-E

KOBI CONN

DC Power Cord 2.1mm

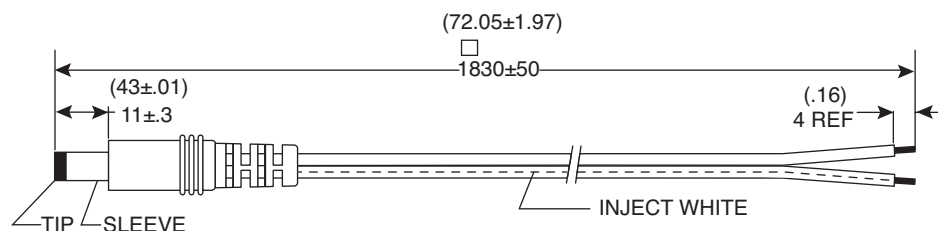

Dimensions: mm(in)

CONNECTIONS	
Plug	Black
Tip	Inject White
Sleeve	Black

ELECTRICAL SPECIFICATIONS	
ITEM	SPECIFICATIONS
1	Operation Temperature: -10°C ~ + 60°C
2	Insulation Resistance: DC/25OV, 10 M Ω Min.
3	Withstand Voltage: AC/25OV 5mA for one minute.

MATERIAL SPECIFICATIONS	
ITEM	SPECIFICATIONS
1	Tensile Strength: DC Plug overmold to cable jacket shall withstand 2Kg pull for one minute.
RoHS Compliant	

Date Last Revised: 3-26-13

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301437

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7443-B-E