


DIMENSIONS: mm

Date Last Revised: 10/17/19

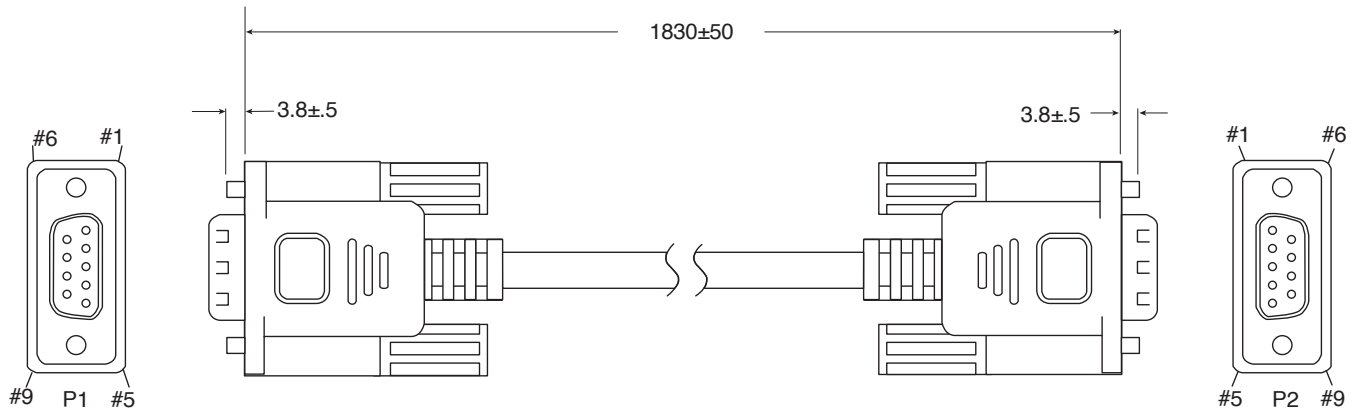

CONNECTION		
P1	WIRE COLOR	P2
1	BLACK	1
2	BROWN	2
3	RED	3
4	YELLOW	4
5	GREEN	5
6	BLUE	6
7	PURPLE	7
8	ORANGE	8
9	GRAY	9

SPECIFICATIONS	
Operation Temperature	-10°C~80°C
Isulation Resistance	DC/250V 5MΩ Min.
Continuity Resistance	5Ω
Tensile Strength	Overmold to cable jacket shall withstand 10Kgf pull min.for one minute.
RoHS Compliant	

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301449