




Triple Phone Jacks

156-4319-E, 156-4320-E, 156-4322-E

Date Last Revised:10/12/21

DIMENSIONS: In.

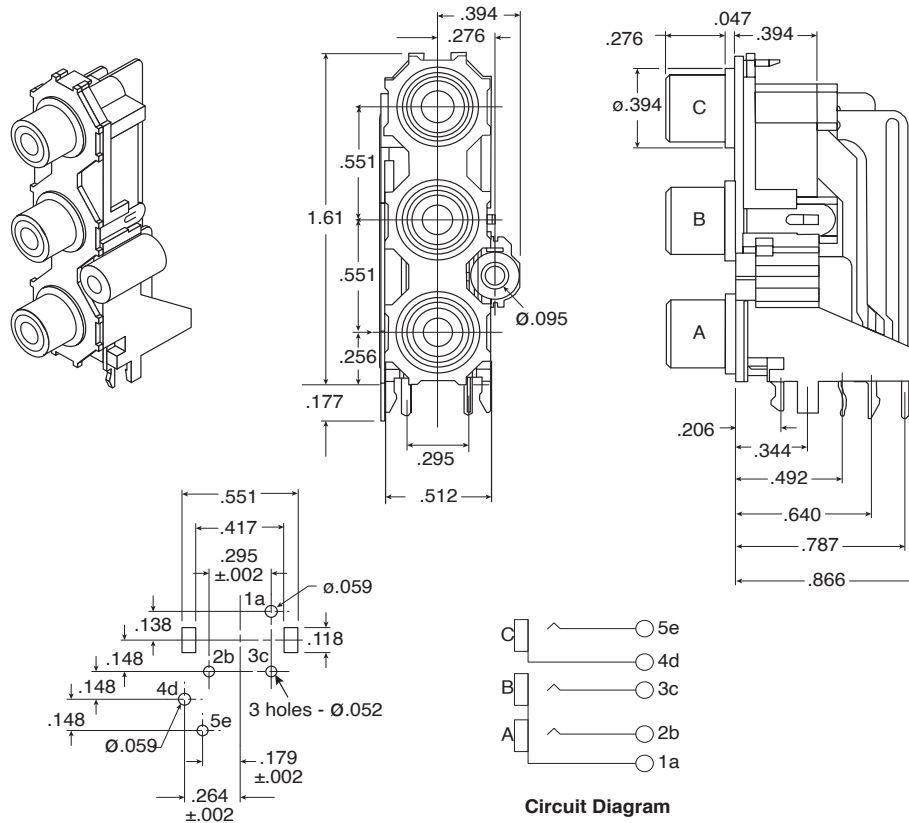

PCB Hole Layout (Bottom View)

SPECIFICATIONS :

- Type: Vertical Mount Triple Phono
- Rating : 2A/34VDC or 34VAC
- Temperature : -25°C ~ +70°C
- Contact resistance: $\leq 30\text{m}\Omega$
- withstanding voltage: 500VAC for 1 minute
- Insulation resistance: $\geq 100\text{M}\Omega$ @ 500VDC
- Insertion / Extraction force: .3Kgf ~ 4Kgf
- Wave Soldering Temp. : $230\pm 5^\circ$ for 3 seconds with $2\pm .5\text{mm}$ Dip
- Terminals: Cu/Sn Plated
- Brushing : Cu/Sn Plated
- Housing: PBT
- Insulators : PBT

MOUSER STOCK NO.	Colors		
	A	B	C
156-4319-E	Red	White	Yellow
156-4320-E	Red	Green	Blue
156-4322-E	Red	White	Orange

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301498