


Right Angle Vertical Type Plugs

156-4100-E, 156-4101-E, 156-4102-E, 156-4103-E,
156-4104-E, 156-4105-E, 156-4106-E, 156-4107-E

Date Last Revised: 6/12/24

DIMENSIONS: mm

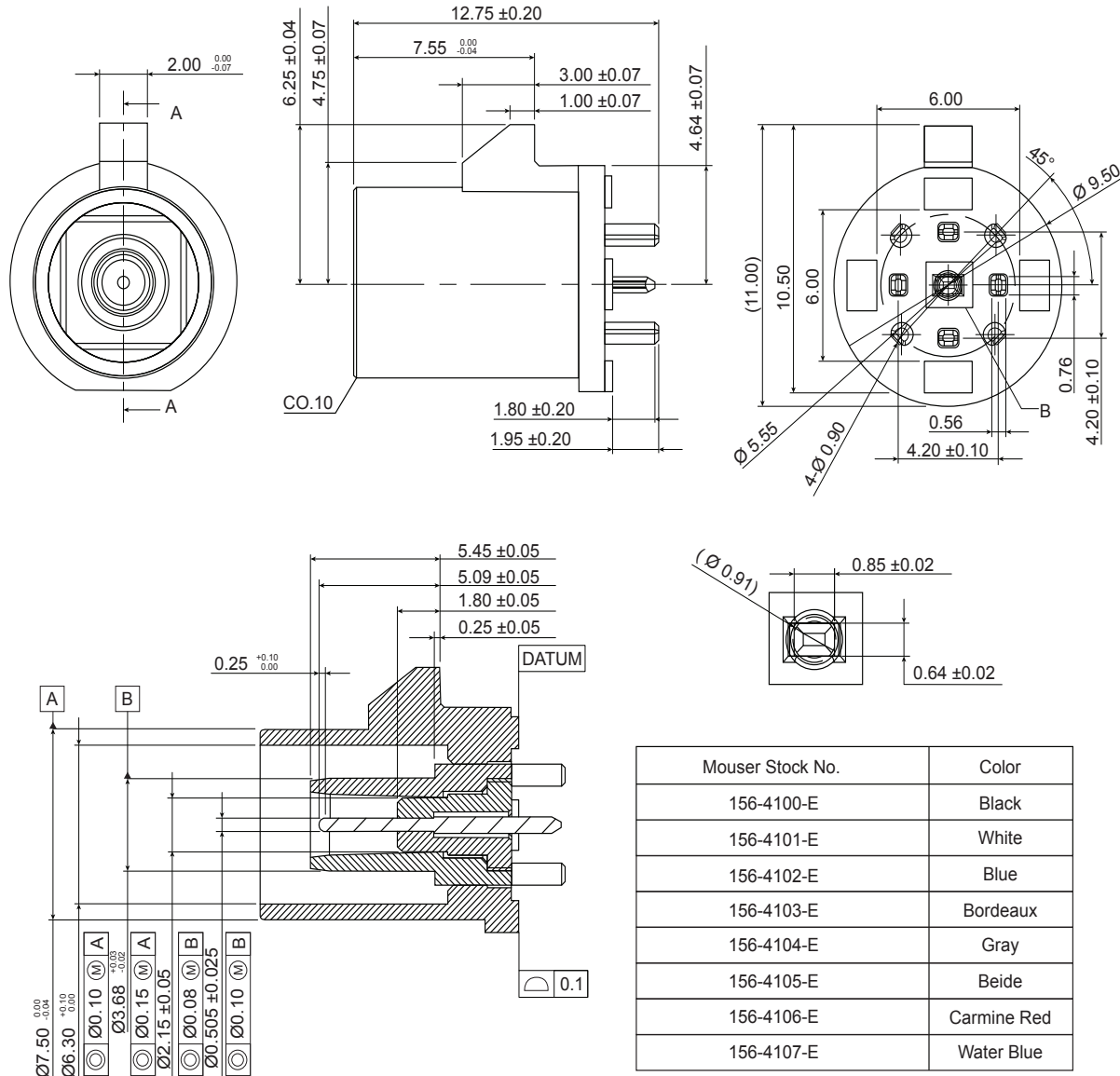

Specifications Materials:

- Insulator: PA6T (E630N)
- Contacts: Brass C2680
- Shell: Zamak3

Contact Plating:

- Contact Area: 6u" Selective Gold
- Solder Tails Area: 50u"~150u" Tin (Matte)

Electrical Specifications:

- Impedance: 50Ohms.
- Insulator Resistance: 1000Mohms Min. at 100VDC
- Withstanding Voltage: AC 780Vrms Min. 60Hz.
- Voltage Rating: AC 335Vrms.
- Current Rating: 1.0A Max.
- Contact Resistance: 5Mohms Max. at 20mV Max.
- Operation Temperature Range: -40°C to +105°C
- Mating Cycles: 25 Insertions.

Note: RoHS Compliant

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301555

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.