




Right Angle Connectors


156-4120-E to 156-4131-E

DIMENSIONS: mm

Date Last Revised: 06/24/24

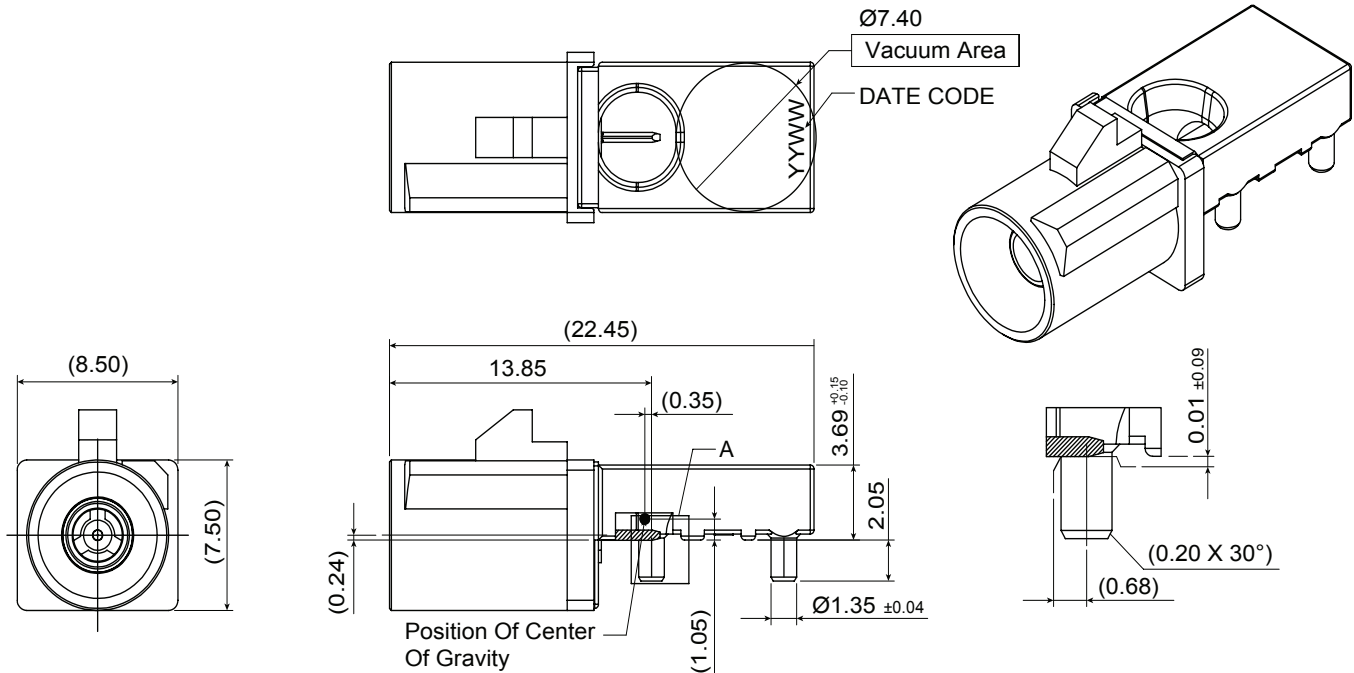

Mouser Stock No.	Color
156-4120-E	Black
156-4121-E	White
156-4122-E	Blue
156-4123-E	Bordeaux
156-4124-E	Green
156-4125-E	Brown
156-4126-E	Gray
156-4127-E	Violet
156-4128-E	Beige
156-4129-E	Curry
156-4130-E	Pastel Green
156-4131-E	Water Blue

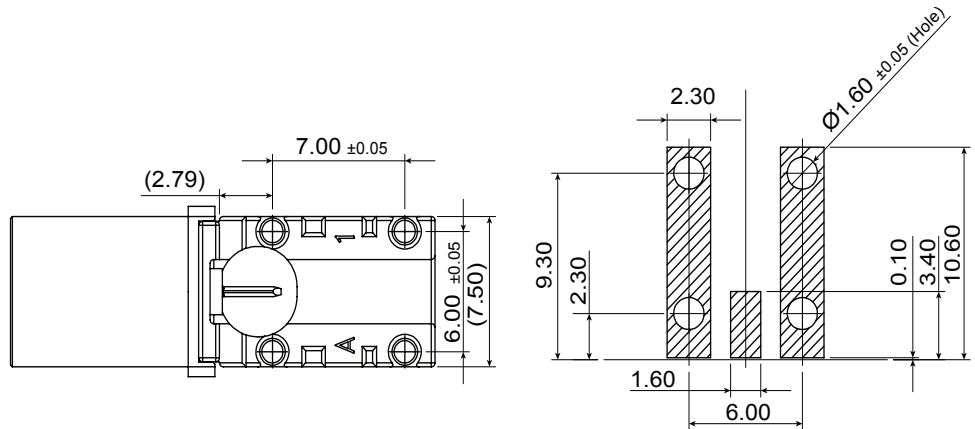

Recommended P.C.B Layout
Tolerance: ± 0.02 mm

Material Specifications:

- Insulator: LCP E130i
- Contacts: Brass C2680
- Shell: Zamak3

Electrical Specifications:

- Impedance: 50 Ω
- Insulator Resistance: 1000M Ω Min. at 100VDC
- Withstand Voltage: AC 780Vrms Min. 60Hz
- Voltage Rating: AC 335Vrms
- Current Rating: 1.0A Max.
- Contact Resistance: 5M Ω Max. at 20mV Max.

Note: RoHS Compliant

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301573