


2-POLE HOUSINGS


50 Amp HOUSINGS

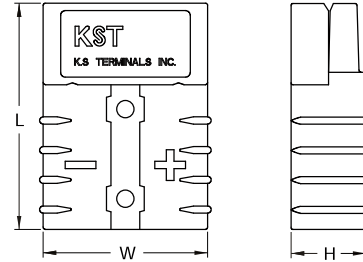

OPERATING TEMPERATURE RANGE: -20°C ~ +125°C
MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.
HOUSING MATERIAL: POLYCARBONATE(PC)
SPRING MATERIAL: STAINLESS STEEL

ITEM NO.	DIMENSION <small>inch mm</small>			DESCRIPTION	COLOR		Q'TY BOX
	W	L	H				
BMC2S-RED	1.374 34.9	1.890 48.0	.626 15.9	HOUSING WITH TWO SPRINGS, CAN BE USED WITH 50Amp SERIES CONTACTS	RED		25
BMC2S-GREY					GREY		25
BMC2S-BLACK					BLACK		25
BMC2S-BLUE					BLUE		25
BMC2S-GREEN					GREEN		25
BMC2S-ORANGE					ORANGE		25
BMC2S-YELLOW					YELLOW		25

120 Amp HOUSINGS

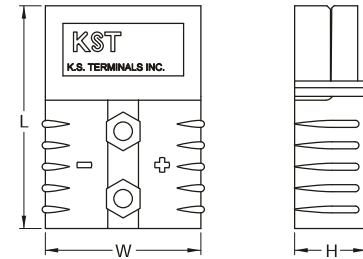

OPERATING TEMPERATURE RANGE: -20°C ~ +125°C
MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.
HOUSING MATERIAL: POLYCARBONATE(PC)
SPRING MATERIAL: STAINLESS STEEL

ITEM NO.	HOUSING COLOR	DIMENSION <small>inch mm</small>			DESCRIPTION	COLOR		Q'TY BOX
		W	L	H				
BMC2MS-RED	RED	1.748 44.4	2.50 63.51	.803 20.4	HOUSING WITH TWO SPRINGS, CAN BE USED WITH 120Amp SERIES CONTACTS	RED		10
BMC2MS-GREY	GREY					GREY		10
BMC2MS-BLUE	BLUE					BLUE		10



ALL LISTED

⊙ : NOT RU AND C-RU LISTED