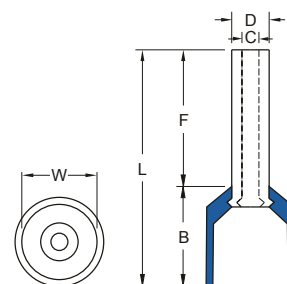


NYLON-INSULATED CORD END TERMINALS (E SERIES)

MAXIMUM ELECTRIC CURRENT:

A.W.G.	26	24	22	20	18
AMP.	5.5	7	9	12	17

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
CONNECTOR MATERIAL: COPPER TUBE.
INSULATION MATERIAL: NYLON


WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch mm						FRENCH COLOR	GERMAN COLOR	DIN COLOR	CRIMPING TOOL
		F	L	W	B	D	C				
24 A.W.G. 0.25 mm ²	E0205	.197 5.0	.370 9.4	.075 1.9	.173 4.4	.043 1.1	.031 0.8	VIOLET	LIGHT BLUE		K.S. MODEL LY8-060 WITH DIE INDEX NO:0.25-0.75
	E0206	.236 6.0	.409 10.4								
	E0208	.315 8.0	.488 12.4								
22 A.W.G. 0.34 mm ²	E0305	.197 5.0	.370 9.4	.075 1.9	.173 4.4	.043 1.1	.031 0.8	PINK	TURQUOISE		K.S. MODEL LY8-060 WITH DIE INDEX NO:0.25-0.75
	E0306	.236 6.0	.409 10.4								
	E0308	.315 8.0	.488 12.4								
	E0309	.354 9.0	.528 13.4								
20 A.W.G. 0.5 mm ²	E0505	.197 5.0	.433 11.0	.102 2.6	.236 6.0	.051 1.3	.039 1.0	WHITE	ORANGE	WHITE	K.S. MODEL KST2000L WITH DIE INDEX NO:0.5 OR K.S. MODEL LY8-060 WITH DIE INDEX NO:0.25-0.75
	E0506	.236 6.0	.472 12.0								
	E0508	.315 8.0	.551 14.0								
	E0509	.354 9.0	.591 15.0								
	E0510	.394 10.0	.630 16.0								
	E0512	.472 12.0	.709 18.0								
18 A.W.G. 0.75 mm ²	E7505	.197 5.0	.445 11.3	.110 2.8	.248 6.3	.059 1.5	.047 1.2	BLUE	WHITE	GREY	K.S. MODEL KST2000L WITH DIE INDEX NO:0.75 OR K.S. MODEL LY8-060 WITH DIE INDEX NO:0.25-0.75
	E7506	.236 6.0	.484 12.3								
	E7508	.315 8.0	.563 14.3								
	E7508-L	.315 8.0	.571 14.5								
	E7510	.394 10.0	.642 16.3								
	E7510-L	.394 10.0	.650 16.5								
	E7512	.472 12.0	.720 18.3								
	E7512-L	.472 12.0	.728 18.5								
	E7518	.709 18.0	.957 24.3								
	E7518-L	.709 18.0	.965 24.5								
18 A.W.G. 1.0 mm ²	E1006	.236 6.0	.472 12.0	.118 3.0	.248 6.3	.067 1.7	.055 1.4	RED	YELLOW	RED	K.S. MODEL KST2000L WITH DIE INDEX NO:1 OR K.S. MODEL LY8-060 WITH DIE INDEX NO:1-1.5
	E1006-L	.236 6.0	.492 12.5								
	E1008	.315 8.0	.551 14.0								
	E1008-L	.315 8.0	.571 14.5								
	E1010	.394 10.0	.630 16.0								
	E1010-L	.394 10.0	.650 16.5								
	E1012	.472 12.0	.709 18.0								



ALL LISTED

©: NOT RU AND C-RU LISTED