

HEAT SHRINKABLE-BUTT SPLICE CONNECTORS "HT"(TUBULAR TYPE)

MAXIMUM ELECTRIC CURRENT:


A.W.G.	26	24	22	20	18	16	14	12	10	8
AMP.	5.5	7	9	12	17	18	30	35	50	70

MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.

SHRINK TEMP.: 150°C OPERATING TEMP.: -40°C~+105°C

INSULATION MATERIAL: HIGH DENSITY PE.

TERMINAL MATERIAL: COPPER TUBULAR

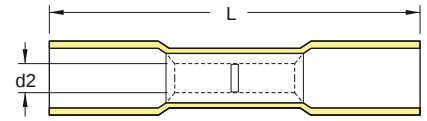

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch/mm				INSULATED COLOR	CRIMPING TOOL	Q'TY BOX
		d2		L				
26-22 A.W.G. 0.2-0.5 mm ²	BHT0.5	.051	1.3	1.138	28.9	CLEAR	K.S. MODEL YL8-067 WITH DIE INDEX NO:0.5	1000
22-16 A.W.G. 0.5-1.5 mm ²	BHT1	.067	1.7	1.417	36.0	RED	K.S. MODEL KST2000G WITH DIE INDEX NO.1	1000
16-14 A.W.G. 1.5-2.5 mm ²	BHT2	.091	2.3	1.417	36.0	BLUE	K.S. MODEL KST2000G WITH DIE INDEX NO.2	500
12-10 A.W.G. 4-6 mm ²	BHT5	.134	3.4	1.614	41.0	YELLOW	K.S. MODEL KST2000G WITH DIE INDEX NO.5	500
8 A.W.G. 8 mm ²	BHT8	.181	4.6	1.929	49.0	RED	K.S. MODEL LY-20450 OR IZUMI MODEL 8 WITH DIE INDEX NO:8	250

US ALL LISTED